

VS-IL-2XGOF-50-2XSCRJ-10 - FO connecting cable



1654442

<https://www.phoenixcontact.com/us/products/1654442>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



Assembled fiber optic cable, round cable, fiberglass multi-mode 50/125 μm , SC-RJ/IP67 on SC-RJ/IP67, for installation inside buildings, length: 10 m

Commercial data

Item number	1654442
Packing unit	1 pc
Note	Made to order (non-returnable)
Sales key	NULL
Product key	ABNIBC
GTIN	4017918970727
Weight per piece (including packing)	610.5 g
Weight per piece (excluding packing)	610.5 g
Customs tariff number	85447000
Country of origin	CH

VS-IL-2XGOF-50-2XSCRJ-10 - FO connecting cable



1654442

<https://www.phoenixcontact.com/us/products/1654442>

Technical data

Product properties

Product type	Data cable preassembled
Sensor type	Ethernet
Number of positions	2

Electrical properties

Attenuation	≤ 0.5 dB
-------------	----------

Mechanical properties

Mechanical data

Insertion/withdrawal cycles	≥ 1000
-----------------------------	--------

Material specifications

Seal material Cable seal	NBR
Housing material	PA
Outer sheath, material	PUR

Connector

Connection 1

Type	Plug straight SC-RJ
Degree of protection	IP67

Connection 2

Type	Plug straight SC-RJ
Degree of protection	IP67

Cable/line

Cable length	10.00 m
Cable type	Round cable
Outer sheath, material	PUR
External sheath, color	orange
Smallest bending radius, fixed installation	50 mm
Smallest bending radius, movable installation	50 mm
Ambient temperature (operation)	-20 °C ... 70 °C

FO cable

Number of fibers	2
Fiber type	GOF
Transmission medium	FO

VS-IL-2XGOF-50-2XSCRJ-10 - FO connecting cable




1654442

<https://www.phoenixcontact.com/us/products/1654442>


Drawings

Dimensional drawing

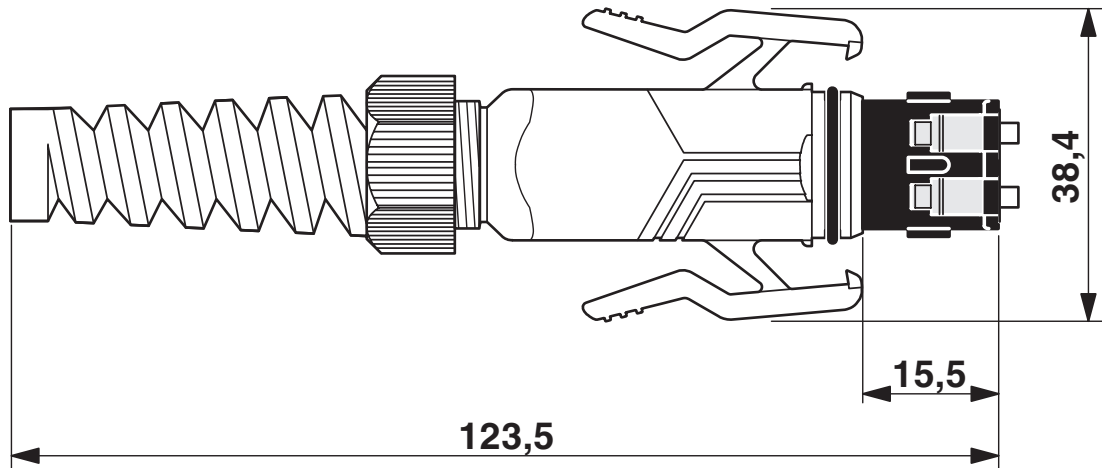

SC-RJ connector, GOF, IP67

Dimensional drawing

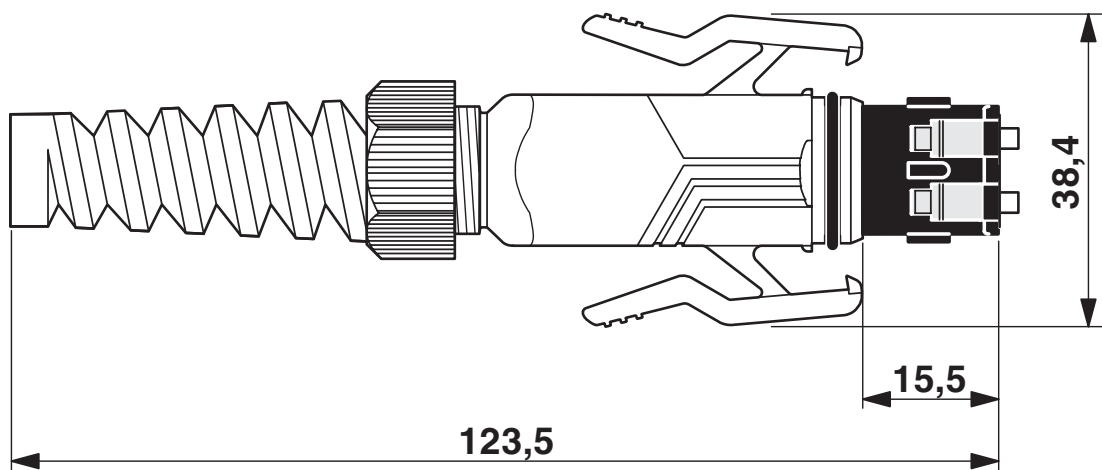

SC-RJ connector, GOF, IP67

VS-IL-2XGOF-50-2XSCRJ-10 - FO connecting cable



1654442

<https://www.phoenixcontact.com/us/products/1654442>

Environmental product compliance

EU REACH SVHC

REACH candidate substance (CAS No.)	
-------------------------------------	--

	No substance above 0.1 wt%
--	----------------------------

Phoenix Contact 2026 © - all rights reserved

<https://www.phoenixcontact.com>

Phoenix Contact USA
586 Fulling Mill Road
Middletown, PA 17057, United States
(+717) 944-1300
info@phoenixcon.com