

VS-ST-CD-HD-1,0/13,5/0,37 - D-SUB crimp contact



1655276

<https://www.phoenixcontact.com/us/products/1655276>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



Crimp contact, for D-SUB contact inserts with high density, pin, connection cross section AWG 22, turned, gold-plated

Commercial data

| | |
|--------------------------------------|--------------------------------|
| Item number | 1655276 |
| Packing unit | 1 pc |
| Note | Made to order (non-returnable) |
| Sales key | NULL |
| Product key | ABNCAA |
| GTIN | 4046356029216 |
| Weight per piece (including packing) | 0.09 g |
| Weight per piece (excluding packing) | 0.09 g |
| Customs tariff number | 85369010 |
| Country of origin | DE |

VS-ST-CD-HD-1,0/13,5/0,37 - D-SUB crimp contact



1655276

<https://www.phoenixcontact.com/us/products/1655276>

Technical data

Mounting

| | |
|---------------|------------------|
| Mounting type | Crimp connection |
|---------------|------------------|

Product properties

| | |
|-----------------------|---------------|
| Product type | Crimp contact |
| Contact material type | turned |

 
Connection data

| | |
|------------------------------|----------------------|
| Connection method | Crimp connection |
| Contact connection type | Pin |
| Connection technology | Crimp connection |
| Conductor cross-section | 0.34 mm ² |
| Connection cross section AWG | 22 |

Material specifications

| | |
|--------------------------|------------------------------|
| Contact material | Copper alloy |
| Contact surface material | Hard gold-plated over nickel |

Dimensions

| | |
|---------------------|--|
| Dimensional drawing |  |
| Length | 13.5 mm |

Mechanical characteristics

| | |
|------------------|------|
| Contact diameter | 1 mm |
|------------------|------|

Electrical properties

| | |
|-----------------------|--------|
| Rated voltage (III/3) | 60 V |
| Rated surge voltage | 1 kV |
| Rated current | 3 A |
| Insulation resistance | ≥ 5 GΩ |

Mechanical properties

Mechanical data

| | |
|-----------------------------|------|
| Insertion/withdrawal cycles | ≥ 50 |
|-----------------------------|------|

Environmental and real-life conditions

Ambient conditions

VS-ST-CD-HD-1,0/13,5/0,37 - D-SUB crimp contact



1655276

<https://www.phoenixcontact.com/us/products/1655276>

Ambient temperature (operation)

-55 °C ... 125 °C

VS-ST-CD-HD-1,0/13,5/0,37 - D-SUB crimp contact




1655276

<https://www.phoenixcontact.com/us/products/1655276>

Drawings

Dimensional drawing

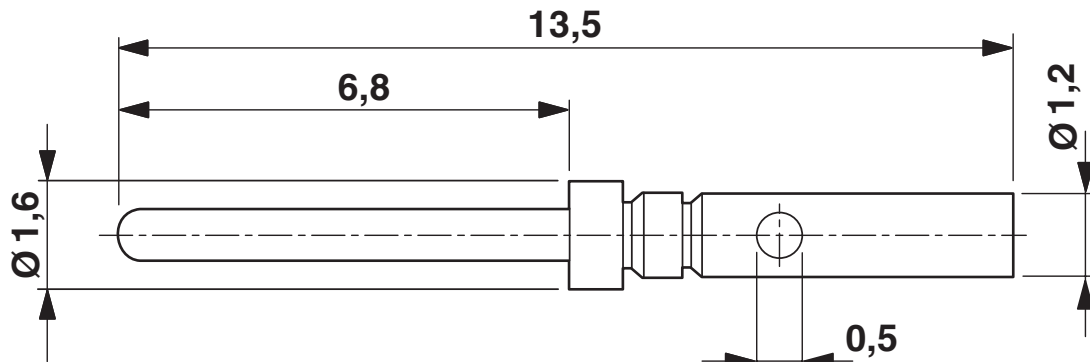

D-SUB crimp contact pin

Phoenix Contact 2026 © - all rights reserved
<https://www.phoenixcontact.com>

Phoenix Contact USA
586 Fulling Mill Road
Middletown, PA 17057, United States
(+717) 944-1300
info@phoenixcon.com