

# VS-15-ST-DSUB-3P-LH - D-SUB contact support



1655331

<https://www.phoenixcontact.com/us/products/1655331>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.

D-SUB contact carrier, shell size 2, accommodation for 3 combined contacts, type of contact pin, fixing with 4-40 UNC thread and solder pins, for panel mounting frame VS-15-...



## Your advantages

- Compatible with IP67 sleeve housing and panel-mount frame
- Easy assembly

## Commercial data

|                                      |               |
|--------------------------------------|---------------|
| Item number                          | 1655331       |
| Packing unit                         | 50 pc         |
| Minimum order quantity               | 1 pc          |
| Sales key                            | AB19          |
| Product key                          | ABNCAA        |
| GTIN                                 | 4046356029278 |
| Weight per piece (including packing) | 11.452 g      |
| Weight per piece (excluding packing) | 10.99 g       |
| Customs tariff number                | 85366990      |
| Country of origin                    | DE            |

1655331

<https://www.phoenixcontact.com/us/products/1655331>

## Technical data

### Notes

|                    |  |
|--------------------|--|
| Order information: | The contacts must be ordered separately since they are not included in the scope of supply of the combi contact inserts. |
|--------------------|--|

### Product properties

|                     |                            |
|---------------------|----------------------------|
| Product type        | Contact insert             |
| Application         | Combination contact insert |
| Type                | D-SUB                      |
| Number of positions | 3                          |
| Connection profile  | D-SUB                      |
| Shielded            | no                         |

### Electrical properties

|                     |        |
|---------------------|--------|
| Transmission medium | Copper |
|---------------------|--------|

### Connection data

|                   |       |
|-------------------|-------|
| Connection method | D-SUB |
|-------------------|-------|

### Material specifications

|  |                         |
|--|-------------------------|
| Flammability rating according to UL 94 | V0                      |
| Housing material                       | Steel, yellow chromated |
| Contact material                       | Copper alloy            |
| Contact surface material               | Gold over nickel        |
| Contact carrier material               | PBTP                    |

### Mechanical properties

#### Mechanical data

|                             |       |
|-----------------------------|-------|
| Insertion/withdrawal cycles | ≥ 500 |
|-----------------------------|-------|

### Environmental and real-life conditions

#### Ambient conditions

|                                 |                   |
|---------------------------------|-------------------|
| Degree of protection            | IP20              |
| Ambient temperature (operation) | -55 °C ... 125 °C |

### Mounting

|               |                         |
|---------------|-------------------------|
| Mounting type | Threads and solder pins |
|---------------|-------------------------|

# VS-15-ST-DSUB-3P-LH - D-SUB contact support




1655331

<https://www.phoenixcontact.com/us/products/1655331>

## Drawings

Drilling plan/solder pad geometry

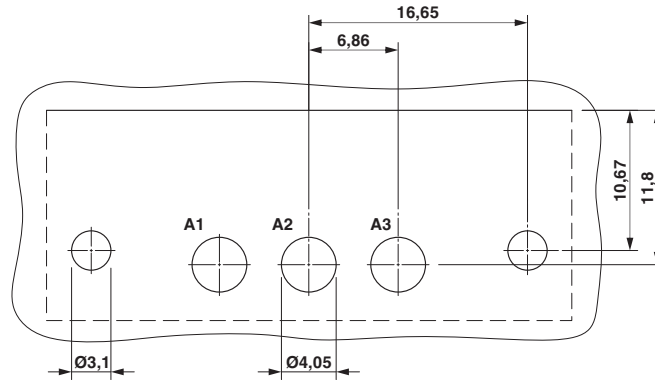

Drilling diagram

# VS-15-ST-DSUB-3P-LH - D-SUB contact support



1655331

<https://www.phoenixcontact.com/us/products/1655331>

## Approvals

To download certificates, visit the product detail page: <https://www.phoenixcontact.com/us/products/1655331>



**UL Recognized**

Approval ID: E118976

# VS-15-ST-DSUB-3P-LH - D-SUB contact support



1655331

<https://www.phoenixcontact.com/us/products/1655331>

## Classifications

### ECLASS

|             |          |
|-------------|----------|
| ECLASS-13.0 | 27440302 |
| ECLASS-15.0 | 27440323 |

### ETIM

|           |          |
|-----------|----------|
| ETIM 10.0 | EC001132 |
|-----------|----------|

### UNSPSC

|             |          |
|-------------|----------|
| UNSPSC 21.0 | 39121400 |
|-------------|----------|

1655331

<https://www.phoenixcontact.com/us/products/1655331>

## Environmental product compliance

### EU RoHS

|   |              |
|---|--------------|
| Fulfills EU RoHS substance requirements | Yes          |
| Exemption                               | 6(a), 6(a)-I |

### China RoHS

|  |   |
|--|---|
| Environment friendly use period (EFUP) | EFUP-50   |
|  | An article-related China RoHS declaration table can be found in the download area for the respective article under "Manufacturer declaration". For all articles with EFUP-E, no China RoHS declaration table issued and required. |

### EU REACH SVHC

|                                     |                                      |
|-------------------------------------|--------------------------------------|
| REACH candidate substance (CAS No.) | Lead(CAS: 7439-92-1)                 |
| SCIP                                | ebc2c67d-ac4b-4864-aedb-23412b446b1d |

Phoenix Contact 2026 © - all rights reserved

<https://www.phoenixcontact.com>

Phoenix Contact USA  
586 Fulling Mill Road  
Middletown, PA 17057, United States  
(+717) 944-1300  
[info@phoenixcon.com](mailto:info@phoenixcon.com)