


# VS-PN-CABLE-932-A/... - Network cable



1657342

<https://www.phoenixcontact.com/us/products/1657342>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.

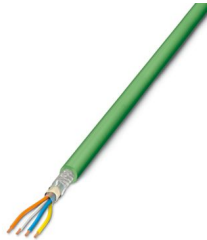

PROFINET cable type A, CAT5e-SF/Q cable, 1 x 4 x 22 AWG, solid (1-wire), shielded, outer sheath: PVC, outside diameter 6.5 mm, RAL 6018 (yellow-green), by the meter:

## Commercial data

Item number	1657342
Packing unit	1 pc
Note	Made to order (non-returnable)
Sales key	BF11
Product key	AF1LEA
Customs tariff number	85444980
Country of origin	DE

1657342

<https://www.phoenixcontact.com/us/products/1657342>

## Technical data

### Notes

General	This product corresponds to the PROFINET Cabling and Interconnection Technology Guideline for PROFINET regulations, version 2.00, order no: 2.252, Chapter 9.1.1 Balanced Cables (Type A,B,C)
---------	---

### Product properties

Product type	Data cable by the meter
Sensor type	PROFINET
Number of positions	4
Shielded	yes

### Electrical properties

Rated voltage (III/3)	125 V
Transmission medium	Copper
Transmission characteristics (category)	CAT5 (IEC 11801:2002)

### Interfaces

Signal type/category	PROFINET CAT5 (IEC 11801:2002)
----------------------	--------------------------------

### Cable/line

Cable length	Free input (0.2 ... 40.0 m)
Signal type/category	PROFINET CAT5 (IEC 11801:2002)
Ambient temperature (operation)	-40 °C ... 70 °C (cable, fixed installation)

### Environmental and real-life conditions

#### Ambient conditions

Ambient temperature (operation) (Cable, fixed installation)	-40 °C ... 70 °C (cable, fixed installation)
---	--

1657342

<https://www.phoenixcontact.com/us/products/1657342>

## Environmental product compliance

### China RoHS

Environment friendly use period (EFUP)	EFUP-50
	An article-related China RoHS declaration table can be found in the download area for the respective article under "Manufacturer declaration". For all articles with EFUP-E, no China RoHS declaration table issued and required.

### EU REACH SVHC

REACH candidate substance (CAS No.)	No substance above 0.1 wt%
-------------------------------------	----------------------------

Phoenix Contact 2026 © - all rights reserved  
<https://www.phoenixcontact.com>

Phoenix Contact USA  
586 Fulling Mill Road  
Middletown, PA 17057, United States  
(+717) 944-1300  
[info@phoenixcon.com](mailto:info@phoenixcon.com)