


VS-PN-CABLE-932-A/100 - Network cable



1657371

<https://www.phoenixcontact.com/us/products/1657371>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.

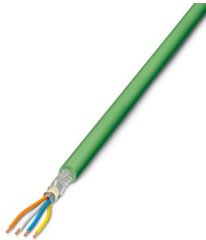

PROFINET cable type A, CAT5e-SF/Q cable, 1 x 4 x 22 AWG, solid (1-wire), shielded, outer sheath: PVC, outside diameter 6.5 mm, RAL 6018 (yellow-green), cable ring: 100 m

Commercial data

Item number	1657371
Packing unit	1 pc
Note	Made to order (non-returnable)
Sales key	BF11
Product key	AF1LFA
GTIN	4046356101646
Weight per piece (including packing)	6,720 g
Weight per piece (excluding packing)	6,720 g
Customs tariff number	85445190
Country of origin	DE

1657371

<https://www.phoenixcontact.com/us/products/1657371>

Technical data

Notes

General	This product corresponds to the PROFINET Cabling and Interconnection Technology Guideline for PROFINET regulations, version 2.00, order no: 2.252, Chapter 9.1.1 Balanced Cables (Type A,B,C)
---------	---

Product properties

Product type	Data cable by the meter
Sensor type	PROFINET
Number of positions	4
Shielded	yes

Electrical properties

Rated voltage (III/3)	125 V
Transmission medium	Copper
Transmission characteristics (category)	CAT5 (IEC 11801:2002)

Interfaces

Signal type/category	PROFINET CAT5 (IEC 11801)
----------------------	---------------------------

Cable/line

Cable length	100 m
Signal type/category	PROFINET CAT5 (IEC 11801)
Ambient temperature (operation)	-40 °C ... 70 °C (cable, fixed installation)

Environmental and real-life conditions

Ambient conditions

Ambient temperature (operation) (Cable, fixed installation)	-40 °C ... 70 °C (cable, fixed installation)
---	--

1657371

<https://www.phoenixcontact.com/us/products/1657371>

Environmental product compliance

China RoHS

Environment friendly use period (EFUP)	EFUP-50
	An article-related China RoHS declaration table can be found in the download area for the respective article under "Manufacturer declaration". For all articles with EFUP-E, no China RoHS declaration table issued and required.

EU REACH SVHC

REACH candidate substance (CAS No.)	No substance above 0.1 wt%
-------------------------------------	----------------------------

Phoenix Contact 2026 © - all rights reserved
<https://www.phoenixcontact.com>

Phoenix Contact USA
586 Fulling Mill Road
Middletown, PA 17057, United States
(+717) 944-1300
info@phoenixcon.com