

HC-B 10-AP-GY - Cover plate



1660371

<https://www.phoenixcontact.com/us/products/1660371>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.

HEAVYCON cover plate, for panel cutouts of type B10/HV3, 3.5 mm thick, gray



Commercial data

| | |
|--------------------------------------|---------------|
| Item number | 1660371 |
| Packing unit | 10 pc |
| Minimum order quantity | 1 pc |
| Sales key | BF66 |
| Product key | AF7AZD |
| GTIN | 4017918022013 |
| Weight per piece (including packing) | 19.94 g |
| Weight per piece (excluding packing) | 18.35 g |
| Customs tariff number | 39269097 |
| Country of origin | DE |

HC-B 10-AP-GY - Cover plate

1660371


<https://www.phoenixcontact.com/us/products/1660371>

Technical data

Product properties

| | |
|--------------|-------------|
| Product type | Cover plate |
| Type | B10/HV3 |
| Seal present | yes |

Dimensions
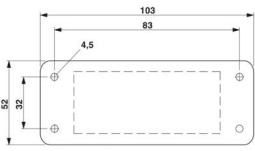
| | |
|---------------------------------|--|
| Dimensional drawing |  |
| Width | 52 mm |
| Height | 4.5 mm |
| Length | 103 mm |
| Drill hole distance, horizontal | 83 mm |
| Drill hole distance, vertical | 32 mm |
| Hole diameter | 4.5 mm |

Installation dimensions

| | |
|-------------------------------|-------|
| Width of the assembly cutout | 36 mm |
| Length of the assembly cutout | 65 mm |

Material specifications

| | |
|--|-----|
| Material | PA |
| Flammability rating according to UL 94 | HB |
| Seal material | PTS |

Environmental and real-life conditions

Ambient conditions

| | |
|---------------------------------|-------------------|
| Degree of protection | IP54 |
| Ambient temperature (operation) | -20 °C ... 100 °C |


HC-B 10-AP-GY - Cover plate

1660371

<https://www.phoenixcontact.com/us/products/1660371>



Drawings

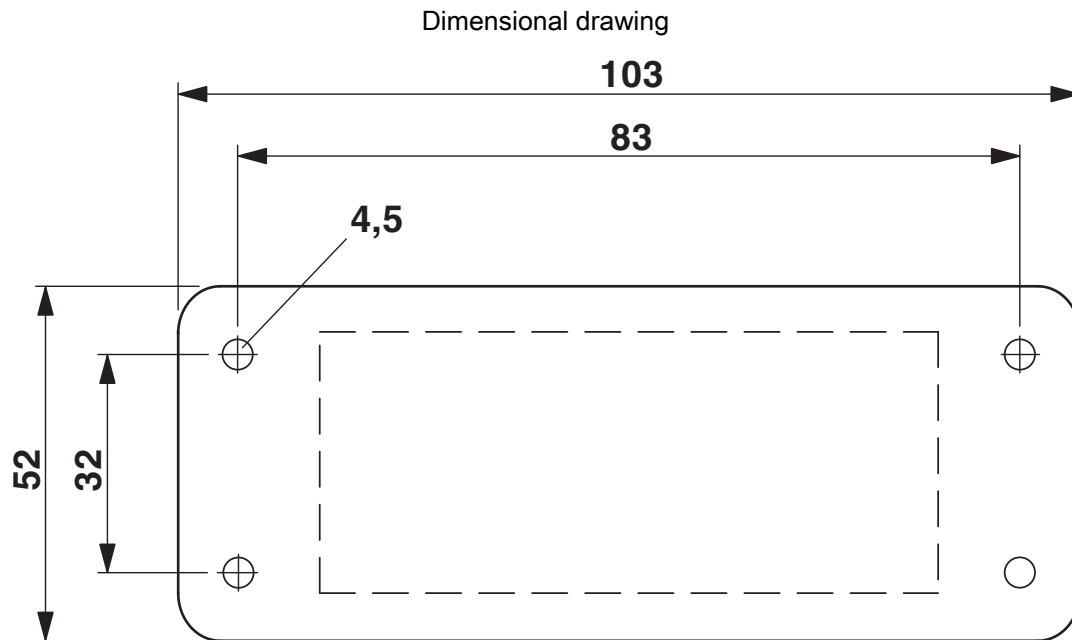

Dimensional drawing

HC-B 10-AP-GY - Cover plate



1660371

<https://www.phoenixcontact.com/us/products/1660371>

Classifications

ECLASS

| | |
|-------------|----------|
| ECLASS-13.0 | 27440201 |
| ECLASS-15.0 | 27440201 |

ETIM

| | |
|-----------|----------|
| ETIM 10.0 | EC002309 |
|-----------|----------|

UNSPSC

| | |
|-------------|----------|
| UNSPSC 21.0 | 31261500 |
|-------------|----------|

HC-B 10-AP-GY - Cover plate



1660371

<https://www.phoenixcontact.com/us/products/1660371>

Environmental product compliance

EU RoHS

| | |
|---|--------------------|
| Fulfills EU RoHS substance requirements | Yes, No exemptions |
|---|--------------------|

China RoHS

| | |
|--|--|
| Environment friendly use period (EFUP) | EFUP-E |
| | No hazardous substances above the limits |

EU REACH SVHC

| | |
|-------------------------------------|----------------------------|
| REACH candidate substance (CAS No.) | No substance above 0.1 wt% |
|-------------------------------------|----------------------------|

EF3.1 Climate Change

| | |
|---------|---------------|
| CO2e kg | 0.323 kg CO2e |
|---------|---------------|

Phoenix Contact 2026 © - all rights reserved
<https://www.phoenixcontact.com>

Phoenix Contact USA
586 Fulling Mill Road
Middletown, PA 17057, United States
(+717) 944-1300
info@phoenixcon.com