

HC-B 24-APV-GY - Cover plate



1661037

<https://www.phoenixcontact.com/us/products/1661037>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.

HEAVYCON cover plate, for wall cutouts of type B24, 7 mm thick, gray



Commercial data

| | |
|--------------------------------------|---------------|
| Item number | 1661037 |
| Packing unit | 10 pc |
| Minimum order quantity | 1 pc |
| Sales key | BF66 |
| Product key | AF7AZD |
| GTIN | 4017918022433 |
| Weight per piece (including packing) | 36.2 g |
| Weight per piece (excluding packing) | 36.2 g |
| Customs tariff number | 39269097 |
| Country of origin | DE |

HC-B 24-APV-GY - Cover plate

1661037


<https://www.phoenixcontact.com/us/products/1661037>

Technical data

Product properties

| | |
|--------------|-------------|
| Product type | Cover plate |
| Type | B24 |
| Seal present | yes |

Dimensions
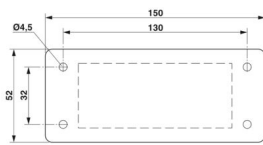
| | |
|---------------------------------|--|
| Dimensional drawing |  |
| Width | 52 mm |
| Height | 7 mm |
| Length | 150 mm |
| Drill hole distance, horizontal | 130 mm |
| Drill hole distance, vertical | 32 mm |
| Hole diameter | 4.5 mm |

Installation dimensions

| | |
|-------------------------------|--------|
| Width of the assembly cutout | 36 mm |
| Length of the assembly cutout | 113 mm |

Material specifications

| | |
|--|----|
| Material | PA |
| Flammability rating according to UL 94 | HB |

Environmental and real-life conditions

Ambient conditions

| | |
|---------------------------------|-------------------|
| Degree of protection | IP54 |
| Ambient temperature (operation) | -20 °C ... 100 °C |

HC-B 24-APV-GY - Cover plate




1661037

<https://www.phoenixcontact.com/us/products/1661037>

Drawings

Dimensional drawing

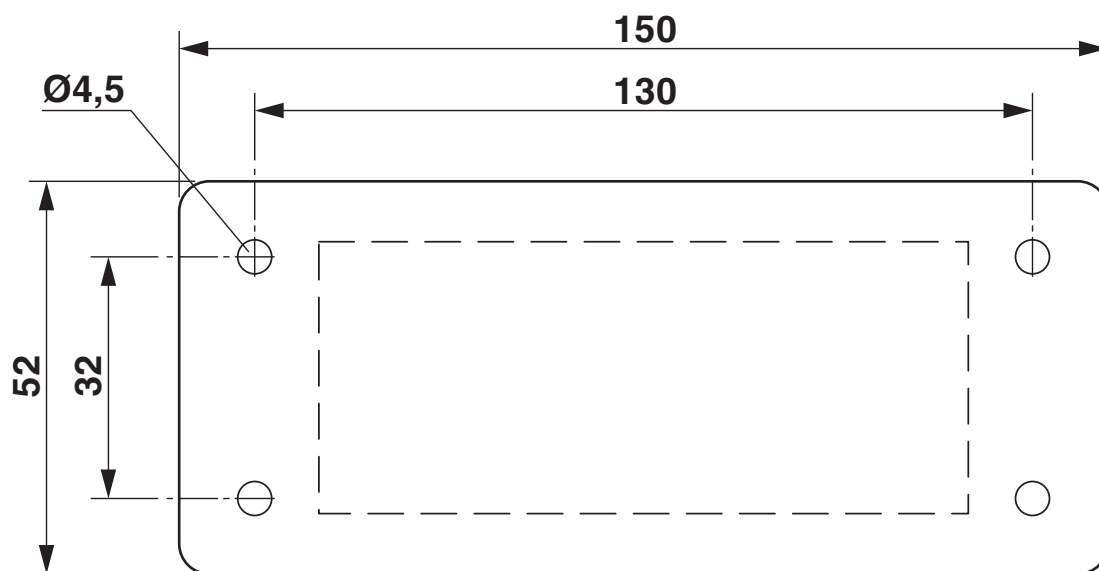

Processing area 2 mm thick

HC-B 24-APV-GY - Cover plate



1661037

<https://www.phoenixcontact.com/us/products/1661037>

Classifications

ECLASS

| | |
|-------------|----------|
| ECLASS-13.0 | 27440201 |
| ECLASS-15.0 | 27440201 |

ETIM

| | |
|-----------|----------|
| ETIM 10.0 | EC002309 |
|-----------|----------|

UNSPSC

| | |
|-------------|----------|
| UNSPSC 21.0 | 31261500 |
|-------------|----------|

HC-B 24-APV-GY - Cover plate



1661037

<https://www.phoenixcontact.com/us/products/1661037>

Environmental product compliance

EU RoHS

| | |
|---|--------------------|
| Fulfills EU RoHS substance requirements | Yes, No exemptions |
|---|--------------------|

China RoHS

| | |
|--|--|
| Environment friendly use period (EFUP) | EFUP-E |
| | No hazardous substances above the limits |

EU REACH SVHC

| | |
|-------------------------------------|----------------------------|
| REACH candidate substance (CAS No.) | No substance above 0.1 wt% |
|-------------------------------------|----------------------------|

EF3.1 Climate Change

| | |
|---------|---------------|
| CO2e kg | 0.379 kg CO2e |
|---------|---------------|

Phoenix Contact 2026 © - all rights reserved
<https://www.phoenixcontact.com>

Phoenix Contact USA
586 Fulling Mill Road
Middletown, PA 17057, United States
(+717) 944-1300
info@phoenixcon.com