

HC-B 24-ADP-3RST-GY - Adapter plate



1662175

<https://www.phoenixcontact.com/us/products/1662175>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



Adapter plates with a reinforced wall, three openings for an M23 circular connector; type B24 on an M23 circular connector; for panel cutouts of type B24; gray

Commercial data

| | |
|--------------------------------------|---------------|
| Item number | 1662175 |
| Packing unit | 10 pc |
| Minimum order quantity | 1 pc |
| Sales key | BF66 |
| Product key | AF7AZD |
| GTIN | 4017918100087 |
| Weight per piece (including packing) | 37.9 g |
| Weight per piece (excluding packing) | 37.34 g |
| Customs tariff number | 39269097 |
| Country of origin | DE |

HC-B 24-ADP-3RST-GY - Adapter plate



1662175

<https://www.phoenixcontact.com/us/products/1662175>

Technical data

Product properties

| | |
|--------------|---------------|
| Product type | Adapter plate |
| Type | B24 |
| Seal present | yes |

Dimensions

| | |
|---------------------------------|--------|
| Dimensional drawing | |
| Width | 52 mm |
| Height | 7 mm |
| Length | 150 mm |
| Drill hole distance, horizontal | 130 mm |
| Drill hole distance, vertical | 32 mm |
| Hole diameter | 4.5 mm |

Internal dimensions

| | |
|---------------------------|-----------|
| Internal cutout dimension | 3 x 21 mm |
|---------------------------|-----------|

Installation dimensions

| | |
|-------------------------------|--------|
| Width of the assembly cutout | 36 mm |
| Length of the assembly cutout | 113 mm |

Material specifications

| | |
|--|-----|
| Material | PA |
| Flammability rating according to UL 94 | HB |
| Seal material | PTS |

Environmental and real-life conditions

Ambient conditions

| | |
|---------------------------------|-------------------|
| Degree of protection | IP54 |
| Ambient temperature (operation) | -20 °C ... 100 °C |


HC-B 24-ADP-3RST-GY - Adapter plate



1662175

<https://www.phoenixcontact.com/us/products/1662175>

Drawings

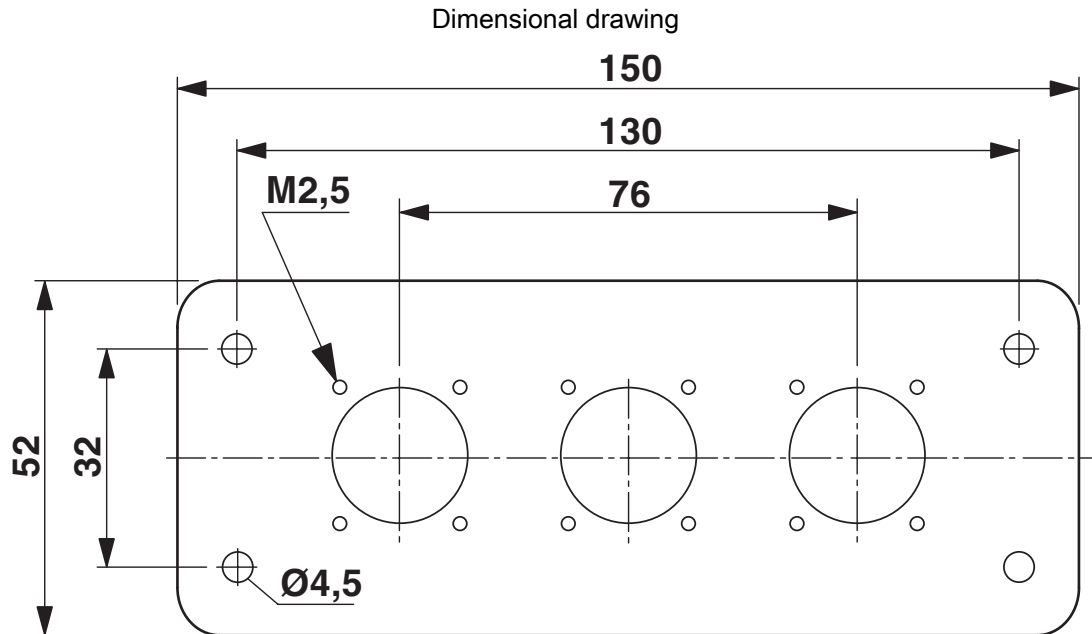

HC-B 24-ADP-3RST-GY - Adapter plate



1662175

<https://www.phoenixcontact.com/us/products/1662175>

Classifications

ECLASS

| | |
|-------------|----------|
| ECLASS-13.0 | 27440201 |
| ECLASS-15.0 | 27440201 |

ETIM

| | |
|-----------|----------|
| ETIM 10.0 | EC002309 |
|-----------|----------|

UNSPSC

| | |
|-------------|----------|
| UNSPSC 21.0 | 31261500 |
|-------------|----------|

HC-B 24-ADP-3RST-GY - Adapter plate



1662175

<https://www.phoenixcontact.com/us/products/1662175>

Environmental product compliance

EU RoHS

| | |
|---|--------------------|
| Fulfills EU RoHS substance requirements | Yes, No exemptions |
|---|--------------------|

China RoHS

| | |
|--|--|
| Environment friendly use period (EFUP) | EFUP-E |
| | No hazardous substances above the limits |

EU REACH SVHC

| | |
|-------------------------------------|----------------------------|
| REACH candidate substance (CAS No.) | No substance above 0.1 wt% |
|-------------------------------------|----------------------------|

Phoenix Contact 2026 © - all rights reserved
<https://www.phoenixcontact.com>

Phoenix Contact USA
586 Fulling Mill Road
Middletown, PA 17057, United States
(+717) 944-1300
info@phoenixcon.com