

# HC-M-PN3-3,00-ST - Pneumatic contact



1663491

<https://www.phoenixcontact.com/us/products/1663491>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.

Pneumatic pin, for HC-M-PN3 module, internal hose diameter of 3.0 mm



## Commercial data

|                                      |               |
|--------------------------------------|---------------|
| Item number                          | 1663491       |
| Packing unit                         | 10 pc         |
| Minimum order quantity               | 1 pc          |
| Sales key                            | BF62          |
| Product key                          | AF7ACZ        |
| GTIN                                 | 4017918123307 |
| Weight per piece (including packing) | 0.86 g        |
| Weight per piece (excluding packing) | 0.8 g         |
| Customs tariff number                | 39174000      |
| Country of origin                    | US            |

# HC-M-PN3-3,00-ST - Pneumatic contact



1663491

<https://www.phoenixcontact.com/us/products/1663491>

## Technical data

### Product properties

 
|                  |                   |
|------------------|-------------------|
| Product type     | Pneumatic contact |
| Series           | HC-M-03-PN        |
| Integrated valve | No                |

### Connection data

#### Connection technology

|                         |                 |
|-------------------------|-----------------|
| Contact connection type | Pin             |
| Connection method       | Tube connection |

### Dimensions

|                                   |   |
|-----------------------------------|---|
| Dimensional drawing               |  |
| Width [w]                         | 8.2 mm  |
| Height [h]                        | 8.2 mm  |
| Depth                             | 20.4 mm   |
| Diameter (Internal hose diameter) | 3 mm  |
| Diameter (Contact diameter)       | 5.2 mm  |

### Material specifications

|                  |               |
|------------------|---------------|
| Material Valve   | Polypropylene |
| Material Seal    | Buna-N        |
| Material Contact | Delrin Acetal |

### Mechanical properties

#### Mechanical data

|                             |       |
|-----------------------------|-------|
| Insertion/withdrawal cycles | ≥ 500 |
|-----------------------------|-------|

### Characteristics

|                    |          |
|--------------------|----------|
| Operating pressure | 8.00 bar |
|--------------------|----------|

### Environmental and real-life conditions

#### Ambient conditions

|                                 |                  |
|---------------------------------|------------------|
| Ambient temperature (operation) | -40 °C ... 80 °C |
|---------------------------------|------------------|

# HC-M-PN3-3,00-ST - Pneumatic contact




1663491

<https://www.phoenixcontact.com/us/products/1663491>

## Drawings

Dimensional drawing

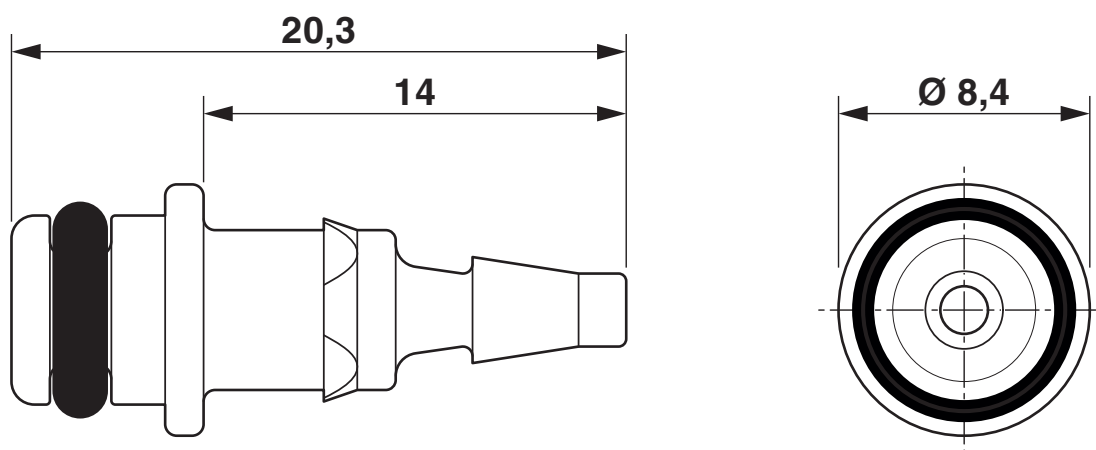

# HC-M-PN3-3,00-ST - Pneumatic contact



1663491

<https://www.phoenixcontact.com/us/products/1663491>

## Approvals

To download certificates, visit the product detail page: <https://www.phoenixcontact.com/us/products/1663491>



**EAC**

Approval ID: RU C-DE.AI30.B.01102

# HC-M-PN3-3,00-ST - Pneumatic contact



1663491

<https://www.phoenixcontact.com/us/products/1663491>

## Classifications

### ECLASS

|             |          |
|-------------|----------|
| ECLASS-13.0 | 27440204 |
| ECLASS-15.0 | 27440204 |

### ETIM

|           |          |
|-----------|----------|
| ETIM 10.0 | EC000796 |
|-----------|----------|

### UNSPSC

|             |          |
|-------------|----------|
| UNSPSC 21.0 | 39121500 |
|-------------|----------|

# HC-M-PN3-3,00-ST - Pneumatic contact



1663491

<https://www.phoenixcontact.com/us/products/1663491>

## Environmental product compliance

### EU RoHS

|   |                    |
|---|--------------------|
| Fulfills EU RoHS substance requirements | Yes, No exemptions |
|---|--------------------|

### China RoHS

|  |  |
|--|--|
| Environment friendly use period (EFUP) | EFUP-E                                   |
|  | No hazardous substances above the limits |

### EU REACH SVHC

|                                     |                            |
|-------------------------------------|----------------------------|
| REACH candidate substance (CAS No.) | No substance above 0.1 wt% |
|-------------------------------------|----------------------------|

### EF3.1 Climate Change

|         |               |
|---------|---------------|
| CO2e kg | 0.368 kg CO2e |
|---------|---------------|

Phoenix Contact 2026 © - all rights reserved  
<https://www.phoenixcontact.com>

Phoenix Contact USA  
586 Fulling Mill Road  
Middletown, PA 17057, United States  
(+717) 944-1300  
[info@phoenixcon.com](mailto:info@phoenixcon.com)