

HC-M-PN3-3,00-BU - Pneumatic contact



1663527

<https://www.phoenixcontact.com/us/products/1663527>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.

Pneumatic socket, for HC-M-PN3 module, internal hose diameter of 3.0 mm



Commercial data

| | |
|--------------------------------------|---------------|
| Item number | 1663527 |
| Packing unit | 10 pc |
| Minimum order quantity | 10 pc |
| Sales key | BF62 |
| Product key | AF7ACZ |
| GTIN | 4017918123338 |
| Weight per piece (including packing) | 0.9 g |
| Weight per piece (excluding packing) | 0.74 g |
| Customs tariff number | 39174000 |
| Country of origin | US |

HC-M-PN3-3,00-BU - Pneumatic contact



1663527

<https://www.phoenixcontact.com/us/products/1663527>

Technical data

Product properties

 
| | |
|------------------|-------------------|
| Product type | Pneumatic contact |
| Series | HC-M-03-PN |
| Integrated valve | No |

Connection data

Connection technology

| | |
|-------------------------|-----------------|
| Contact connection type | Socket |
| Connection method | Tube connection |

Dimensions

| | |
|-----------------------------------|---|
| Dimensional drawing |  |
| Width [w] | 8.2 mm |
| Height [h] | 8.2 mm |
| Depth | 25.5 mm |
| Diameter (Internal hose diameter) | 3 mm |
| Diameter (Contact diameter) | 5.2 mm |

Material specifications

| | |
|------------------|---------------|
| Material Valve | Polypropylene |
| Material Seal | Buna-N |
| Material Contact | Delrin Acetal |

Mechanical properties

Mechanical data

| | |
|-----------------------------|-------|
| Insertion/withdrawal cycles | ≥ 500 |
|-----------------------------|-------|

Characteristics

| | |
|--------------------|----------|
| Operating pressure | 8.00 bar |
|--------------------|----------|

Environmental and real-life conditions

Ambient conditions

| | |
|---------------------------------|------------------|
| Ambient temperature (operation) | -40 °C ... 80 °C |
|---------------------------------|------------------|

HC-M-PN3-3,00-BU - Pneumatic contact




1663527

<https://www.phoenixcontact.com/us/products/1663527>

Drawings

Dimensional drawing

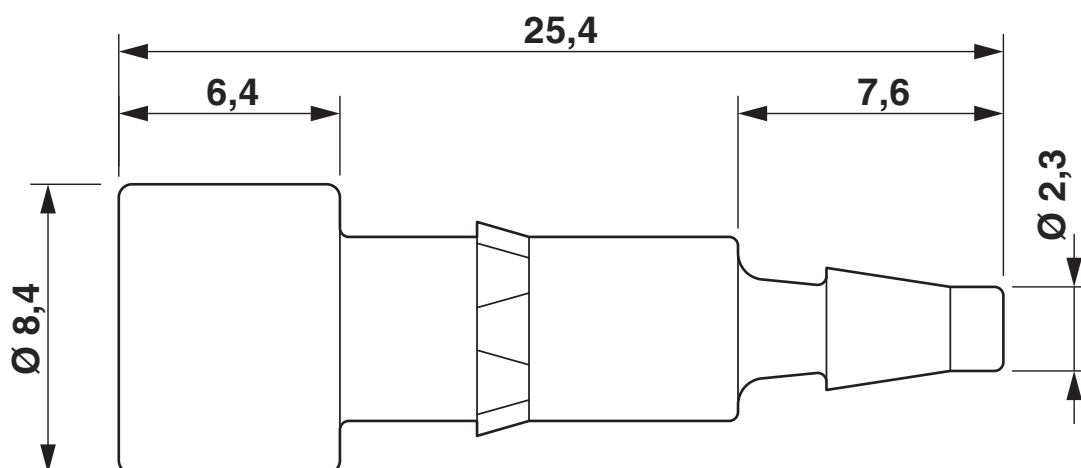

HC-M-PN3-3,00-BU - Pneumatic contact



1663527

<https://www.phoenixcontact.com/us/products/1663527>

Approvals

To download certificates, visit the product detail page: <https://www.phoenixcontact.com/us/products/1663527>



EAC

Approval ID: RU C-DE.AI30.B.01102

HC-M-PN3-3,00-BU - Pneumatic contact



1663527

<https://www.phoenixcontact.com/us/products/1663527>

Classifications

ECLASS

| | |
|-------------|----------|
| ECLASS-13.0 | 27440204 |
| ECLASS-15.0 | 27440204 |

ETIM

| | |
|-----------|----------|
| ETIM 10.0 | EC000796 |
|-----------|----------|

UNSPSC

| | |
|-------------|----------|
| UNSPSC 21.0 | 39121500 |
|-------------|----------|

HC-M-PN3-3,00-BU - Pneumatic contact



1663527

<https://www.phoenixcontact.com/us/products/1663527>

Environmental product compliance

EU RoHS

| | |
|---|--------------------|
| Fulfills EU RoHS substance requirements | Yes, No exemptions |
|---|--------------------|

China RoHS

| | |
|--|--|
| Environment friendly use period (EFUP) | EFUP-E |
| | No hazardous substances above the limits |

EU REACH SVHC

| | |
|-------------------------------------|----------------------------|
| REACH candidate substance (CAS No.) | No substance above 0.1 wt% |
|-------------------------------------|----------------------------|

EF3.1 Climate Change

| | |
|---------|---------------|
| CO2e kg | 0.351 kg CO2e |
|---------|---------------|

Phoenix Contact 2026 © - all rights reserved
<https://www.phoenixcontact.com>

Phoenix Contact USA
586 Fulling Mill Road
Middletown, PA 17057, United States
(+717) 944-1300
info@phoenixcon.com