

HC-B 32-KMQ-82/O1PG29 - Housing



1675023

<https://www.phoenixcontact.com/us/products/1675023>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.

Coupling housing, with double locking latch, height: 82 mm, with gland, 1 x Pg29



Commercial data

| | |
|--------------------------------------|--------------------------------|
| Item number | 1675023 |
| Packing unit | 1 pc |
| Note | Made to order (non-returnable) |
| Sales key | BF55 |
| Product key | AF7AAC |
| GTIN | 4017918149789 |
| Weight per piece (including packing) | 525.6 g |
| Weight per piece (excluding packing) | 525.6 g |
| Customs tariff number | 85389099 |
| Country of origin | DE |

HC-B 32-KMQ-82/O1PG29 - Housing

1675023

<https://www.phoenixcontact.com/us/products/1675023>

Technical data


Notes

| | |
|---------|--------------------------------------|
| General | For contact inserts HC-B32, DD144, M |
|---------|--------------------------------------|

Product properties

| | |
|------------------------------|----------------------------|
| Product type | Housing with locking latch |
| Housing type | Coupling housings |
| Application | Standard |
| Type | B32 |
| No. of cable outlets | 1 |
| Type of the screw connection | 1x Pg29 |
| Cable outlet | straight |
| Pg screw connection | none |

Dimensions
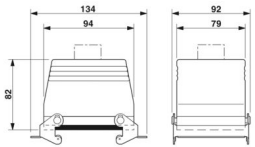
| | |
|---------------------|--|
| Dimensional drawing |  |
| Width | 79 mm |
| Height | 82 mm |
| Length | 94 mm |

Material specifications

| | |
|--------------------------|---------------------|
| Seal material | NBR |
| Housing material | Die-cast aluminum |
| Housing surface material | Powder-coated, gray |
| Locking latch material | Steel, galvanized |

Mechanical properties

Mechanical data

| | |
|------------------------------|---------|
| Type of the screw connection | 1x Pg29 |
| Locking type | Latch |

Mounting

| | |
|---------------|-------------------------------------|
| Assembly note | For half and full screw connections |
|---------------|-------------------------------------|

Environmental and real-life conditions

Ambient conditions

| | |
|---------------------------------|-------------------|
| Degree of protection | IP65 |
| Ambient temperature (operation) | -40 °C ... 125 °C |

HC-B 32-KMQ-82/O1PG29 - Housing




1675023

<https://www.phoenixcontact.com/us/products/1675023>

Drawings

Dimensional drawing

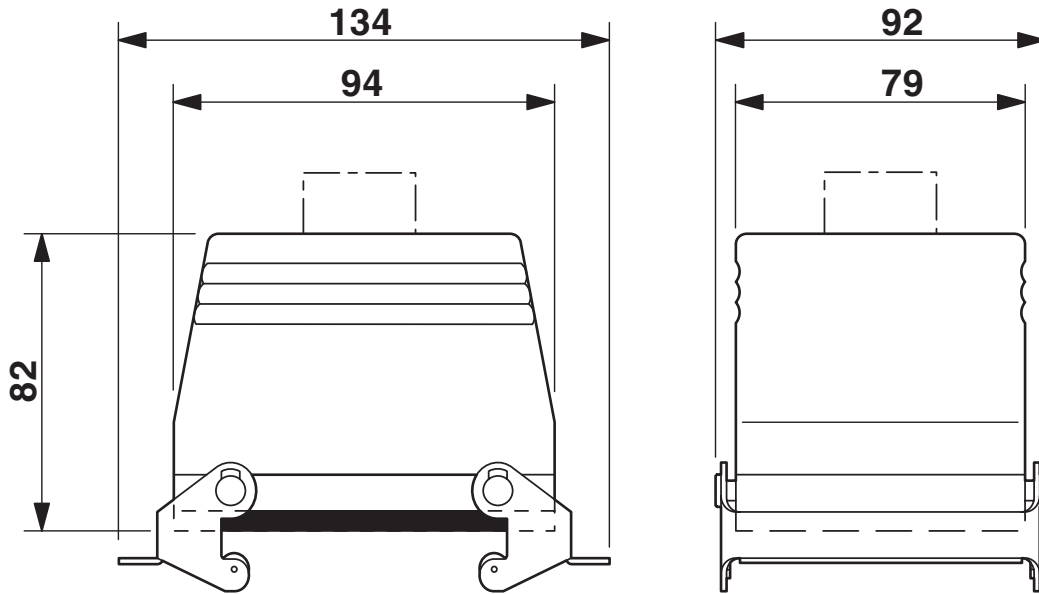

Dimensional drawing

HC-B 32-KMQ-82/O1PG29 - Housing



1675023

<https://www.phoenixcontact.com/us/products/1675023>

Classifications

ECLASS

| | |
|-------------|----------|
| ECLASS-13.0 | 27440202 |
| ECLASS-15.0 | 27440202 |

UNSPSC

| | |
|-------------|----------|
| UNSPSC 21.0 | 31261501 |
|-------------|----------|

HC-B 32-KMQ-82/O1PG29 - Housing



1675023

<https://www.phoenixcontact.com/us/products/1675023>

Environmental product compliance

China RoHS

| | |
|--|--|
| Environment friendly use period (EFUP) | EFUP-E |
| | No hazardous substances above the limits |

EU REACH SVHC

| | |
|-------------------------------------|----------------------------|
| REACH candidate substance (CAS No.) | No substance above 0.1 wt% |
|-------------------------------------|----------------------------|

Phoenix Contact 2026 © - all rights reserved
<https://www.phoenixcontact.com>

Phoenix Contact USA
586 Fulling Mill Road
Middletown, PA 17057, United States
(+717) 944-1300
info@phoenixcon.com