

HC-B 24-SD-MQ/FS - Protective cover



1678347

<https://www.phoenixcontact.com/us/products/1678347>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



Protective cover B24, with double locking latch, protective cover material: PA, height: 21.6 mm, seal: yes, with lanyard

Commercial data

| | |
|--------------------------------------|---------------|
| Item number | 1678347 |
| Packing unit | 1 pc |
| Sales key | BF66 |
| Product key | AF7AZC |
| GTIN | 4017918151881 |
| Weight per piece (including packing) | 81.44 g |
| Weight per piece (excluding packing) | 46.972 g |
| Customs tariff number | 85389099 |
| Country of origin | DE |

HC-B 24-SD-MQ/FS - Protective cover



1678347


<https://www.phoenixcontact.com/us/products/1678347>

Technical data

Product properties

| | |
|------------------------|------------------|
| Product type | Protective cover |
| Housing type | Protective cover |
| Type | B24 |
| Retaining cord present | yes |
| Seal present | yes |

Dimensions
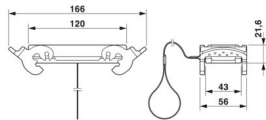
| | |
|---------------------|------------------------------------------------------------------------------------|
| Dimensional drawing |  |
| Width | 43 mm |
| Height | 21.6 mm |
| Length | 120 mm |
| Diameter | 30 mm |

Material specifications

| | |
|----------------------------------------|---------------------------------|
| Material Protective cover | PA |
| Flammability rating according to UL 94 | HB |
| Seal material | NBR |
| Material, protective cover | PA |
| Locking latch material | High-grade steel, handle: PA-GF |

Mechanical properties

Mechanical data

| | |
|--------------|-------|
| Locking type | Latch |
|--------------|-------|

Environmental and real-life conditions

Ambient conditions

| | |
|---------------------------------|-------------------|
| Degree of protection | IP66 |
| Ambient temperature (operation) | -20 °C ... 100 °C |

Mounting

| | |
|---------------|----------------------------------------------------|
| Assembly note | Plastic protective cover for short-term protection |
|---------------|----------------------------------------------------|

HC-B 24-SD-MQ/FS - Protective cover




1678347

<https://www.phoenixcontact.com/us/products/1678347>

Drawings

Dimensional drawing

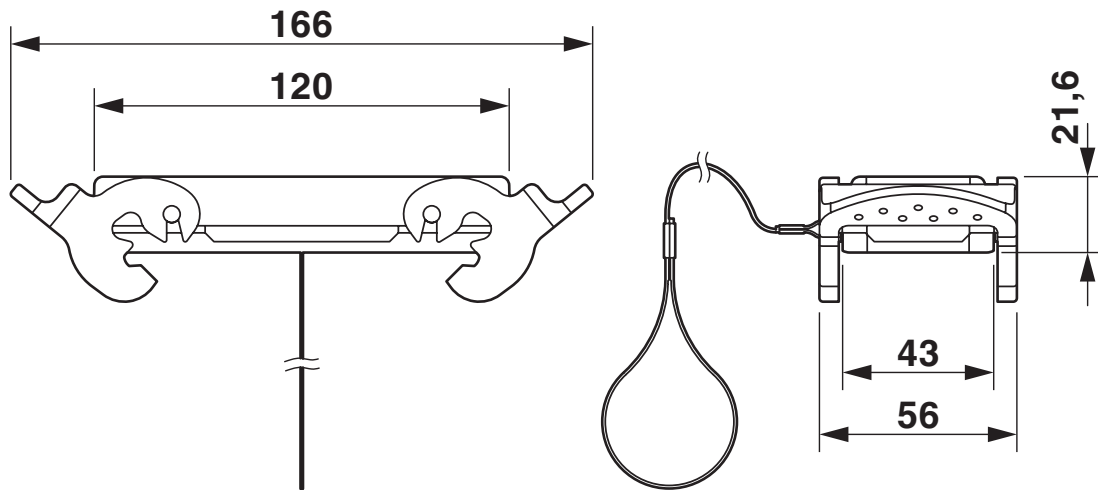

Dimensional drawing

HC-B 24-SD-MQ/FS - Protective cover



1678347

<https://www.phoenixcontact.com/us/products/1678347>

Classifications

ECLASS

| | |
|-------------|----------|
| ECLASS-13.0 | 27440208 |
| ECLASS-15.0 | 27440208 |

UNSPSC

| | |
|-------------|----------|
| UNSPSC 21.0 | 39121400 |
|-------------|----------|

HC-B 24-SD-MQ/FS - Protective cover



1678347

<https://www.phoenixcontact.com/us/products/1678347>

Environmental product compliance

EU RoHS

| | |
|-----------------------------------------|--------------------|
| Fulfills EU RoHS substance requirements | Yes, No exemptions |
|-----------------------------------------|--------------------|

China RoHS

| | |
|----------------------------------------|------------------------------------------|
| Environment friendly use period (EFUP) | EFUP-E |
| | No hazardous substances above the limits |

EU REACH SVHC

| | |
|-------------------------------------|----------------------------|
| REACH candidate substance (CAS No.) | No substance above 0.1 wt% |
|-------------------------------------|----------------------------|

Phoenix Contact 2026 © - all rights reserved
<https://www.phoenixcontact.com>

Phoenix Contact USA
586 Fulling Mill Road
Middletown, PA 17057, United States
(+717) 944-1300
info@phoenixcon.com