

# HC-B-ZG - Strain relief clamp

1685327

<https://www.phoenixcontact.com/us/products/1685327>



Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.

Strain relief clamps contact inserts of series: B-, BB-, D 40, D 64, DD and HV, straight cable exit



## Commercial data

Item number	1685327
Packing unit	10 pc
Minimum order quantity	10 pc
Sales key	BF61
Product key	AF7ABZ
GTIN	4017918197001
Weight per piece (including packing)	14.86 g
Weight per piece (excluding packing)	13.57 g
Customs tariff number	73269098
Country of origin	CN

# HC-B-ZG - Strain relief clamp

1685327

<https://www.phoenixcontact.com/us/products/1685327>




## Technical data

### Product properties

Product type	Mounting material
--------------	-------------------

### Dimensions

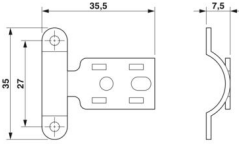Dimensional drawing	
Clamping range of the strain relief clip	9.00 mm ... 19.00 mm

### Material specifications

Material	Steel, galvanized
----------	-------------------

### Cable/line

External cable diameter	9 mm ... 19 mm
-------------------------	----------------

### Mounting

Assembly note	<p>For use in combination with contact inserts without housing. Fastening on the opposite side to the PE connection. M4 mounting screw.</p> <p>Suitable for HC-DD... / HC-B... / HC-BB... / HC-BBB... / HC-D40.. / HC-D64...</p>
---------------	--


# HC-B-ZG - Strain relief clamp

1685327

<https://www.phoenixcontact.com/us/products/1685327>



## Drawings

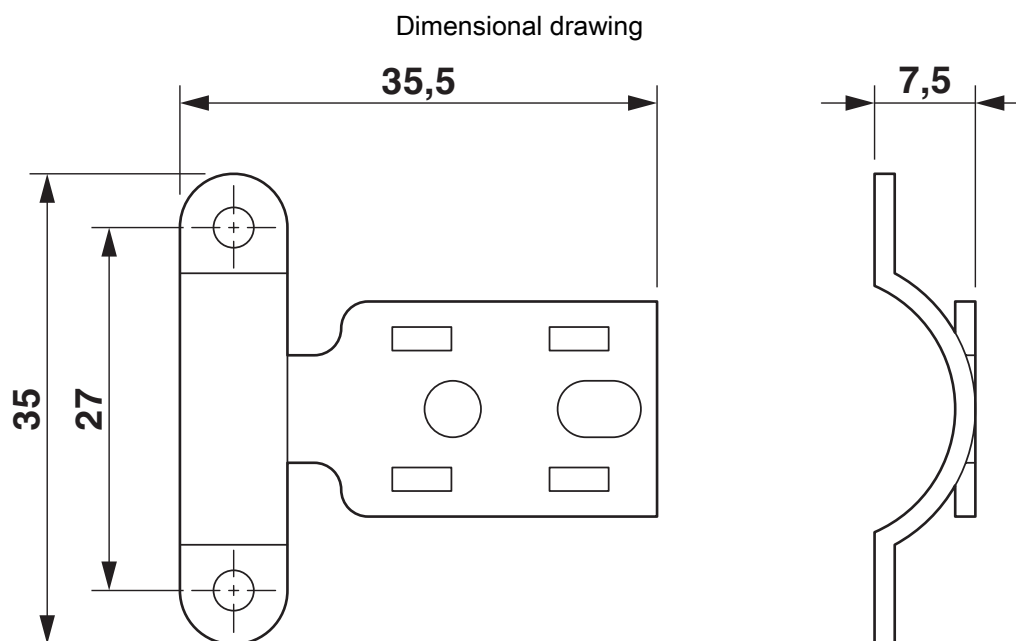

Dimensional drawing

# HC-B-ZG - Strain relief clamp

1685327

<https://www.phoenixcontact.com/us/products/1685327>



## Classifications

### ECLASS

ECLASS-13.0	27440192
ECLASS-15.0	27440192

### ETIM

ETIM 10.0	EC002943
-----------	----------

### UNSPSC

UNSPSC 21.0	39121400
-------------	----------

# HC-B-ZG - Strain relief clamp



1685327

<https://www.phoenixcontact.com/us/products/1685327>

## Environmental product compliance

### EU RoHS

Fulfills EU RoHS substance requirements	Yes, No exemptions
---	--------------------

### China RoHS

Environment friendly use period (EFUP)	EFUP-E
	No hazardous substances above the limits

### EU REACH SVHC

REACH candidate substance (CAS No.)	No substance above 0.1 wt%
-------------------------------------	----------------------------

### EF3.1 Climate Change

CO2e kg	1.991 kg CO2e
---------	---------------

Phoenix Contact 2026 © - all rights reserved  
<https://www.phoenixcontact.com>

Phoenix Contact USA  
586 Fulling Mill Road  
Middletown, PA 17057, United States  
(+717) 944-1300  
[info@phoenixcon.com](mailto:info@phoenixcon.com)