

HC-B-ZG - Strain relief clamp

1685327

<https://www.phoenixcontact.com/us/products/1685327>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.

Strain relief clamps contact inserts of series: B-, BB-, D 40, D 64, DD and HV, straight cable exit



Commercial data

| | |
|--------------------------------------|---------------|
| Item number | 1685327 |
| Packing unit | 10 pc |
| Minimum order quantity | 10 pc |
| Sales key | BF61 |
| Product key | AF7ABZ |
| GTIN | 4017918197001 |
| Weight per piece (including packing) | 14.86 g |
| Weight per piece (excluding packing) | 13.57 g |
| Customs tariff number | 73269098 |
| Country of origin | CN |

HC-B-ZG - Strain relief clamp

1685327

<https://www.phoenixcontact.com/us/products/1685327>




Technical data

Product properties

| | |
|--------------|-------------------|
| Product type | Mounting material |
|--------------|-------------------|

Dimensions
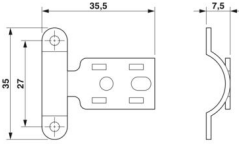
| | |
|--|--|
| Dimensional drawing |  |
| Clamping range of the strain relief clip | 9.00 mm ... 19.00 mm |

Material specifications

| | |
|----------|-------------------|
| Material | Steel, galvanized |
|----------|-------------------|

Cable/line

| | |
|-------------------------|----------------|
| External cable diameter | 9 mm ... 19 mm |
|-------------------------|----------------|

Mounting

| | |
|---------------|--|
| Assembly note | <p>For use in combination with contact inserts without housing. Fastening on the opposite side to the PE connection. M4 mounting screw.</p> <p>Suitable for HC-DD... / HC-B... / HC-BB... / HC-BBB... / HC-D40.. / HC-D64...</p> |
|---------------|--|


HC-B-ZG - Strain relief clamp

1685327

<https://www.phoenixcontact.com/us/products/1685327>



Drawings

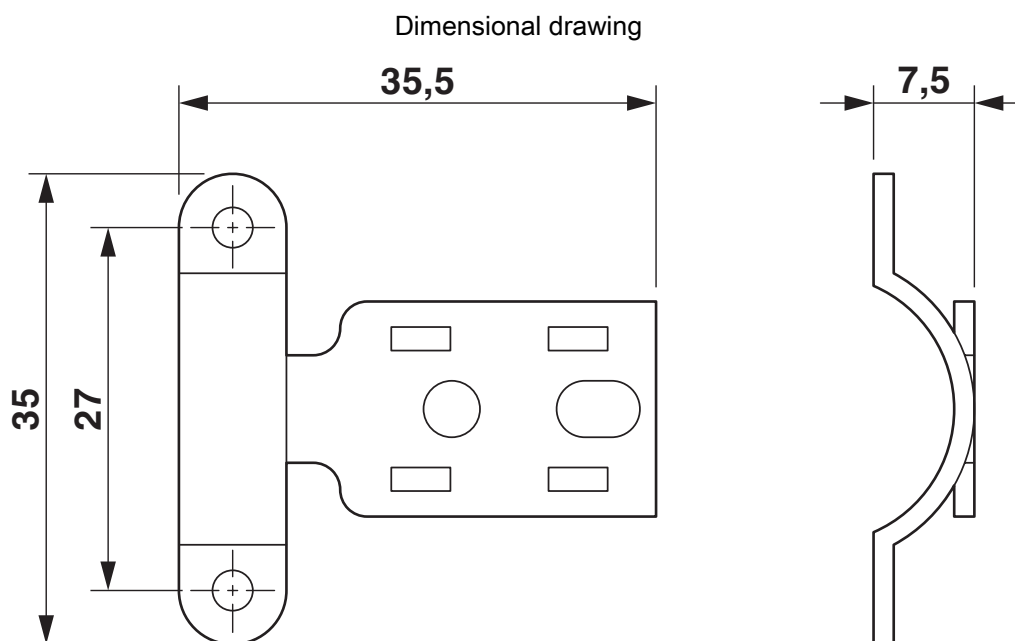

Dimensional drawing

HC-B-ZG - Strain relief clamp

1685327

<https://www.phoenixcontact.com/us/products/1685327>



Classifications

ECLASS

| | |
|-------------|----------|
| ECLASS-13.0 | 27440192 |
| ECLASS-15.0 | 27440192 |

ETIM

| | |
|-----------|----------|
| ETIM 10.0 | EC002943 |
|-----------|----------|

UNSPSC

| | |
|-------------|----------|
| UNSPSC 21.0 | 39121400 |
|-------------|----------|

HC-B-ZG - Strain relief clamp



1685327

<https://www.phoenixcontact.com/us/products/1685327>

Environmental product compliance

EU RoHS

| | |
|---|--------------------|
| Fulfills EU RoHS substance requirements | Yes, No exemptions |
|---|--------------------|

China RoHS

| | |
|--|--|
| Environment friendly use period (EFUP) | EFUP-E |
| | No hazardous substances above the limits |

EU REACH SVHC

| | |
|-------------------------------------|----------------------------|
| REACH candidate substance (CAS No.) | No substance above 0.1 wt% |
|-------------------------------------|----------------------------|

EF3.1 Climate Change

| | |
|---------|---------------|
| CO2e kg | 1.991 kg CO2e |
|---------|---------------|

Phoenix Contact 2026 © - all rights reserved
<https://www.phoenixcontact.com>

Phoenix Contact USA
586 Fulling Mill Road
Middletown, PA 17057, United States
(+717) 944-1300
info@phoenixcon.com