

# VS-ST-CD-1,0/14,8/0,2 - D-SUB crimp contact



1688971

<https://www.phoenixcontact.com/us/products/1688971>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



Crimp contact, for D-SUB contact inserts with standard contact density, pin, connection cross section AWG 28 ... 24, turned, gold-plated

## Commercial data

Item number	1688971
Packing unit	1 pc
Note	Made to order (non-returnable)
Sales key	NULL
Product key	ABNCAA
GTIN	4017918822897
Weight per piece (including packing)	0.267 g
Weight per piece (excluding packing)	0.25 g
Customs tariff number	85366990
Country of origin	DE

# VS-ST-CD-1,0/14,8/0,2 - D-SUB crimp contact



1688971

<https://www.phoenixcontact.com/us/products/1688971>

## Technical data

### Product properties

Product type	Crimp contact
Series	HC-M-DSUB
	HC-M-25
	HC-M-08-GBIT
Contact material type	turned

 
### Connection data

Connection method	Crimp connection
Contact connection type	Pin
Connection technology	Crimp connection
Conductor cross-section	0.08 mm <sup>2</sup> ... 0.2 mm <sup>2</sup>
Connection cross section AWG	28 ... 24

### Material specifications

Contact material	Copper alloy
Contact surface material	Hard gold-plated over nickel

### Dimensions

Dimensional drawing	
Length	14.8 mm

### Mechanical characteristics

Contact diameter	1 mm
------------------	------

### Electrical properties

Rated voltage (III/3)	125 V
Rated surge voltage	1 kV
Rated current	5 A
Insulation resistance	≥ 5 GΩ

### Mechanical properties

#### Mechanical data

Insertion/withdrawal cycles	≥ 50
-----------------------------	------

### Environmental and real-life conditions

#### Ambient conditions

# VS-ST-CD-1,0/14,8/0,2 - D-SUB crimp contact



1688971

<https://www.phoenixcontact.com/us/products/1688971>

Ambient temperature (operation)

-55 °C ... 125 °C


# VS-ST-CD-1,0/14,8/0,2 - D-SUB crimp contact

1688971

<https://www.phoenixcontact.com/us/products/1688971>

## Drawings

Dimensional drawing

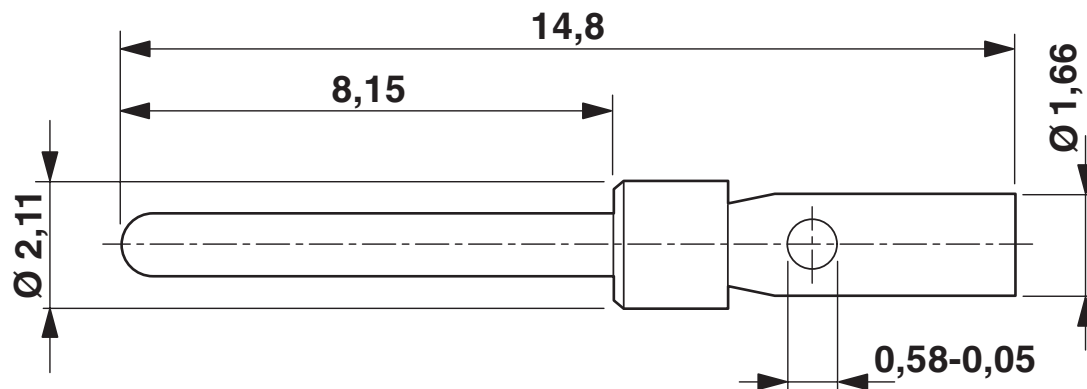

D-SUB crimp contact pin

# VS-ST-CD-1,0/14,8/0,2 - D-SUB crimp contact



1688971

<https://www.phoenixcontact.com/us/products/1688971>

## Classifications

### ECLASS

ECLASS-13.0	27440302
-------------	----------

# VS-ST-CD-1,0/14,8/0,2 - D-SUB crimp contact



1688971

<https://www.phoenixcontact.com/us/products/1688971>

## Environmental product compliance

### China RoHS

Environment friendly use period (EFUP)	EFUP-50
	An article-related China RoHS declaration table can be found in the download area for the respective article under "Manufacturer declaration". For all articles with EFUP-E, no China RoHS declaration table issued and required.

### EU REACH SVHC

REACH candidate substance (CAS No.)	No substance above 0.1 wt%
-------------------------------------	----------------------------

Phoenix Contact 2026 © - all rights reserved  
<https://www.phoenixcontact.com>

Phoenix Contact USA  
586 Fulling Mill Road  
Middletown, PA 17057, United States  
(+717) 944-1300  
[info@phoenixcon.com](mailto:info@phoenixcon.com)