

# HC-B 24-TMS-SD-IP50 - Protective cover



1690765

<https://www.phoenixcontact.com/us/products/1690765>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



Protective cover B24, with clip locking, protective cover material: PA, height: 31.2 mm, seal: no, with lanyard

## Commercial data

Item number	1690765
Packing unit	10 pc
Minimum order quantity	1 pc
Sales key	BF66
Product key	AF7AZC
GTIN	4017918890650
Weight per piece (including packing)	42.89 g
Weight per piece (excluding packing)	38.93 g
Customs tariff number	85389099
Country of origin	DE

# HC-B 24-TMS-SD-IP50 - Protective cover

1690765

 
<https://www.phoenixcontact.com/us/products/1690765>

## Technical data

### Product properties

Product type	Protective cover
Housing type	Protective cover
Type	B24
Retaining cord present	yes
Seal present	no

### Dimensions

Dimensional drawing	
Width	55 mm
Height	31.2 mm
Length	150 mm
Diameter Retaining cord eyelet	3.5 mm

### Material specifications

Material Protective cover	PA
Flammability rating according to UL 94	V0
Material, protective cover	PA

### Environmental and real-life conditions

#### Ambient conditions

Degree of protection	IP50
Ambient temperature (operation)	-20 °C ... 100 °C

# HC-B 24-TMS-SD-IP50 - Protective cover




1690765

<https://www.phoenixcontact.com/us/products/1690765>

## Drawings

Dimensional drawing

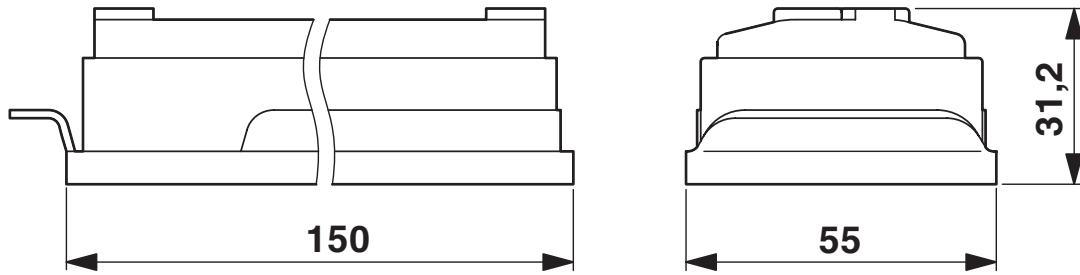

Dimensional drawing

# HC-B 24-TMS-SD-IP50 - Protective cover



1690765

<https://www.phoenixcontact.com/us/products/1690765>

## Approvals

To download certificates, visit the product detail page: <https://www.phoenixcontact.com/us/products/1690765>



**EAC**

Approval ID: RU C-DE.AI30.B.01102

# HC-B 24-TMS-SD-IP50 - Protective cover



1690765

<https://www.phoenixcontact.com/us/products/1690765>

## Classifications

### ECLASS

ECLASS-13.0	27440208
ECLASS-15.0	27440208

### ETIM

ETIM 10.0	EC002314
-----------	----------

### UNSPSC

UNSPSC 21.0	39121400
-------------	----------

# HC-B 24-TMS-SD-IP50 - Protective cover



1690765

<https://www.phoenixcontact.com/us/products/1690765>

## Environmental product compliance

### EU RoHS

Fulfills EU RoHS substance requirements	Yes, No exemptions
---	--------------------

### China RoHS

Environment friendly use period (EFUP)	EFUP-E
	No hazardous substances above the limits

### EU REACH SVHC

REACH candidate substance (CAS No.)	No substance above 0.1 wt%
-------------------------------------	----------------------------

### EF3.1 Climate Change

CO2e kg	0.278 kg CO2e
---------	---------------

Phoenix Contact 2026 © - all rights reserved  
<https://www.phoenixcontact.com>

Phoenix Contact USA  
586 Fulling Mill Road  
Middletown, PA 17057, United States  
(+717) 944-1300  
[info@phoenixcon.com](mailto:info@phoenixcon.com)