

# HC-B 24-TMS-SD-IP50-OLOGO - Protective cover



1690846

<https://www.phoenixcontact.com/us/products/1690846>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



Protective cover B24, Clip locking, protective cover material: PA, height: 31.2 mm, seal: no, with lanyard

Photo shows the product with the PC logo

## Commercial data

Item number	1690846
Packing unit	10 pc
Minimum order quantity	1 pc
Product key	AF7AZC
GTIN	4017918890735
Weight per piece (including packing)	46.2 g
Weight per piece (excluding packing)	39.6 g
Country of origin	DE

# HC-B 24-TMS-SD-IP50-OLOGO - Protective cover



1690846

 
<https://www.phoenixcontact.com/us/products/1690846>

## Technical data

### Product properties

Product type	Protective cover
Housing type	Protective cover
Type	B24
Seal present	no

### Dimensions

Dimensional drawing	
Width	55 mm
Height	31.2 mm
Length	150 mm

### Material specifications

Flammability rating according to UL 94	V0
Material, protective cover	PA

### Environmental and real-life conditions

#### Ambient conditions

Degree of protection	IP50
Ambient temperature (operation)	-20 °C ... 100 °C

# HC-B 24-TMS-SD-IP50-OLOGO - Protective cover




1690846

<https://www.phoenixcontact.com/us/products/1690846>

## Drawings

Dimensional drawing

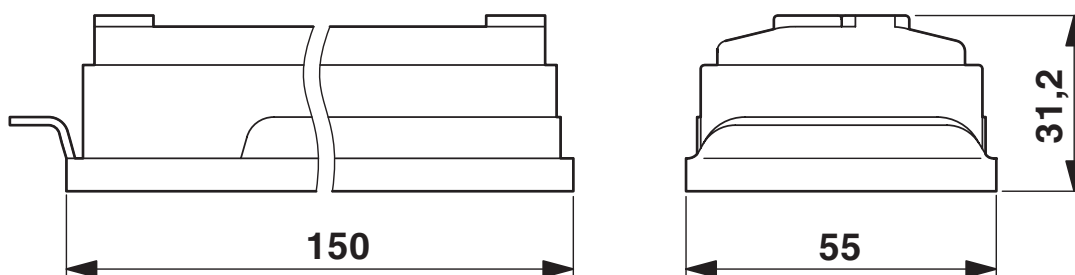

Dimensional drawing

# HC-B 24-TMS-SD-IP50-OLOGO - Protective cover



1690846

<https://www.phoenixcontact.com/us/products/1690846>

## Classifications

### ECLASS

ECLASS-13.0	27440208
ECLASS-15.0	27440208

# HC-B 24-TMS-SD-IP50-OLOGO - Protective cover



1690846

<https://www.phoenixcontact.com/us/products/1690846>

## Environmental product compliance

### EU RoHS

Fulfills EU RoHS substance requirements	Yes, No exemptions
---	--------------------

### EU REACH SVHC

REACH candidate substance (CAS No.)	No substance above 0.1 wt%
-------------------------------------	----------------------------

Phoenix Contact 2026 © - all rights reserved

<https://www.phoenixcontact.com>

Phoenix Contact USA  
586 Fulling Mill Road  
Middletown, PA 17057, United States  
(+717) 944-1300  
[info@phoenixcon.com](mailto:info@phoenixcon.com)