

HC-B 24-AFQD - Housing

1771956

<https://www.phoenixcontact.com/us/products/1771956>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



HEAVYCON B24 panel mounting base, for double locking latch, height: 29 mm, with plastic cover, with flat gasket

Commercial data

| | |
|--------------------------------------|--------------------------------|
| Item number | 1771956 |
| Packing unit | 1 pc |
| Note | Made to order (non-returnable) |
| Sales key | BF55 |
| Product key | AF7AAC |
| GTIN | 4017918036638 |
| Weight per piece (including packing) | 157.82 g |
| Weight per piece (excluding packing) | 157.26 g |
| Customs tariff number | 85389099 |
| Country of origin | DE |

HC-B 24-AFQD - Housing

1771956

 
<https://www.phoenixcontact.com/us/products/1771956>

Technical data

Product properties

| | |
|---------------------|----------------------------|
| Product type | Housing with locking latch |
| Housing type | Panel mounting base |
| Application | Standard |
| Type | B24 |
| Protective cover | yes |
| Shielded | no |
| Pg screw connection | none |

Dimensions

| | |
|---------------------|---|
| Dimensional drawing |  |
| Width | 43 mm |
| Height | 29 mm |
| Length | 140 mm |

Installation dimensions

| | |
|-------------------------------|--------|
| Width of the assembly cutout | 35 mm |
| Length of the assembly cutout | 113 mm |

Material specifications

| | |
|----------------------------|---------------------|
| Seal material | NBR CR |
| Housing material | Die-cast aluminum |
| Housing surface material | Powder-coated, gray |
| Material, protective cover | PA |

Mechanical properties

Mechanical data

| | |
|--------------|-----|
| Locking type | Pin |
|--------------|-----|

Connection data

| | |
|-------------------|----------------------------------|
| Tightening torque | 1.5 Nm ... 2 Nm (Mounting screw) |
|-------------------|----------------------------------|

Environmental and real-life conditions

Ambient conditions

| | |
|---------------------------------|------------------------|
| Degree of protection | IP65 (When plugged in) |
| Ambient temperature (operation) | -40 °C ... 125 °C |

HC-B 24-AFQD - Housing




1771956


<https://www.phoenixcontact.com/us/products/1771956>

Drawings

Dimensional drawing

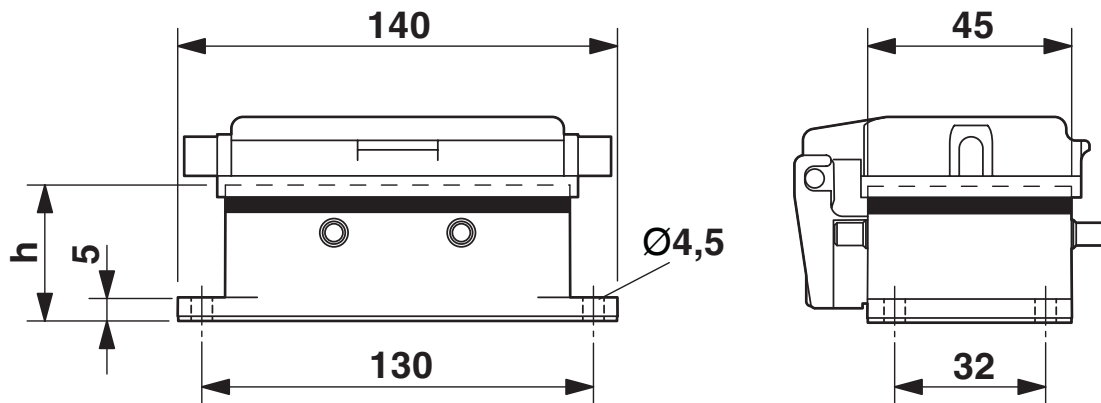

Dimensional drawing

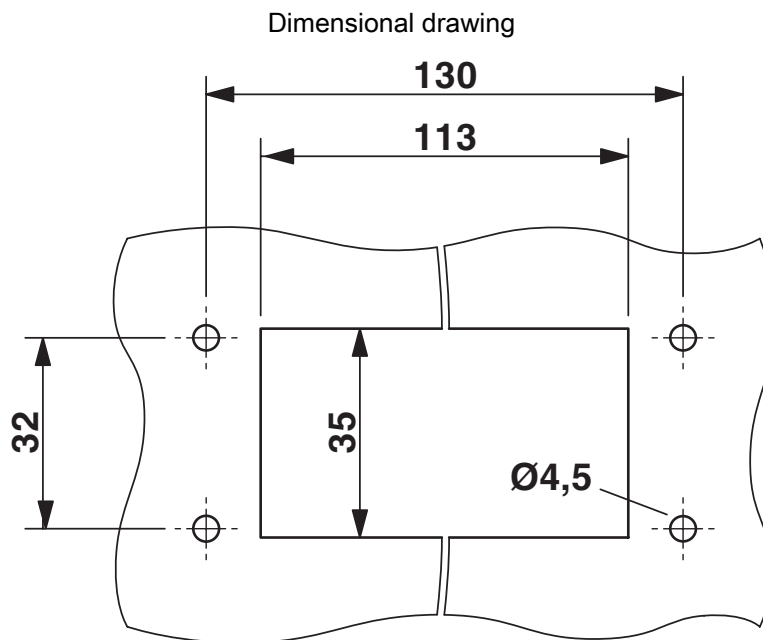

Mounting cutout

HC-B 24-AFQD - Housing

1771956

<https://www.phoenixcontact.com/us/products/1771956>



Classifications

ECLASS

| | |
|-------------|----------|
| ECLASS-13.0 | 27440202 |
| ECLASS-15.0 | 27440202 |

UNSPSC

| | |
|-------------|----------|
| UNSPSC 21.0 | 31261501 |
|-------------|----------|

HC-B 24-AFQD - Housing



1771956

<https://www.phoenixcontact.com/us/products/1771956>

Environmental product compliance

EU RoHS

| | |
|---|--------------------|
| Fulfills EU RoHS substance requirements | Yes, No exemptions |
|---|--------------------|

China RoHS

| | |
|--|--|
| Environment friendly use period (EFUP) | EFUP-E |
| | No hazardous substances above the limits |

EU REACH SVHC

| | |
|-------------------------------------|----------------------------|
| REACH candidate substance (CAS No.) | No substance above 0.1 wt% |
|-------------------------------------|----------------------------|

Phoenix Contact 2026 © - all rights reserved
<https://www.phoenixcontact.com>

Phoenix Contact USA
586 Fulling Mill Road
Middletown, PA 17057, United States
(+717) 944-1300
info@phoenixcon.com