

HC-DS-PG21-Z - Pressure screw



1772641

<https://www.phoenixcontact.com/us/products/1772641>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.

Pressure screws, with strain relief clamps, nickel-plated brass, clamping area 12 mm ... 20 mm, type Pg21



Commercial data

Item number	1772641
Packing unit	1 pc
Note	Made to order (non-returnable)
Sales key	BF68
Product key	AF7DFX
GTIN	4017918037307
Weight per piece (including packing)	60.59 g
Weight per piece (excluding packing)	60.59 g
Customs tariff number	74199990
Country of origin	DE

HC-DS-PG21-Z - Pressure screw



1772641

 
<https://www.phoenixcontact.com/us/products/1772641>

Technical data

Product properties

Product type	Half screw connection
Pg screw connection	Pg21

Dimensions

Dimensional drawing	
Wrench size, union nut	34 mm
Clamping range of the strain relief clip	12.00 mm ... 20.00 mm

Material specifications

Material Pressure screw	Brass, nickel-plated
-------------------------	----------------------


HC-DS-PG21-Z - Pressure screw

1772641

<https://www.phoenixcontact.com/us/products/1772641>



Drawings

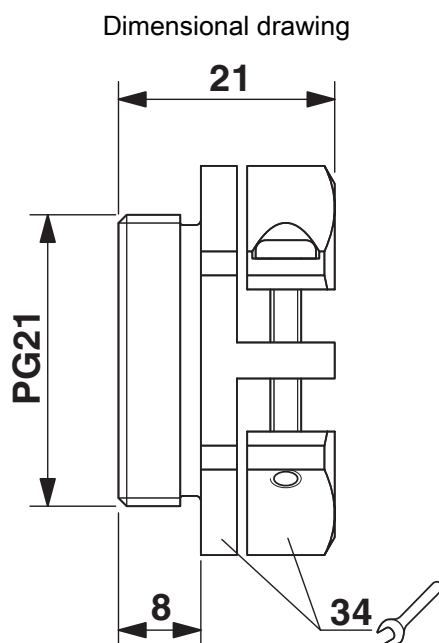

Dimensional drawing

HC-DS-PG21-Z - Pressure screw



1772641

<https://www.phoenixcontact.com/us/products/1772641>

Classifications

UNSPSC

UNSPSC 21.0

39121311

Phoenix Contact 2026 © - all rights reserved

<https://www.phoenixcontact.com>

Phoenix Contact USA

586 Fulling Mill Road

Middletown, PA 17057, United States

(+717) 944-1300

info@phoenixcon.com