

HC-DS-PG36-Z - Pressure screw



1772667

<https://www.phoenixcontact.com/us/products/1772667>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.

Pressure screws, with strain relief clamps, nickel-plated brass, clamping area 25.5 mm ... 34 mm, type Pg36



Commercial data

| | |
|--------------------------------------|--------------------------------|
| Item number | 1772667 |
| Packing unit | 1 pc |
| Note | Made to order (non-returnable) |
| Sales key | BF68 |
| Product key | AF7DFX |
| GTIN | 4017918037321 |
| Weight per piece (including packing) | 166.72 g |
| Weight per piece (excluding packing) | 166.72 g |
| Customs tariff number | 74153300 |
| Country of origin | DE |

HC-DS-PG36-Z - Pressure screw



1772667

 
<https://www.phoenixcontact.com/us/products/1772667>

Technical data

Product properties

| | |
|---------------------|-----------------------|
| Product type | Half screw connection |
| Pg screw connection | Pg36 |

Dimensions

| | |
|--|--|
| Dimensional drawing |  |
| Wrench size, union nut | 52 mm |
| Clamping range of the strain relief clip | 26.00 mm ... 34.00 mm |

Material specifications

| | |
|-------------------------|----------------------|
| Material Pressure screw | Brass, nickel-plated |
|-------------------------|----------------------|

HC-DS-PG36-Z - Pressure screw


1772667

<https://www.phoenixcontact.com/us/products/1772667>



Drawings

Dimensional drawing

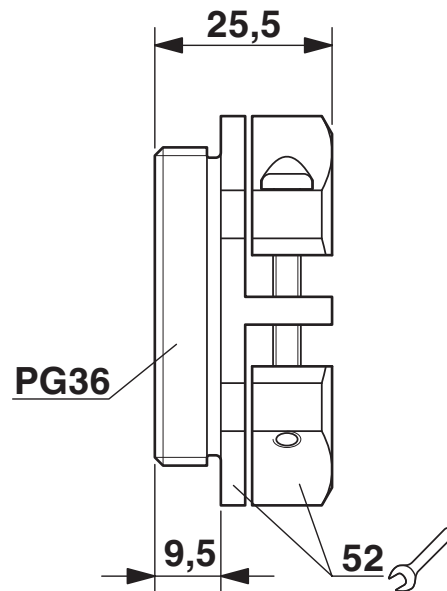

Dimensional drawing

HC-DS-PG36-Z - Pressure screw



1772667

<https://www.phoenixcontact.com/us/products/1772667>

Classifications

UNSPSC

UNSPSC 21.0

31161514

Phoenix Contact 2026 © - all rights reserved

<https://www.phoenixcontact.com>

Phoenix Contact USA
586 Fulling Mill Road
Middletown, PA 17057, United States
(+717) 944-1300
info@phoenixcon.com