

HC-B 10-ADP/2 DSUB 25 - Adapter plate




1775509

<https://www.phoenixcontact.com/us/products/1775509>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.

D-SUB adapter plate, for two D-SUB connectors, no. of positions 25, housing series HC-B 10...

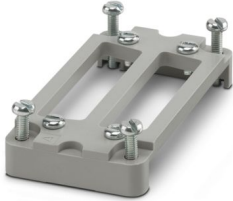

Commercial data

| | |
|--------------------------------------|---------------|
| Item number | 1775509 |
| Packing unit | 2 pc |
| Minimum order quantity | 2 pc |
| Sales key | BF66 |
| Product key | AF7AZD |
| GTIN | 4017918038106 |
| Weight per piece (including packing) | 13.6 g |
| Weight per piece (excluding packing) | 11.52 g |
| Customs tariff number | 39269097 |
| Country of origin | DE |

HC-B 10-ADP/2 DSUB 25 - Adapter plate

1775509


<https://www.phoenixcontact.com/us/products/1775509>

Technical data

Product properties

| | |
|---------------------|---------------|
| Product type | Adapter plate |
| Type | B10 |
| Number of positions | 25 |
| Seal present | no |

Dimensions
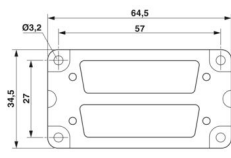
| | |
|---------------------|--|
| Dimensional drawing |  |
| Width | 34.5 mm |
| Height | 10 mm |
| Length | 64.5 mm |

Material specifications

| | |
|--|----|
| Material | PA |
| Flammability rating according to UL 94 | HB |

Environmental and real-life conditions

Ambient conditions

| | |
|---------------------------------|-------------------|
| Ambient temperature (operation) | -20 °C ... 100 °C |
|---------------------------------|-------------------|

Mounting

| | |
|---------------|--|
| Assembly note | Mounting position of the adapter plate in the sleeve housing: T is visible after mounting in the housing. Mounting position of the adapter plate in the panel mounting base/socket housing/coupling housing: A is visible after mounting in the housing. Mounting position of the D-SUB (after mounting in the housing): in front of the mounting panel (front mounting) |
|---------------|--|


HC-B 10-ADP/2 DSUB 25 - Adapter plate



1775509

<https://www.phoenixcontact.com/us/products/1775509>

Drawings

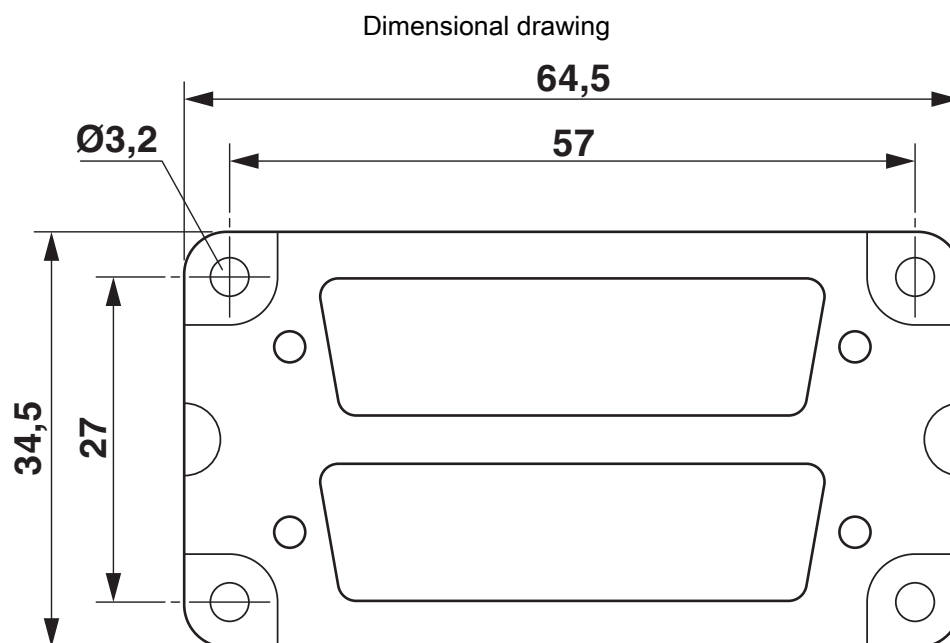

See assembly instruction

HC-B 10-ADP/2 DSUB 25 - Adapter plate



1775509

<https://www.phoenixcontact.com/us/products/1775509>

Approvals

To download certificates, visit the product detail page: <https://www.phoenixcontact.com/us/products/1775509>



EAC

Approval ID: RU C-DE.AI30.B.01102

HC-B 10-ADP/2 DSUB 25 - Adapter plate



1775509

<https://www.phoenixcontact.com/us/products/1775509>

Classifications

ECLASS

| | |
|-------------|----------|
| ECLASS-13.0 | 27440201 |
| ECLASS-15.0 | 27440201 |

ETIM

| | |
|-----------|----------|
| ETIM 10.0 | EC002309 |
|-----------|----------|

UNSPSC

| | |
|-------------|----------|
| UNSPSC 21.0 | 31261500 |
|-------------|----------|

HC-B 10-ADP/2 DSUB 25 - Adapter plate



1775509

<https://www.phoenixcontact.com/us/products/1775509>

Environmental product compliance

EU RoHS

| | |
|---|--------------|
| Fulfills EU RoHS substance requirements | Yes |
| Exemption | 6(a), 6(a)-I |

China RoHS

| | |
|--|---|
| Environment friendly use period (EFUP) | EFUP-50 |
| | An article-related China RoHS declaration table can be found in the download area for the respective article under "Manufacturer declaration". For all articles with EFUP-E, no China RoHS declaration table issued and required. |

EU REACH SVHC

| | |
|-------------------------------------|--------------------------------------|
| REACH candidate substance (CAS No.) | Lead(CAS: 7439-92-1) |
| SCIP | 1c4c9aaa-9569-4d6c-a682-9338f636edea |

EF3.1 Climate Change

| | |
|---------|---------------|
| CO2e kg | 9.949 kg CO2e |
|---------|---------------|

Phoenix Contact 2026 © - all rights reserved
<https://www.phoenixcontact.com>

Phoenix Contact USA
586 Fulling Mill Road
Middletown, PA 17057, United States
(+717) 944-1300
info@phoenixcon.com