

UM-BASIC/PRO A/U 73 CM - Covering hood



2202036

<https://www.phoenixcontact.com/us/products/2202036>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



Press-drawn section housings, Latching, Cover, width: 73 mm, profile length (configurable): 3 cm ... 100 cm, height: 63.2 mm, Note: max. length of the cover = PCB length - 19 mm

Your advantages

- Different base profiles, each with three PCB levels
- Module covers of different geometries can be positioned in any way
- Compatibility with many standard connection technologies
- Easy device mounting thanks to snap-mount principle (the sides are fixed without the aid of tools)
- High degree of flexibility, thanks to freely positionable covering hoods

Commercial data

| | |
|------------------------|--------------------------------|
| Item number | 2202036 |
| Packing unit | 1 pc |
| Minimum order quantity | 1 pc |
| Note | Made to order (non-returnable) |
| Sales key | AC17 |
| Product key | ACHDAZ |
| GTIN | 4055626005478 |
| Customs tariff number | 39169010 |
| Country of origin | DE |

UM-BASIC/PRO A/U 73 CM - Covering hood

2202036

<https://www.phoenixcontact.com/us/products/2202036>

Technical data


Notes

| | |
|---------------|---|
| Assembly note | Please observe the application note in the download area. |
|---------------|---|

Product properties

| | |
|------------------------------|------------------------------|
| Product type | Component housing cover |
| Housing type | Press-drawn section housings |
| Housing series | UM |
| Ventilation openings present | no |

Dimensions
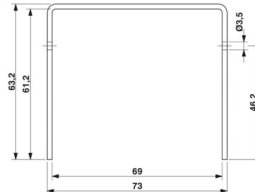
| | |
|---------------------|---|
| Dimensional drawing |  |
| Width | 73 mm |
| Height | 63.2 mm |

Material specifications

| | |
|--|-------------|
| Color (Housing) | transparent |
| Material | PC |
| Flammability rating according to UL 94 | V0 |

Environmental and real-life conditions

Ambient conditions

| | |
|---|--|
| Ambient temperature (operation) | -40 °C ... 105 °C (depending on power dissipation) |
| Ambient temperature (storage/transport) | -40 °C ... 70 °C |
| Ambient temperature (assembly) | -5 °C ... 100 °C |
| Relative humidity (storage/transport) | 95 % |

Mounting

| | |
|-------------------|------------------------|
| Mounting type | Latching |
| Mounting position | vertical or horizontal |

Packaging specifications

| | |
|----------------------|---------------------|
| Type of packaging | packed in cardboard |
| Outer packaging type | Carton |

UM-BASIC/PRO A/U 73 CM - Covering hood




2202036

<https://www.phoenixcontact.com/us/products/2202036>

Drawings

Dimensional drawing

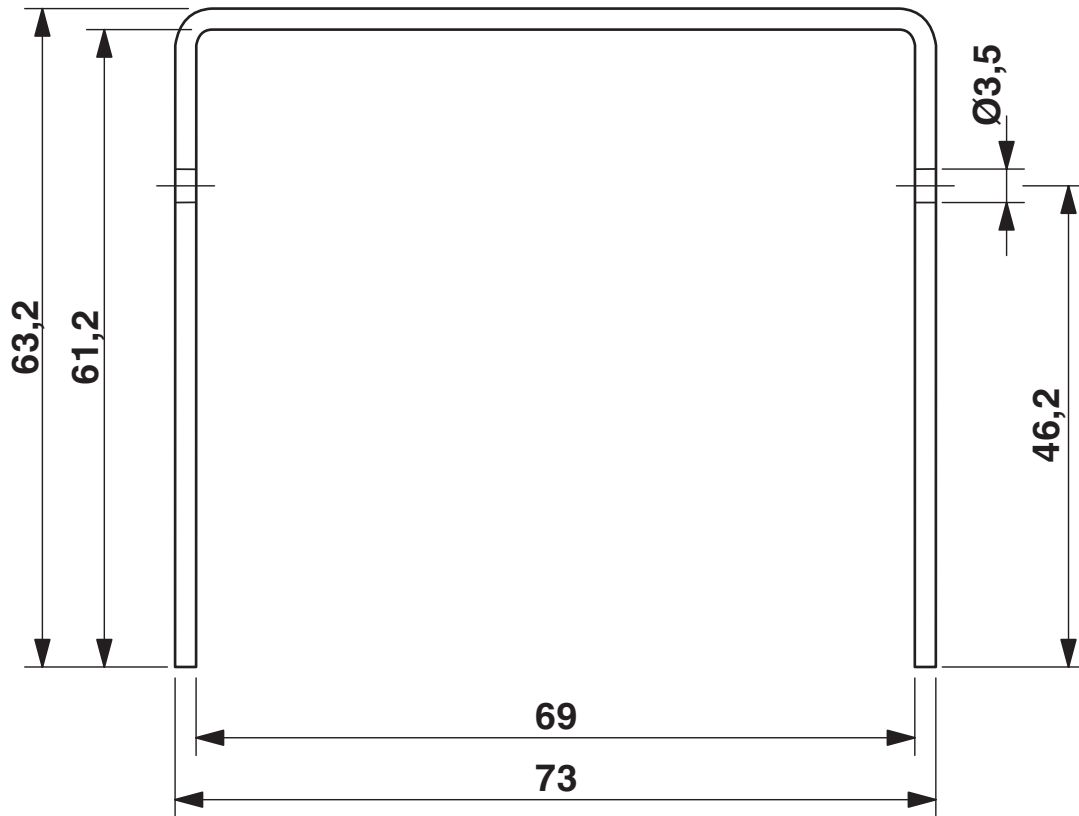

UM-BASIC/PRO A/U 73 CM - Covering hood



2202036

<https://www.phoenixcontact.com/us/products/2202036>

Approvals

To download certificates, visit the product detail page: <https://www.phoenixcontact.com/us/products/2202036>



UL Recognized

Approval ID: E240868

UM-BASIC/PRO A/U 73 CM - Covering hood



2202036

<https://www.phoenixcontact.com/us/products/2202036>

Classifications

ECLASS

ECLASS-15.0

27190603

ETIM

ETIM 10.0

EC002779

UNSPSC

UNSPSC 21.0

31261500

UM-BASIC/PRO A/U 73 CM - Covering hood



2202036

<https://www.phoenixcontact.com/us/products/2202036>

Environmental product compliance

EU RoHS

| | |
|---|--------------------|
| Fulfills EU RoHS substance requirements | Yes, No exemptions |
|---|--------------------|

China RoHS

| | |
|--|--|
| Environment friendly use period (EFUP) | EFUP-E |
| | No hazardous substances above the limits |

EU REACH SVHC

| | |
|-------------------------------------|----------------------------|
| REACH candidate substance (CAS No.) | No substance above 0.1 wt% |
|-------------------------------------|----------------------------|

Phoenix Contact 2026 © - all rights reserved
<https://www.phoenixcontact.com>

Phoenix Contact USA
586 Fulling Mill Road
Middletown, PA 17057, United States
(+717) 944-1300
info@phoenixcon.com