


# UM-BASIC/PRO A/U 73 CM - Covering hood



2202036

<https://www.phoenixcontact.com/us/products/2202036>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.

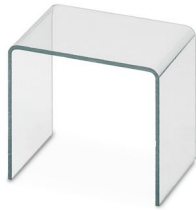

Press-drawn section housings, Latching, Cover, width: 73 mm, profile length (configurable): 3 cm ... 100 cm, height: 63.2 mm, Note: max. length of the cover = PCB length - 19 mm

## Your advantages

- Different base profiles, each with three PCB levels
- Module covers of different geometries can be positioned in any way
- Compatibility with many standard connection technologies
- Easy device mounting thanks to snap-mount principle (the sides are fixed without the aid of tools)
- High degree of flexibility, thanks to freely positionable covering hoods

## Commercial data

Item number	2202036
Packing unit	1 pc
Minimum order quantity	1 pc
Note	Made to order (non-returnable)
Sales key	AC17
Product key	ACHDAZ
GTIN	4055626005478
Customs tariff number	39169010
Country of origin	DE

# UM-BASIC/PRO A/U 73 CM - Covering hood



2202036

<https://www.phoenixcontact.com/us/products/2202036>

## Technical data


### Notes

Assembly note	Please observe the application note in the download area.
---------------	-----------------------------------------------------------

### Product properties

Product type	Component housing cover
Housing type	Press-drawn section housings
Housing series	UM
Ventilation openings present	no

### Dimensions

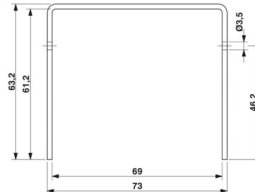Dimensional drawing	
Width	73 mm
Height	63.2 mm

### Material specifications

Color (Housing)	transparent
Material	PC
Flammability rating according to UL 94	V0

### Environmental and real-life conditions

#### Ambient conditions

Ambient temperature (operation)	-40 °C ... 105 °C (depending on power dissipation)
Ambient temperature (storage/transport)	-40 °C ... 70 °C
Ambient temperature (assembly)	-5 °C ... 100 °C
Relative humidity (storage/transport)	95 %

### Mounting

Mounting type	Latching
Mounting position	vertical or horizontal

### Packaging specifications

Type of packaging	packed in cardboard
Outer packaging type	Carton

# UM-BASIC/PRO A/U 73 CM - Covering hood




2202036

<https://www.phoenixcontact.com/us/products/2202036>

## Drawings

Dimensional drawing

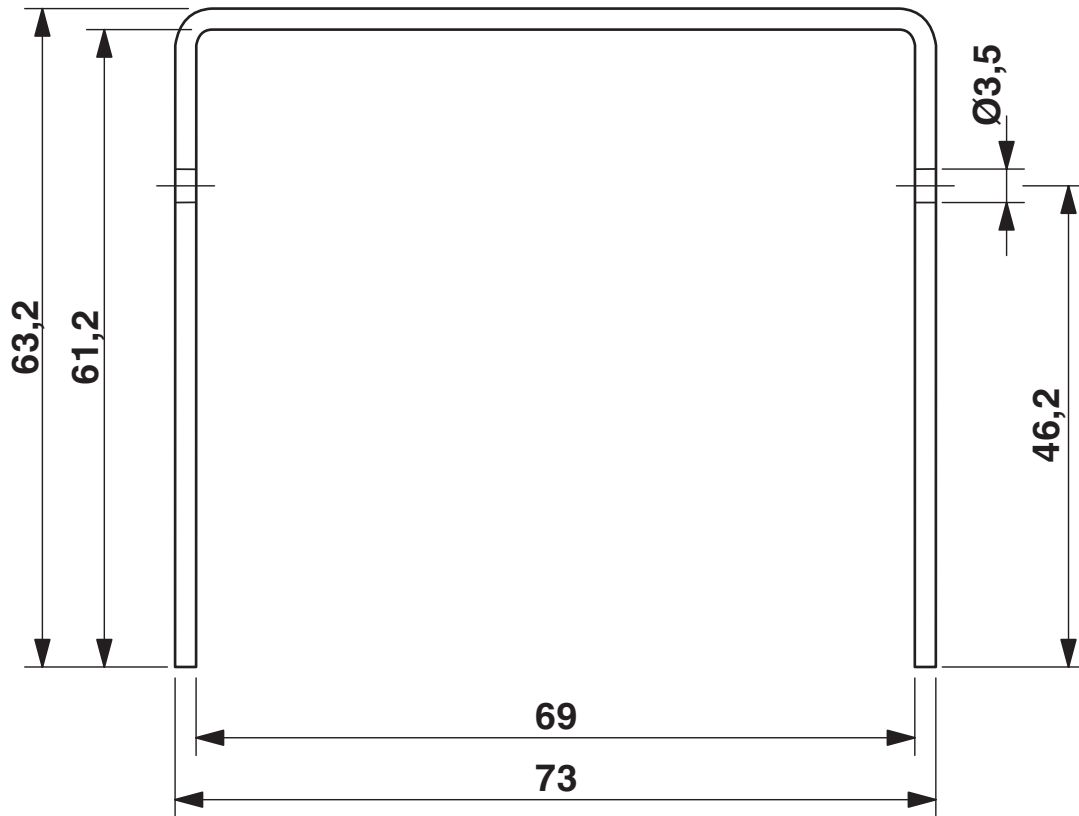

# UM-BASIC/PRO A/U 73 CM - Covering hood



2202036

<https://www.phoenixcontact.com/us/products/2202036>

## Approvals

To download certificates, visit the product detail page: <https://www.phoenixcontact.com/us/products/2202036>



**UL Recognized**

Approval ID: E240868

# UM-BASIC/PRO A/U 73 CM - Covering hood



2202036

<https://www.phoenixcontact.com/us/products/2202036>

## Classifications

### ECLASS

ECLASS-15.0

27190603

### ETIM

ETIM 10.0

EC002779

### UNSPSC

UNSPSC 21.0

31261500

# UM-BASIC/PRO A/U 73 CM - Covering hood



2202036

<https://www.phoenixcontact.com/us/products/2202036>

## Environmental product compliance

### EU RoHS

Fulfills EU RoHS substance requirements	Yes, No exemptions
-----------------------------------------	--------------------

### China RoHS

Environment friendly use period (EFUP)	EFUP-E
	No hazardous substances above the limits

### EU REACH SVHC

REACH candidate substance (CAS No.)	No substance above 0.1 wt%
-------------------------------------	----------------------------

Phoenix Contact 2026 © - all rights reserved  
<https://www.phoenixcontact.com>

Phoenix Contact USA  
586 Fulling Mill Road  
Middletown, PA 17057, United States  
(+717) 944-1300  
[info@phoenixcon.com](mailto:info@phoenixcon.com)