

# ME PLC 40 CTRJ45 GY7035 VPE1 - Front connection module




2202054

<https://www.phoenixcontact.com/us/products/2202054>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.

Connection technology carrier for RJ45 connection, pre-assembled with cover and release lever, incl. fitted cover and 2x RJ45 connector plugs

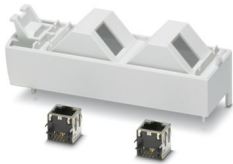

## Your advantages

- Tool-free mounting
- Available in 40 mm overall width
- Flammability rating V0 in accordance with UL 94
- Variety of connection technology
- Can be mounted on the DIN rail
- With DIN-rail-mountable bus connector and power connector system as an option

## Commercial data

Item number	2202054
Packing unit	1 pc
Minimum order quantity	1 pc
Note	Made to order (non-returnable)
Product key	ACHEAB
GTIN	4046356980579
Weight per piece (including packing)	58.8 g
Weight per piece (excluding packing)	58.8 g
Country of origin	DE

# ME PLC 40 CTRJ45 GY7035 VPE1 - Front connection module



2202054

<https://www.phoenixcontact.com/us/products/2202054>

## Technical data


### Notes

Assembly note	Please observe the application note in the download area.
---------------	---

### Product properties

Product type	Upper housing part
Housing type	DIN rail housing
Housing series	ME PLC
Product family	ME PLC 40
Ventilation openings present	no

### Dimensions

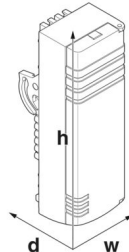Dimensional drawing	
Width	39.7 mm
Height	128 mm
Depth	43.8 mm

### Material specifications

Color (Housing)	light gray (RAL 7035)
Material	PC
Flammability rating according to UL 94	V0
CTI according to IEC 60112	225

### Environmental and real-life conditions

#### Ambient conditions

Max. IP code to attain	IP20
Ambient temperature (operation)	-40 °C ... 105 °C (depending on power dissipation)
Ambient temperature (storage/transport)	-40 °C ... 70 °C
Ambient temperature (assembly)	-5 °C ... 100 °C
Relative humidity (storage/transport)	95 %

### Mounting

Mounting type	Latching with lower housing part
---------------	----------------------------------

### Packaging specifications

# ME PLC 40 CTRJ45 GY7035 VPE1 - Front connection module



2202054

<https://www.phoenixcontact.com/us/products/2202054>

Type of packaging	packed in cardboard
Outer packaging type	Carton


# ME PLC 40 CTRJ45 GY7035 VPE1 - Front connection module

2202054

<https://www.phoenixcontact.com/us/products/2202054>

## Drawings

Dimensional drawing

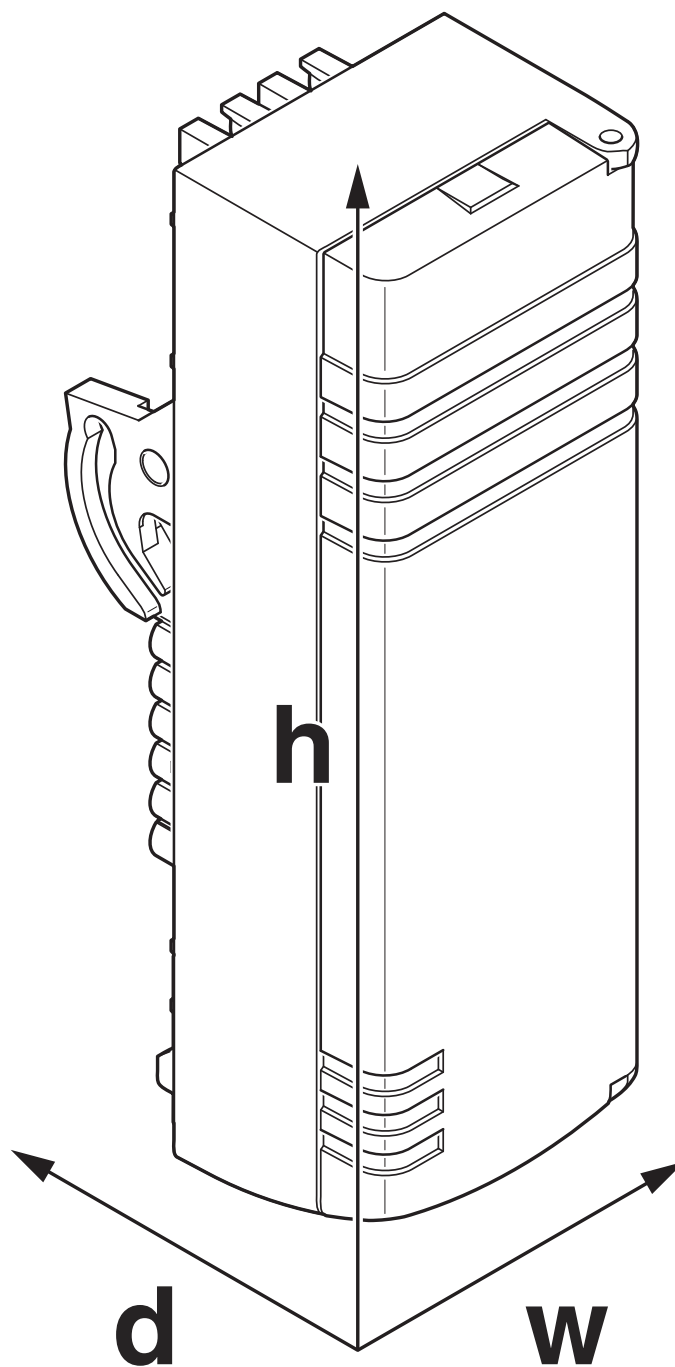

# ME PLC 40 CTRJ45 GY7035 VPE1 - Front connection module



2202054

<https://www.phoenixcontact.com/us/products/2202054>

## Approvals

To download certificates, visit the product detail page: <https://www.phoenixcontact.com/us/products/2202054>



**UL Recognized**  
Approval ID: E240868

# ME PLC 40 CTRJ45 GY7035 VPE1 - Front connection module



2202054

<https://www.phoenixcontact.com/us/products/2202054>

## Classifications

### ECLASS

ECLASS-13.0	27190401
ECLASS-15.0	27190401

### ETIM

ETIM 10.0	EC001031
-----------	----------

### UNSPSC

UNSPSC 21.0	31261500
-------------	----------

# ME PLC 40 CTRJ45 GY7035 VPE1 - Front connection module



2202054

<https://www.phoenixcontact.com/us/products/2202054>

## Environmental product compliance

### EU RoHS

Fulfills EU RoHS substance requirements	Yes, No exemptions
---	--------------------

### China RoHS

Environment friendly use period (EFUP)	EFUP-E
	No hazardous substances above the limits

### EU REACH SVHC

REACH candidate substance (CAS No.)	No substance above 0.1 wt%
-------------------------------------	----------------------------

Phoenix Contact 2026 © - all rights reserved

<https://www.phoenixcontact.com>

Phoenix Contact USA  
586 Fulling Mill Road  
Middletown, PA 17057, United States  
(+717) 944-1300  
[info@phoenixcon.com](mailto:info@phoenixcon.com)