

ME MAX 22,5 PLATE GY - Insertion plate



2202163

<https://www.phoenixcontact.com/us/products/2202163>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.

DIN rail housing, Insertion plate, width: 19.2 mm, height: 73.6 mm, depth: 1 mm, color: gray (similar RAL 7042)



Your advantages

- Easy, tool-free mounting
- Plastic in accordance with UL94 V0: for more rigorous flammability requirements

Commercial data

| | |
|--------------------------------------|--------------------------------|
| Item number | 2202163 |
| Packing unit | 10 pc |
| Minimum order quantity | 10 pc |
| Note | Made to order (non-returnable) |
| Sales key | AC22 |
| Product key | ACHABZ |
| GTIN | 4055626004327 |
| Weight per piece (including packing) | 1.692 g |
| Weight per piece (excluding packing) | 0.78 g |
| Customs tariff number | 85389099 |
| Country of origin | DE |

ME MAX 22,5 PLATE GY - Insertion plate

2202163

<https://www.phoenixcontact.com/us/products/2202163>

Technical data


Notes

| | |
|----------------|---|
| Assembly note | Please observe the application note in the download area. |
| Recommendation | Material of contact pads for bus connector, galvanic gold (hard gold) |

Product properties

| | |
|------------------------------|------------------|
| Product type | Cover |
| Housing type | DIN rail housing |
| Housing type | Modular housings |
| Housing series | ME-MAX |
| Product family | ME MAX 22,5.. |
| Ventilation openings present | no |

Dimensions
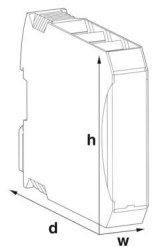
| | |
|---------------------|---|
| Dimensional drawing |  |
| Width | 19.2 mm |
| Height | 73.6 mm |
| Depth | 1 mm |

Material specifications

| | |
|--|-----------------|
| Color (Insertion plate) | gray (RAL 7042) |
| Material | PA |
| Flammability rating according to UL 94 | V0 |
| CTI according to IEC 60112 | 600 |

PCB data

| | |
|-----------------------|---|
| Number of PCB holders | 1 |
|-----------------------|---|

Mounting

| | |
|---------------|------|
| Mounting type | Slot |
|---------------|------|

ME MAX 22,5 PLATE GY - Insertion plate


2202163

<https://www.phoenixcontact.com/us/products/2202163>



Drawings

Dimensional drawing

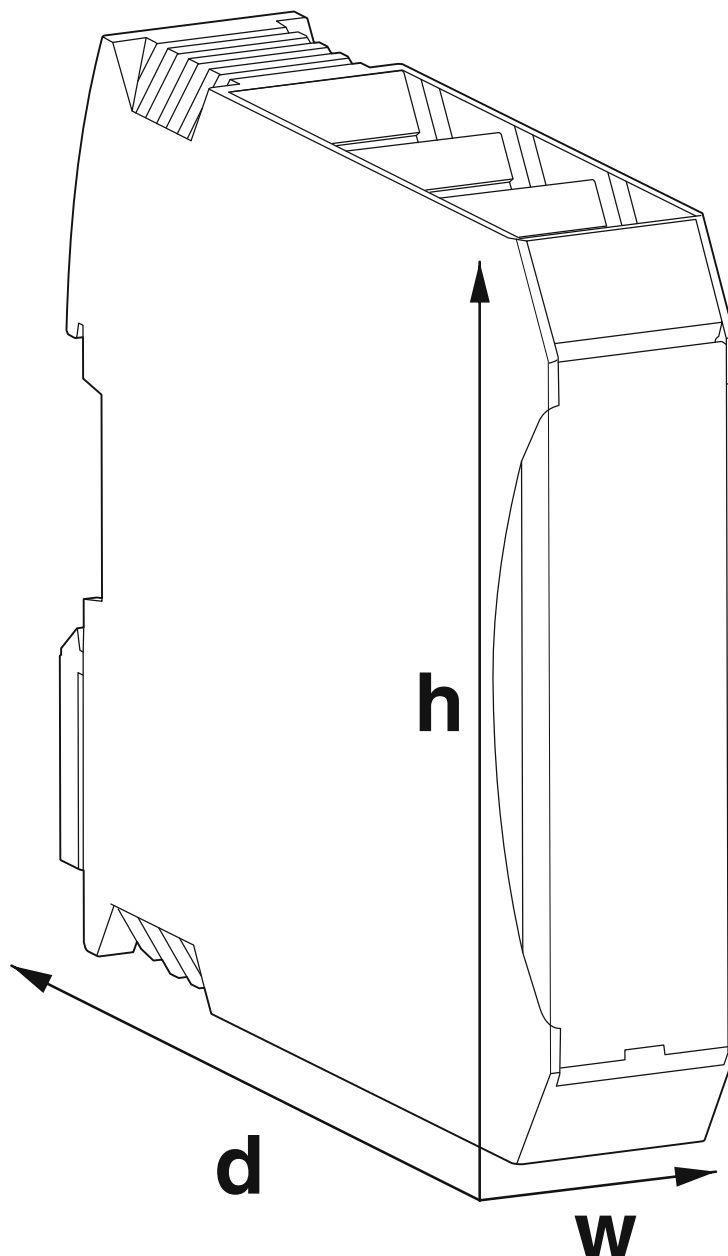

ME MAX 22,5 PLATE GY - Insertion plate



2202163

<https://www.phoenixcontact.com/us/products/2202163>

Approvals

To download certificates, visit the product detail page: <https://www.phoenixcontact.com/us/products/2202163>



UL Recognized

Approval ID: E240868

ME MAX 22,5 PLATE GY - Insertion plate



2202163

<https://www.phoenixcontact.com/us/products/2202163>

Classifications

ECLASS

| | |
|-------------|----------|
| ECLASS-13.0 | 27190605 |
| ECLASS-15.0 | 27190605 |

ETIM

| | |
|-----------|----------|
| ETIM 10.0 | EC002779 |
|-----------|----------|

UNSPSC

| | |
|-------------|----------|
| UNSPSC 21.0 | 31261500 |
|-------------|----------|

ME MAX 22,5 PLATE GY - Insertion plate



2202163

<https://www.phoenixcontact.com/us/products/2202163>

Environmental product compliance

EU RoHS

| | |
|---|--------------------|
| Fulfills EU RoHS substance requirements | Yes, No exemptions |
|---|--------------------|

China RoHS

| | |
|--|--|
| Environment friendly use period (EFUP) | EFUP-E |
| | No hazardous substances above the limits |

EU REACH SVHC

| | |
|-------------------------------------|----------------------------|
| REACH candidate substance (CAS No.) | No substance above 0.1 wt% |
|-------------------------------------|----------------------------|

EF3.1 Climate Change

| | |
|---------|---------------|
| CO2e kg | 0.035 kg CO2e |
|---------|---------------|

Phoenix Contact 2026 © - all rights reserved
<https://www.phoenixcontact.com>

Phoenix Contact USA
586 Fulling Mill Road
Middletown, PA 17057, United States
(+717) 944-1300
info@phoenixcon.com