

UM-BASIC 108/32 DEV-PCB - PCB




2202551

<https://www.phoenixcontact.com/us/products/2202551>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.

Perfboard for the UM-BASIC 108 DEV-KIT; for SMKDS-terminal blocks; ideal for manual soldering

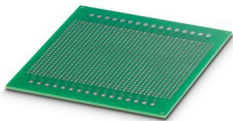

Your advantages

- Hole matrix PCB for self-assembly
- Assembly area: approx. 10,700 mm²
- Hole matrix dimension: 2.54 mm

Commercial data

| | |
|--------------------------------------|---------------|
| Item number | 2202551 |
| Packing unit | 1 pc |
| Minimum order quantity | 1 pc |
| Sales key | AC13 |
| Product key | ACHDAE |
| GTIN | 4055626142661 |
| Weight per piece (including packing) | 38.8 g |
| Weight per piece (excluding packing) | 37.8 g |
| Customs tariff number | 85340011 |
| Country of origin | DE |

2202551

<https://www.phoenixcontact.com/us/products/2202551>

Technical data

Notes

| | |
|---------------|---|
| Assembly note | Please observe the application note in the download area. |
|---------------|---|

Product properties

| | |
|----------------|------------------------------|
| Product type | PCB |
| Housing type | Press-drawn section housings |
| Housing type | Extruded profile housings |
| Housing series | UM-BASIC |
| Product family | UM-BASIC |

Material specifications

| | |
|------------------|------------------|
| Color (Housing) | green (RAL 6021) |
| Housing material | FR 4-21 |

Environmental and real-life conditions

Ambient conditions

| | |
|---------------------------------|--------|
| Ambient temperature (operation) | 110 °C |
|---------------------------------|--------|

2202551

<https://www.phoenixcontact.com/us/products/2202551>

Classifications

ECLASS

| | |
|-------------|----------|
| ECLASS-13.0 | 27260692 |
| ECLASS-15.0 | 27260692 |

ETIM

| | |
|-----------|----------|
| ETIM 10.0 | EC001031 |
|-----------|----------|

UNSPSC

| | |
|-------------|----------|
| UNSPSC 21.0 | 31261500 |
|-------------|----------|

2202551

<https://www.phoenixcontact.com/us/products/2202551>

Environmental product compliance

EU RoHS

| | |
|---|--------------------|
| Fulfills EU RoHS substance requirements | Yes, No exemptions |
|---|--------------------|

China RoHS

| | |
|--|--|
| Environment friendly use period (EFUP) | EFUP-E |
| | No hazardous substances above the limits |

EU REACH SVHC

| | |
|-------------------------------------|----------------------------|
| REACH candidate substance (CAS No.) | No substance above 0.1 wt% |
|-------------------------------------|----------------------------|

Phoenix Contact 2026 © - all rights reserved
<https://www.phoenixcontact.com>

Phoenix Contact USA
586 Fulling Mill Road
Middletown, PA 17057, United States
(+717) 944-1300
info@phoenixcon.com