

FLKM 40/LA/S100 - Passive module



2287562

<https://www.phoenixcontact.com/us/products/2287562>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



VARIOFACE output module, 16 channels for Siemens SIMATIC® S5-95U and S5-100U, with additional LED status display

Commercial data

Item number	2287562
Packing unit	1 pc
Note	Made to order (non-returnable)
Sales key	C421
Product key	DK218S
GTIN	4017918056421
Weight per piece (including packing)	131.6 g
Weight per piece (excluding packing)	87.47 g
Customs tariff number	85369010
Country of origin	DE

FLKM 40/LA/S100 - Passive module



2287562

<https://www.phoenixcontact.com/us/products/2287562>

Technical data

Product properties

Product type	Interface module
Product family	VARIOFACE
Number of positions	40

Insulation characteristics

Overvoltage category	II
Pollution degree	2

Electrical properties

Nominal voltage U_N	24 V DC (up to 30 V DC)
Max. current carrying capacity per branch	0.5 A (0.1 A output n+1)

Connection data

Field level

Stripping length	8 mm
Screw thread	M3
Conductor cross-section rigid	0.2 mm ² ... 4 mm ²
Conductor cross-section flexible	0.2 mm ² ... 2.5 mm ²
Conductor cross-section AWG	24 ... 12

Controller level

Connection method	IDC/FLK pin strip
Number of connections	2
Number of positions	14
Pitch	2.54 mm

Signaling

Status display	LED
Status display present	yes

Dimensions

Item dimensions

Width	78.5 mm
Height	90 mm
Depth	68 mm

Material specifications

Color	green (RAL 6021)
Housing insulation material	Polyamide 6.6 green

Environmental and real-life conditions

FLKM 40/LA/S100 - Passive module



2287562

<https://www.phoenixcontact.com/us/products/2287562>

Ambient conditions

Ambient temperature (operation)	-20 °C ... 50 °C
---------------------------------	------------------

Standards and regulations

Standards/regulations	IEC 60664
	IEC 60664A
	DIN VDE 0110
	DIN VDE 0160 (in parts)

Mounting

Mounting position	any
-------------------	-----

Notes

Notes on operation	For proper use, the specifications of the installation directive (see Downloads) must be observed. For applications or use with third-party products, the specifications, and the safety and warning instructions of the respective third-party manufacturer must also be met.
--------------------	--

FLKM 40/LA/S100 - Passive module




2287562

<https://www.phoenixcontact.com/us/products/2287562>

Drawings

Circuit diagram

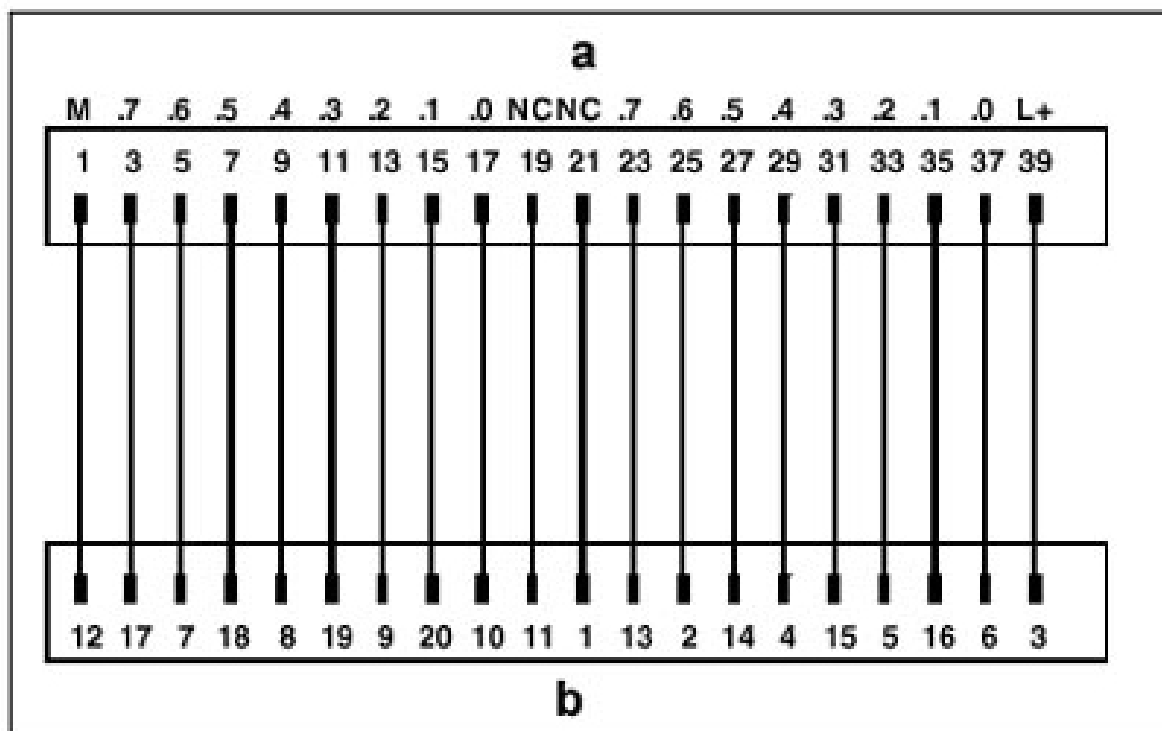

a = pin strip FLK40
b = pin strip FLK20


FLKM 40/LA/S100 - Passive module



2287562

<https://www.phoenixcontact.com/us/products/2287562>

Circuit diagram

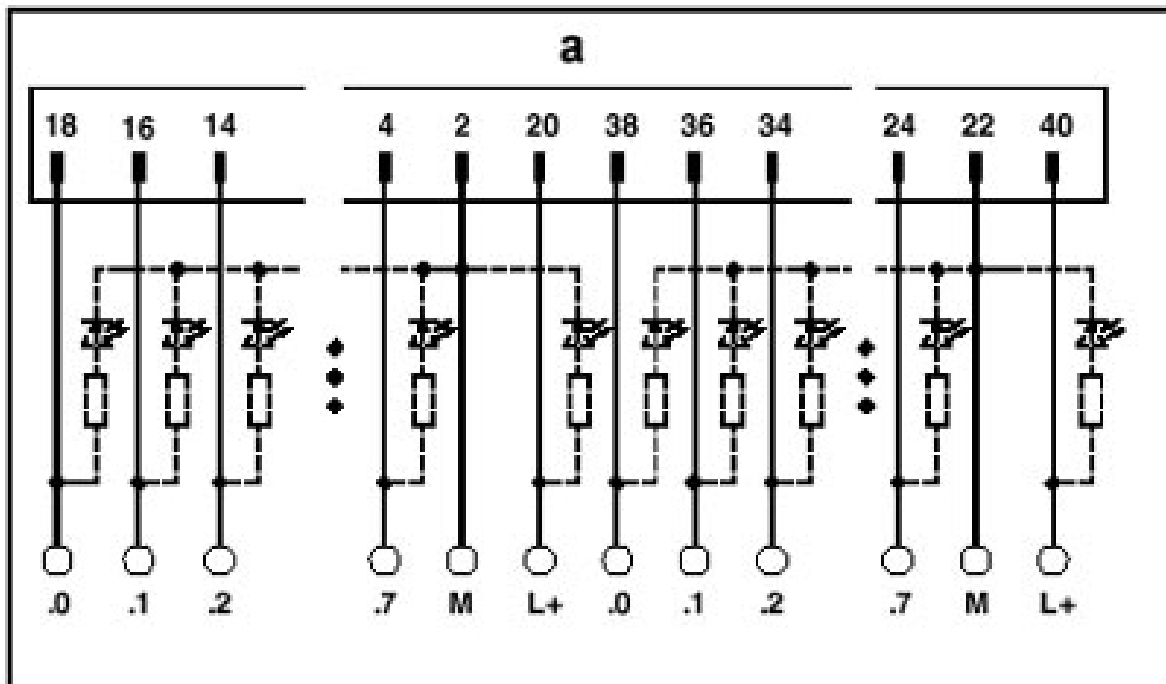

a = pin strip FLK 40

FLKM 40/LA/S100 - Passive module



2287562

<https://www.phoenixcontact.com/us/products/2287562>

Environmental product compliance

EU REACH SVHC

REACH candidate substance (CAS No.)	No substance above 0.1 wt%
-------------------------------------	----------------------------

Phoenix Contact 2026 © - all rights reserved

<https://www.phoenixcontact.com>

Phoenix Contact USA
586 Fulling Mill Road
Middletown, PA 17057, United States
(+717) 944-1300
info@phoenixcon.com