

# FLKMS-D25 SUB/S/REG/S100 - Passive module



2287601

<https://www.phoenixcontact.com/us/products/2287601>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



VARIOFACE interface module, for Siemens SIMATIC® S5-100U, control module 6ES5 262-8MA12 (to adapt a 25-position D-SUB pin strip to screw terminal blocks)

## Commercial data

Item number	2287601
Packing unit	1 pc
Note	Made to order (non-returnable)
Sales key	C421
Product key	DK218S
GTIN	4017918056469
Weight per piece (including packing)	168.2 g
Weight per piece (excluding packing)	168.2 g
Customs tariff number	85369010
Country of origin	DE

# FLKMS-D25 SUB/S/REG/S100 - Passive module



2287601

<https://www.phoenixcontact.com/us/products/2287601>

## Technical data

### Product properties

Product type	Interface module
Product family	VARIOFACE

### Insulation characteristics

Overvoltage category	II
Pollution degree	2

### Electrical properties

Nominal voltage $U_N$	60 V DC
Max. current carrying capacity per branch	1 A

### Connection data

#### Field level

Connection in acc. with standard	IEC / EN
Connection method	Screw connection
Stripping length	8 mm
Screw thread	M3
Conductor cross-section rigid	0.2 mm <sup>2</sup> ... 4 mm <sup>2</sup>
Conductor cross-section flexible	0.2 mm <sup>2</sup> ... 2.5 mm <sup>2</sup>
Conductor cross-section AWG	24 ... 12

#### Controller level

Connection method	D-SUB pin strip
-------------------	-----------------

### Signaling

Status display	no
Status display present	no

### Dimensions

#### Item dimensions

Width	56.5 mm
Height	90 mm
Depth	81 mm

### Material specifications

Color	green (RAL 6021)
Housing insulation material	Polyamide 6.6 green

### Environmental and real-life conditions

#### Ambient conditions

# FLKMS-D25 SUB/S/REG/S100 - Passive module



2287601

<https://www.phoenixcontact.com/us/products/2287601>

Ambient temperature (operation)	-20 °C ... 50 °C
---------------------------------	------------------

## Standards and regulations

Standards/regulations	IEC 60664
	IEC 60664A
	DIN VDE 0110
	DIN VDE 0160 (in parts)

## Mounting

Mounting position	any
-------------------	-----

## Notes

Notes on operation	For proper use, the specifications of the installation directive (see Downloads) must be observed. For applications or use with third-party products, the specifications, and the safety and warning instructions of the respective third-party manufacturer must also be met.
--------------------	--

# FLKMS-D25 SUB/S/REG/S100 - Passive module




2287601

<https://www.phoenixcontact.com/us/products/2287601>

## Drawings

### Circuit diagram

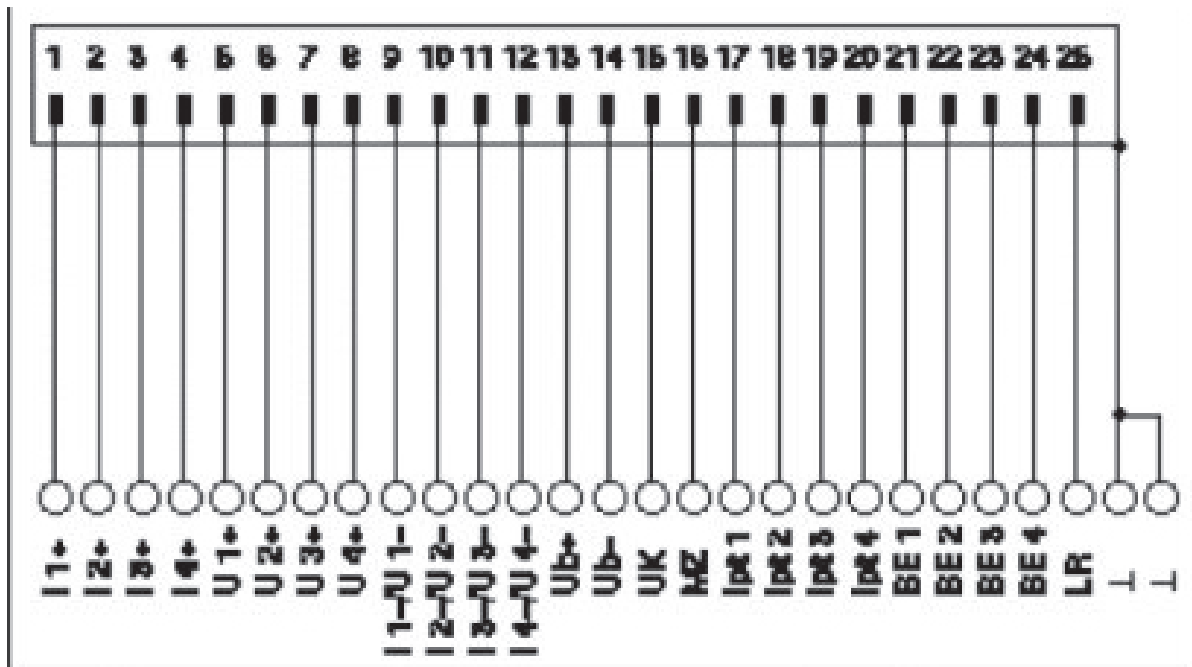

# FLKMS-D25 SUB/S/REG/S100 - Passive module



2287601

<https://www.phoenixcontact.com/us/products/2287601>

## Environmental product compliance

EU REACH SVHC

REACH candidate substance (CAS No.)	No substance above 0.1 wt%
-------------------------------------	----------------------------

Phoenix Contact 2026 © - all rights reserved

<https://www.phoenixcontact.com>

Phoenix Contact USA  
586 Fulling Mill Road  
Middletown, PA 17057, United States  
(+717) 944-1300  
[info@phoenixcon.com](mailto:info@phoenixcon.com)