

UM 45-PROFIL 235CM - Profile



2735441

<https://www.phoenixcontact.com/us/products/2735441>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.

Press-drawn section housings, Basic profile, open, profile width (internal): 41.85 mm, profile width (external): 44.8 mm, length: 2350 mm, height: 44.8 mm, depth: 18.95 mm



Your advantages

- Easy installation
- Flexible size and shape
- Inexpensive as a result of reducing the number of separate housing parts

Commercial data

| | |
|--------------------------------------|---------------|
| Item number | 2735441 |
| Packing unit | 1 pc |
| Minimum order quantity | 1 pc |
| Sales key | AC13 |
| Product key | ACHDBA |
| GTIN | 4017918589554 |
| Weight per piece (including packing) | 485.71 g |
| Weight per piece (excluding packing) | 485.71 g |
| Customs tariff number | 39162000 |
| Country of origin | DE |

UM 45-PROFIL 235CM - Profile

2735441


<https://www.phoenixcontact.com/us/products/2735441>

Technical data

Product properties

| | |
|------------------------------|------------------------------|
| Product type | Component housing lower part |
| Housing type | Press-drawn section housings |
| Housing type | Extruded profile housings |
| Housing series | UM |
| Product family | UM45 |
| Ventilation openings present | no |

Dimensions
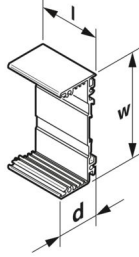
| | |
|---------------------|--|
| Dimensional drawing |  |
| Height | 44.8 mm |
| Depth | 18.95 mm |
| Length | 235 cm |

External dimensions

| | |
|--------------------------|---------|
| Profile width (external) | 44.8 mm |
|--------------------------|---------|

Internal dimensions

| | |
|--------------------------|----------|
| Profile width (internal) | 41.85 mm |
|--------------------------|----------|

Material specifications

| | |
|------------------|-----|
| Material Profile | PVC |
|------------------|-----|

Environmental and real-life conditions

Ambient conditions

| | |
|---------------------------------|------------------|
| Ambient temperature (operation) | -15 °C ... 50 °C |
|---------------------------------|------------------|

PCB data

| | |
|-----------------------|---|
| Number of PCB holders | 2 |
|-----------------------|---|

UM 45-PROFIL 235CM - Profile


2735441

<https://www.phoenixcontact.com/us/products/2735441>



Drawings

Dimensional drawing

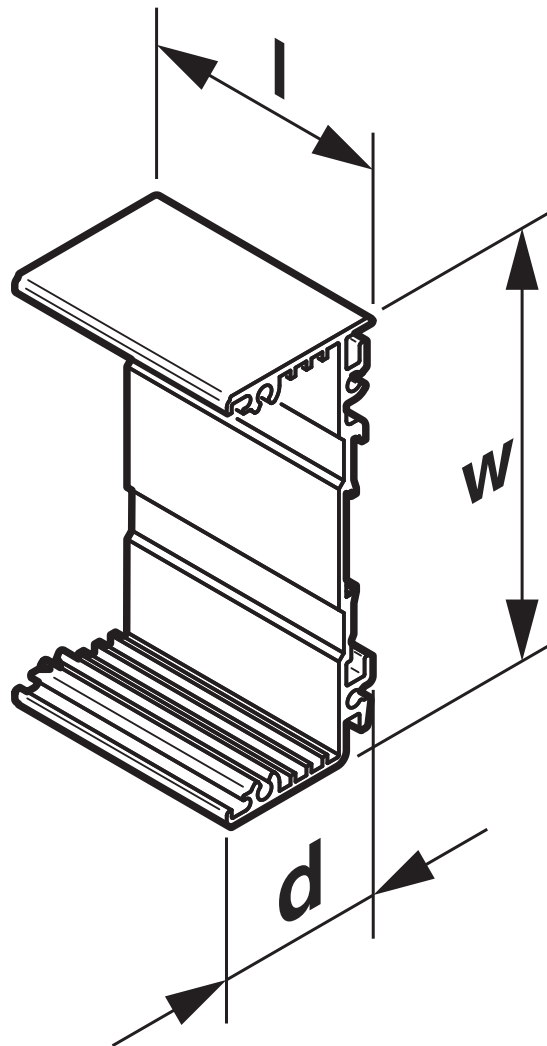

UM 45-PROFIL 235CM - Profile



2735441

<https://www.phoenixcontact.com/us/products/2735441>

Classifications

ECLASS

| | |
|-------------|----------|
| ECLASS-13.0 | 27190601 |
| ECLASS-15.0 | 27190601 |

ETIM

| | |
|-----------|----------|
| ETIM 10.0 | EC002779 |
|-----------|----------|

UNSPSC

| | |
|-------------|----------|
| UNSPSC 21.0 | 31261500 |
|-------------|----------|

UM 45-PROFIL 235CM - Profile



2735441

<https://www.phoenixcontact.com/us/products/2735441>

Environmental product compliance

EU RoHS

| | |
|---|--------------------|
| Fulfills EU RoHS substance requirements | Yes, No exemptions |
|---|--------------------|

China RoHS

| | |
|--|--|
| Environment friendly use period (EFUP) | EFUP-E |
| | No hazardous substances above the limits |

EU REACH SVHC

| | |
|-------------------------------------|----------------------------|
| REACH candidate substance (CAS No.) | No substance above 0.1 wt% |
|-------------------------------------|----------------------------|

Phoenix Contact 2026 © - all rights reserved
<https://www.phoenixcontact.com>

Phoenix Contact USA
586 Fulling Mill Road
Middletown, PA 17057, United States
(+717) 944-1300
info@phoenixcon.com