

EG 22,5-A/ABS BU - Upper housing part



2764726

<https://www.phoenixcontact.com/us/products/2764726>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.

Component housing, Cover, for two-sided connection, width: 22.5 mm, height: 75 mm, color: blue (similar RAL 5015)



Your advantages

- Tool-free mounting

Commercial data

| | |
|--------------------------------------|---------------|
| Item number | 2764726 |
| Packing unit | 20 pc |
| Minimum order quantity | 20 pc |
| Sales key | AC11 |
| Product key | ACHCGA |
| GTIN | 4017918273330 |
| Weight per piece (including packing) | 9.1 g |
| Weight per piece (excluding packing) | 6.98 g |
| Customs tariff number | 85389099 |
| Country of origin | PL |

EG 22,5-A/ABS BU - Upper housing part

2764726


<https://www.phoenixcontact.com/us/products/2764726>

Technical data

Product properties

| | |
|------------------------------|--------------------|
| Product type | Upper housing part |
| Housing type | Component housing |
| Housing series | EG |
| Product family | EG...A |
| Number of positions | 8 |
| Number (Connection openings) | 2 |
| Ventilation openings present | no |

Dimensions
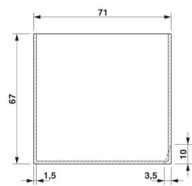
| | |
|---------------------|---|
| Dimensional drawing |  |
| Width | 22.5 mm |
| Height | 75 mm |

PCB design

| | |
|---------------|-------------------|
| PCB thickness | 1.4 mm ... 1.8 mm |
|---------------|-------------------|

Material specifications

| | |
|--|-----------------|
| Color (Upper housing part) | blue (RAL 5015) |
| Material Upper housing part | ABS |
| Flammability rating according to UL 94 | HB |

Environmental and real-life conditions

Ambient conditions

| | |
|---|---|
| Max. IP code to attain | IP20 |
| Ambient temperature (operation) | -40 °C ... 80 °C (depending on power dissipation) |
| Ambient temperature (storage/transport) | -40 °C ... 55 °C |
| Ambient temperature (assembly) | -5 °C ... 80 °C |

PCB data

| | |
|----------------------|-------------------|
| Thickness of the PCB | 1.4 mm ... 1.8 mm |
|----------------------|-------------------|

Mounting

| | |
|---------------|---------|
| Mounting type | Snap in |
|---------------|---------|


EG 22,5-A/ABS BU - Upper housing part

2764726

<https://www.phoenixcontact.com/us/products/2764726>



Drawings

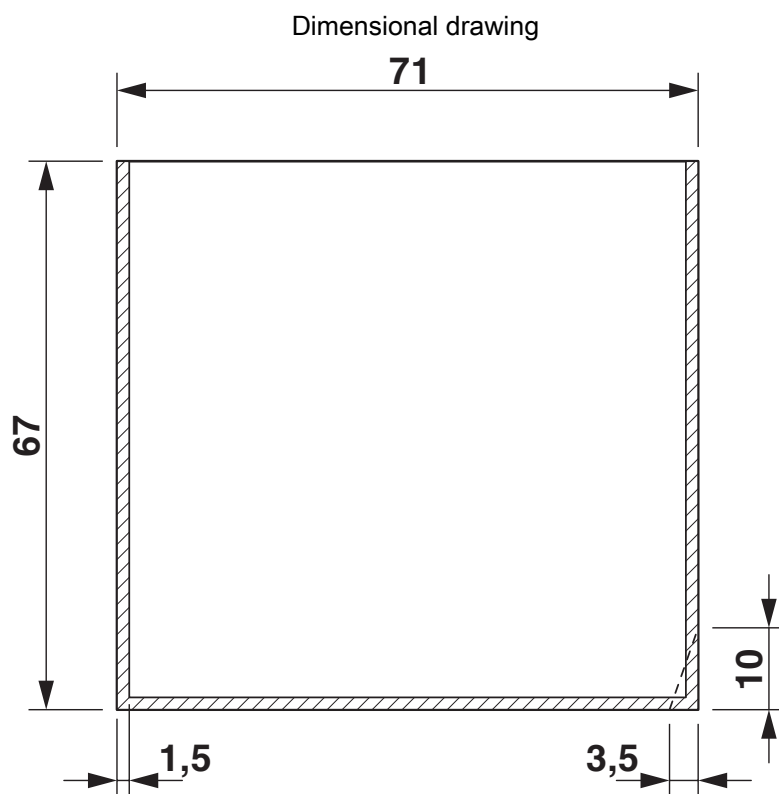

valid for PCB 7, see explosion drawing


EG 22,5-A/ABS BU - Upper housing part

2764726

<https://www.phoenixcontact.com/us/products/2764726>



Dimensional drawing

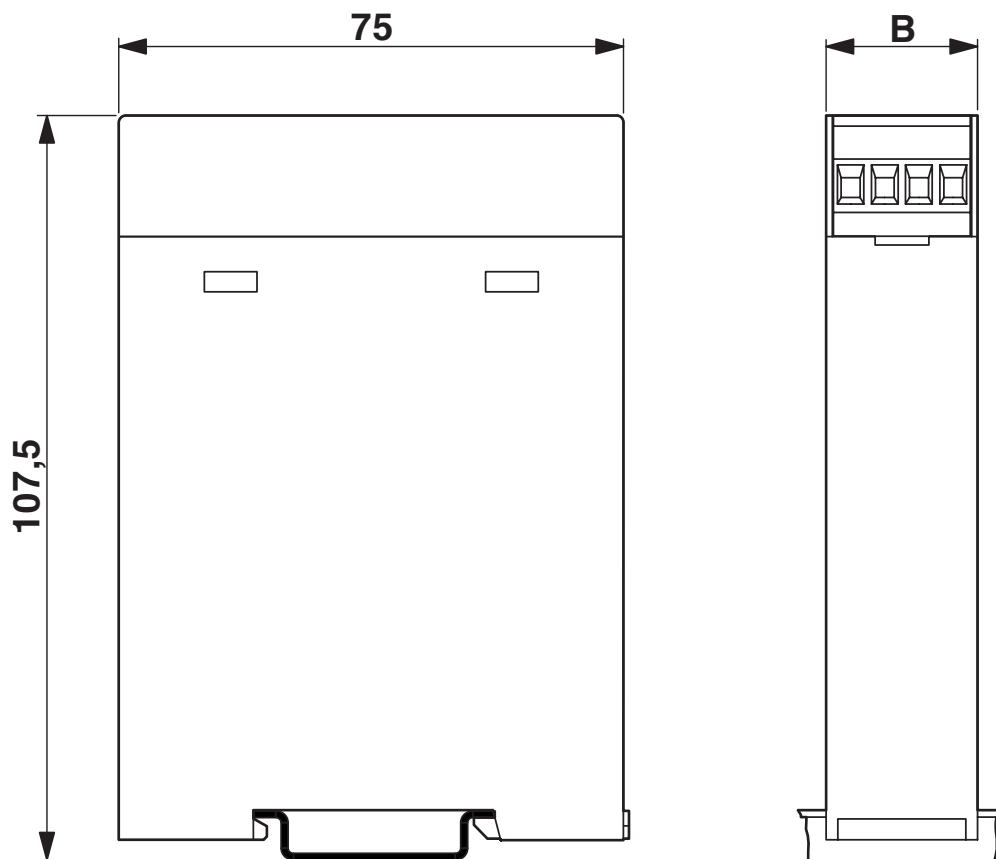


EG 22,5-A/ABS BU - Upper housing part



2764726

<https://www.phoenixcontact.com/us/products/2764726>

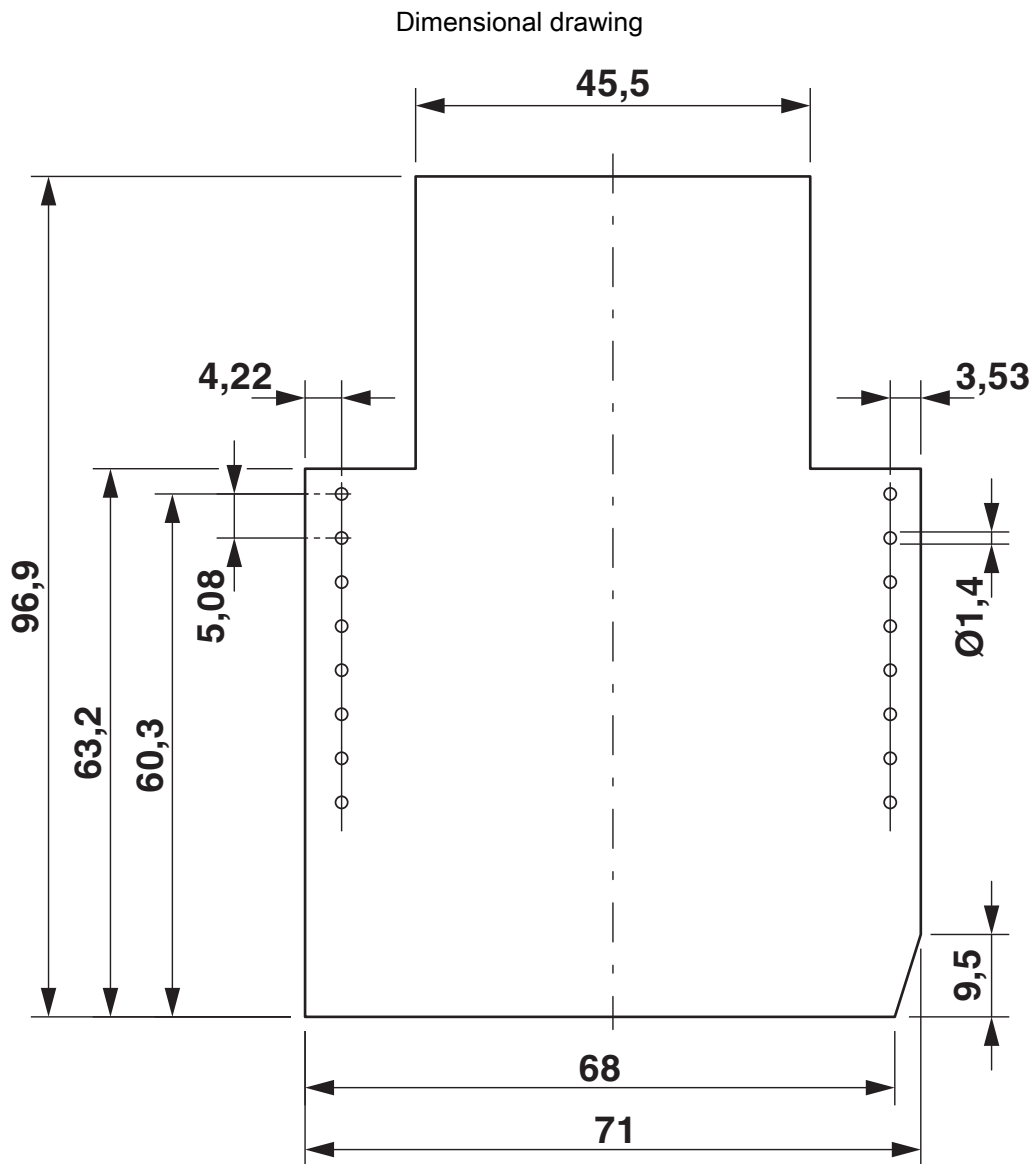

Component mounting side, if the double-level upper part is used


EG 22,5-A/ABS BU - Upper housing part

2764726

<https://www.phoenixcontact.com/us/products/2764726>



Dimensional drawing

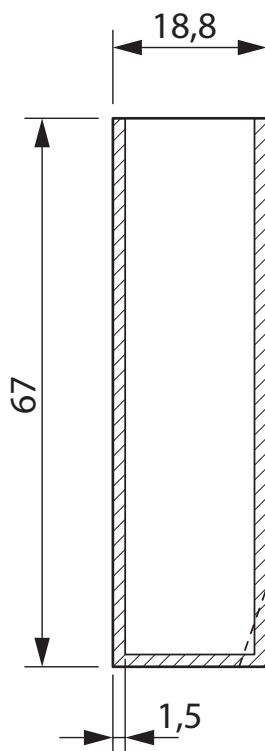

valid for PCB 1, see explosion drawing

EG 22,5-A/ABS BU - Upper housing part

2764726

<https://www.phoenixcontact.com/us/products/2764726>




valid for PCB 14

EG 22,5-A/ABS BU - Upper housing part

2764726

<https://www.phoenixcontact.com/us/products/2764726>

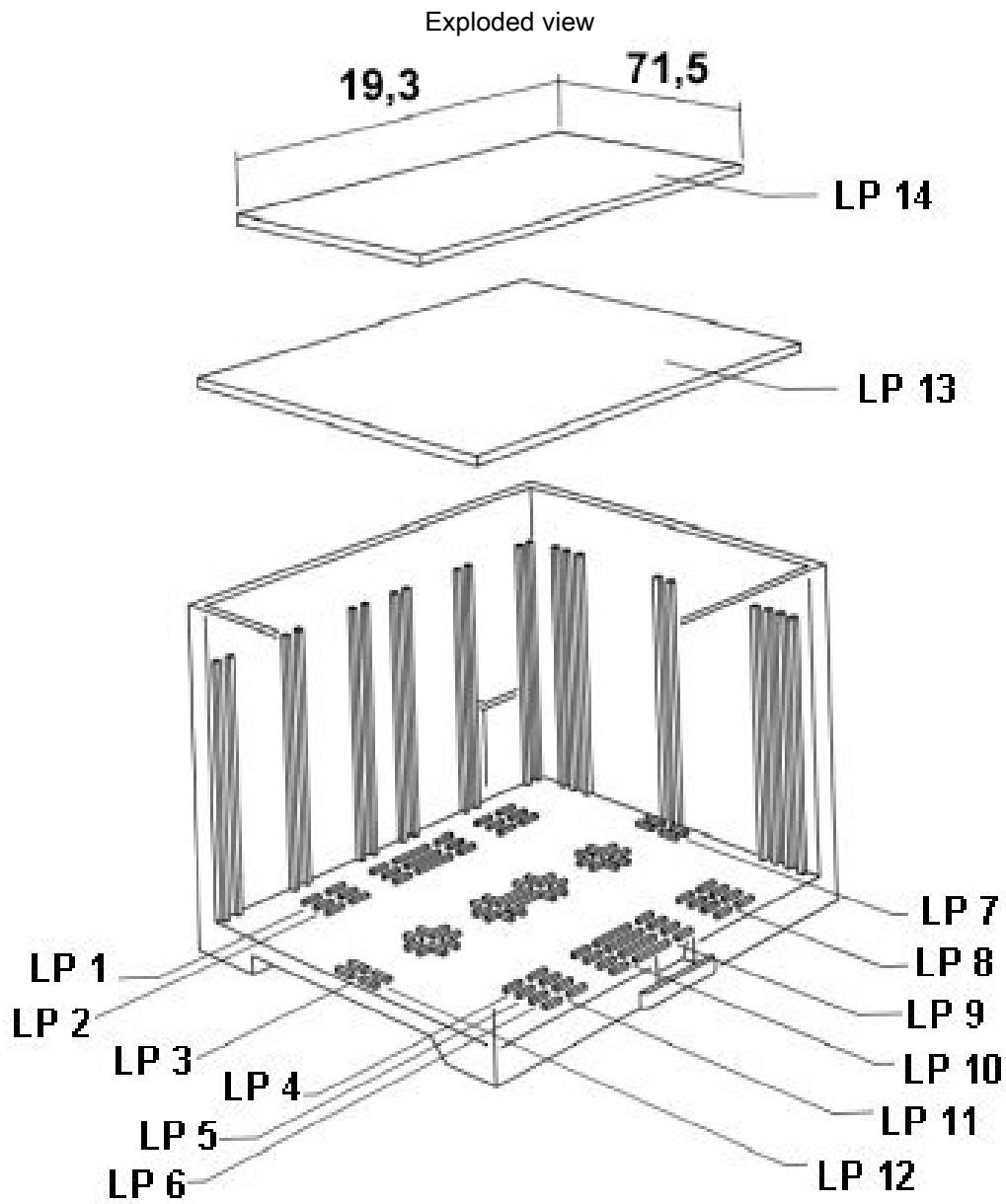

valid for PCB 13

EG 22,5-A/ABS BU - Upper housing part



2764726

<https://www.phoenixcontact.com/us/products/2764726>

Approvals

To download certificates, visit the product detail page: <https://www.phoenixcontact.com/us/products/2764726>



UL Recognized

Approval ID: E240868

EG 22,5-A/ABS BU - Upper housing part



2764726

<https://www.phoenixcontact.com/us/products/2764726>

Classifications

ECLASS

| | |
|-------------|----------|
| ECLASS-13.0 | 27190603 |
| ECLASS-15.0 | 27190603 |

ETIM

| | |
|-----------|----------|
| ETIM 10.0 | EC002779 |
|-----------|----------|

UNSPSC

| | |
|-------------|----------|
| UNSPSC 21.0 | 31261500 |
|-------------|----------|

EG 22,5-A/ABS BU - Upper housing part



2764726

<https://www.phoenixcontact.com/us/products/2764726>

Environmental product compliance

EU RoHS

| | |
|---|--------------------|
| Fulfills EU RoHS substance requirements | Yes, No exemptions |
|---|--------------------|

China RoHS

| | |
|--|--|
| Environment friendly use period (EFUP) | EFUP-E |
| | No hazardous substances above the limits |

EU REACH SVHC

| | |
|-------------------------------------|----------------------------|
| REACH candidate substance (CAS No.) | No substance above 0.1 wt% |
|-------------------------------------|----------------------------|

Phoenix Contact 2026 © - all rights reserved
<https://www.phoenixcontact.com>

Phoenix Contact USA
586 Fulling Mill Road
Middletown, PA 17057, United States
(+717) 944-1300
info@phoenixcon.com