

EG 22,5-GMFP/PC GN - Mounting base housing



2764807

<https://www.phoenixcontact.com/us/products/2764807>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



Housing base, with metal foot catch and test opening with side cover

The figure shows a fully mounted version of the electronic housing

Commercial data

| | |
|--------------------------------------|--------------------------------|
| Item number | 2764807 |
| Packing unit | 10 pc |
| Minimum order quantity | 10 pc |
| Note | Made to order (non-returnable) |
| Sales key | AC11 |
| Product key | ACHCGA |
| GTIN | 4017918131869 |
| Weight per piece (including packing) | 43.17 g |
| Weight per piece (excluding packing) | 35.314 g |
| Customs tariff number | 85389099 |
| Country of origin | PL |

EG 22,5-GMFP/PC GN - Mounting base housing



2764807


<https://www.phoenixcontact.com/us/products/2764807>

Technical data

Product properties

| | |
|---------------------|---|
| Housing type | Component housing |
| Type | Lower housing parts with test opening with side cover, housing cover necessary to complete the module |
| Number of positions | 8 |

Dimensions
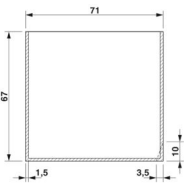
| | |
|---------------------|--|
| Dimensional drawing |  |
| Width | 22.5 mm |
| Installed height | 107.5 mm |
| Height NS 35/7,5 | 107.5 mm |
| Depth | 75 mm |
| Length | 75 mm |

Material specifications

| | |
|--|-------|
| Color | green |
| Flammability rating according to UL 94 | V0 |
| Housing material | PC |

Environmental and real-life conditions

Ambient conditions

| | |
|---------------------------------|-------------------|
| Ambient temperature (operation) | -40 °C ... 125 °C |
|---------------------------------|-------------------|

Mounting

| | |
|---------------|-------------------|
| Mounting type | DIN rail mounting |
|---------------|-------------------|


EG 22,5-GMFP/PC GN - Mounting base housing

2764807

<https://www.phoenixcontact.com/us/products/2764807>



Drawings

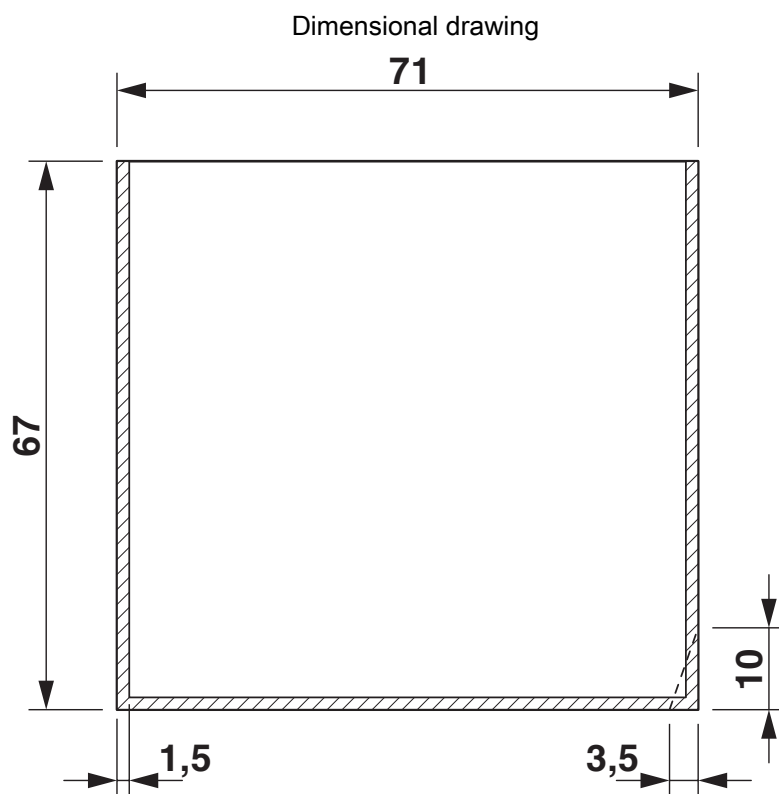

valid for PCB 7, see explosion drawing


EG 22,5-GMFP/PC GN - Mounting base housing

2764807

<https://www.phoenixcontact.com/us/products/2764807>



Dimensional drawing

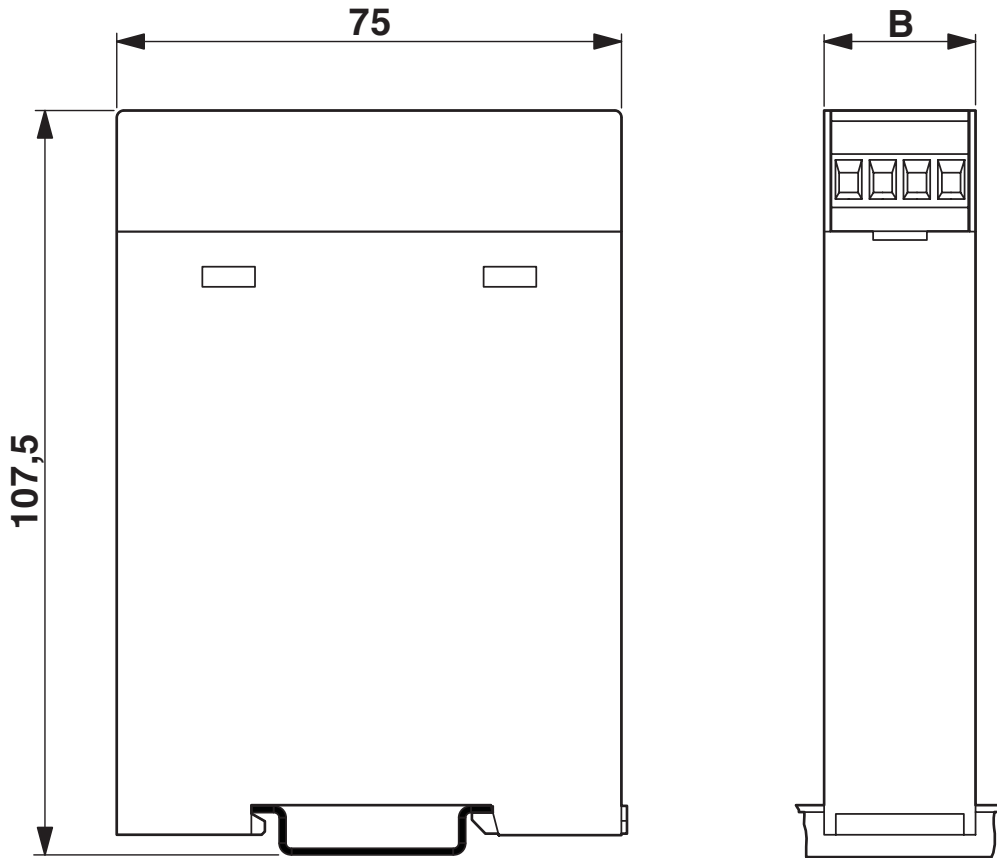

EG 22,5-GMFP/PC GN - Mounting base housing



2764807

<https://www.phoenixcontact.com/us/products/2764807>



Component mounting side, if the double-level upper part is used


EG 22,5-GMFP/PC GN - Mounting base housing

2764807

<https://www.phoenixcontact.com/us/products/2764807>



Dimensional drawing

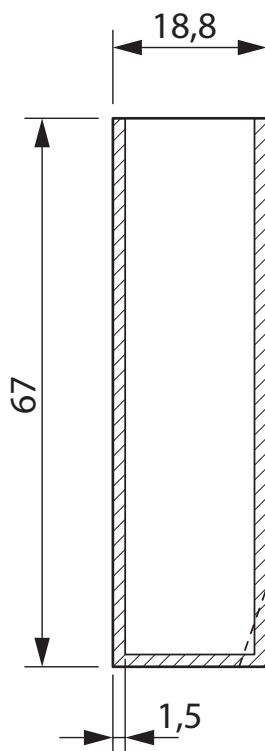

valid for PCB 1, see explosion drawing

EG 22,5-GMFP/PC GN - Mounting base housing

2764807

<https://www.phoenixcontact.com/us/products/2764807>




valid for PCB 14

EG 22,5-GMFP/PC GN - Mounting base housing

2764807

<https://www.phoenixcontact.com/us/products/2764807>

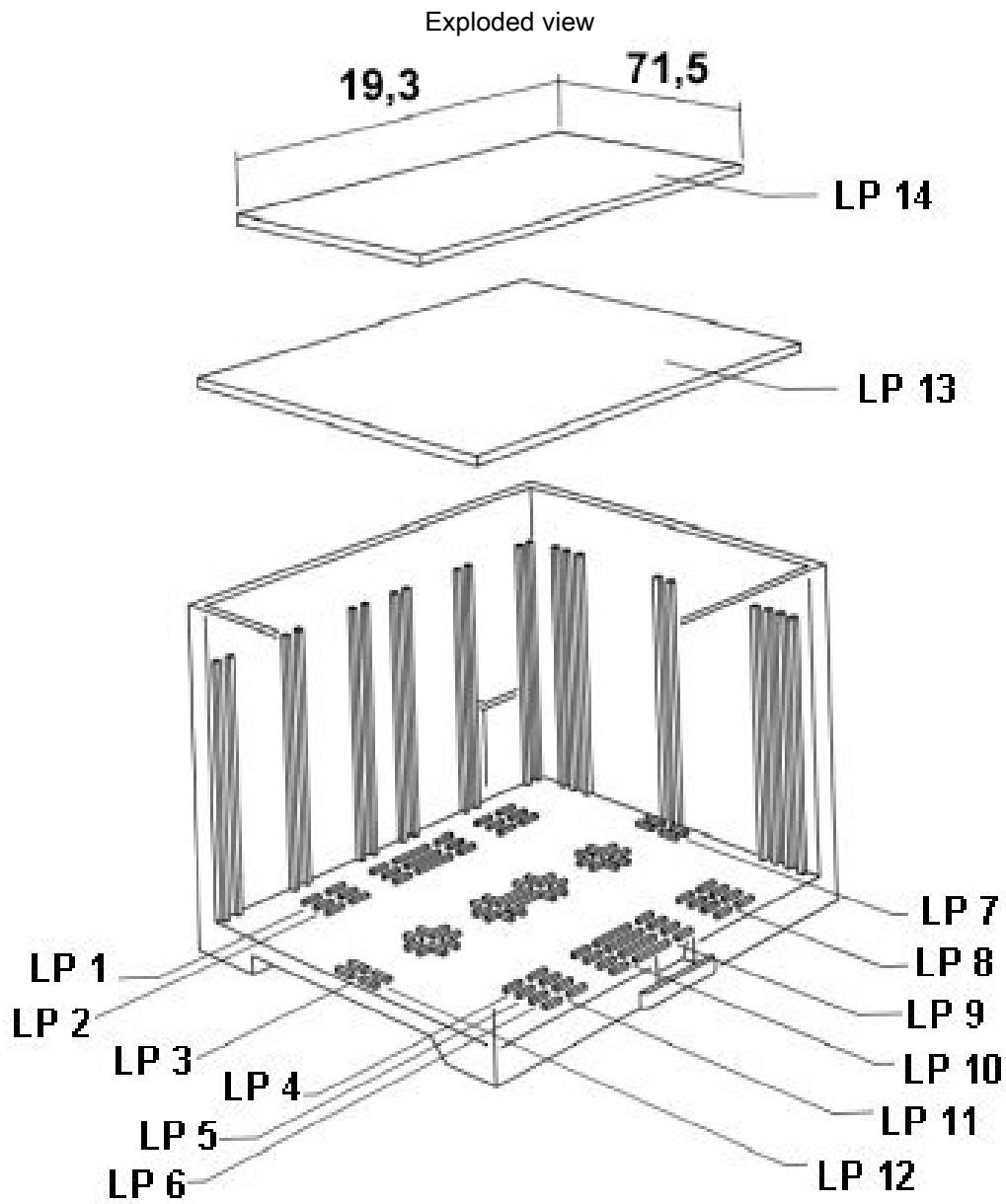

valid for PCB 13

EG 22,5-GMFP/PC GN - Mounting base housing



2764807

<https://www.phoenixcontact.com/us/products/2764807>

Classifications

UNSPSC

| | |
|-------------|----------|
| UNSPSC 21.0 | 31261500 |
|-------------|----------|

EG 22,5-GMFP/PC GN - Mounting base housing



2764807

<https://www.phoenixcontact.com/us/products/2764807>

Environmental product compliance

EU RoHS

| | |
|---|--------------------|
| Fulfills EU RoHS substance requirements | Yes, No exemptions |
|---|--------------------|

China RoHS

| | |
|--|--|
| Environment friendly use period (EFUP) | EFUP-E |
| | No hazardous substances above the limits |

EU REACH SVHC

| | |
|-------------------------------------|----------------------------|
| REACH candidate substance (CAS No.) | No substance above 0.1 wt% |
|-------------------------------------|----------------------------|

Phoenix Contact 2026 © - all rights reserved
<https://www.phoenixcontact.com>

Phoenix Contact USA
586 Fulling Mill Road
Middletown, PA 17057, United States
(+717) 944-1300
info@phoenixcon.com