

# EG 22,5-A/PC GN - Upper housing part



2764823

<https://www.phoenixcontact.com/us/products/2764823>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.

Housing cover, for connection on both sides



## Your advantages

- Tool-free mounting

## Commercial data

|                                      |               |
|--------------------------------------|---------------|
| Item number                          | 2764823       |
| Packing unit                         | 20 pc         |
| Minimum order quantity               | 20 pc         |
| Sales key                            | AC11          |
| Product key                          | ACHCGA        |
| GTIN                                 | 4017918131883 |
| Weight per piece (including packing) | 10.17 g       |
| Weight per piece (excluding packing) | 8.33 g        |
| Customs tariff number                | 85389099      |
| Country of origin                    | PL            |

# EG 22,5-A/PC GN - Upper housing part

2764823


<https://www.phoenixcontact.com/us/products/2764823>

## Technical data

### Product properties

|                              |                    |
|------------------------------|--------------------|
| Product type                 | Upper housing part |
| Housing type                 | Component housing  |
| Housing series               | EG                 |
| Product family               | EG...A             |
| Number of positions          | 8                  |
| Number (Connection openings) | 2                  |
| Ventilation openings present | no                 |

### Dimensions
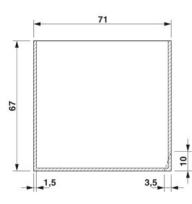
|                     |   |
|---------------------|---|
| Dimensional drawing |  |
| Width               | 22.5 mm   |
| Height              | 75 mm   |

### PCB design

|               |                   |
|---------------|-------------------|
| PCB thickness | 1.4 mm ... 1.8 mm |
|---------------|-------------------|

### Material specifications

|  |                  |
|--|------------------|
| Color (Upper housing part)             | green (RAL 6021) |
| Material Upper housing part            | PC               |
| Flammability rating according to UL 94 | V0               |

### Environmental and real-life conditions

#### Ambient conditions

|   |  |
|---|--|
| Max. IP code to attain                  | IP20   |
| Ambient temperature (operation)         | -40 °C ... 105 °C (depending on power dissipation) |
| Ambient temperature (storage/transport) | -40 °C ... 70 °C                                   |
| Ambient temperature (assembly)          | -5 °C ... 100 °C                                   |

### PCB data

|                      |                   |
|----------------------|-------------------|
| Thickness of the PCB | 1.4 mm ... 1.8 mm |
|----------------------|-------------------|

### Mounting

|               |         |
|---------------|---------|
| Mounting type | Snap in |
|---------------|---------|


# EG 22,5-A/PC GN - Upper housing part

2764823

<https://www.phoenixcontact.com/us/products/2764823>



## Drawings

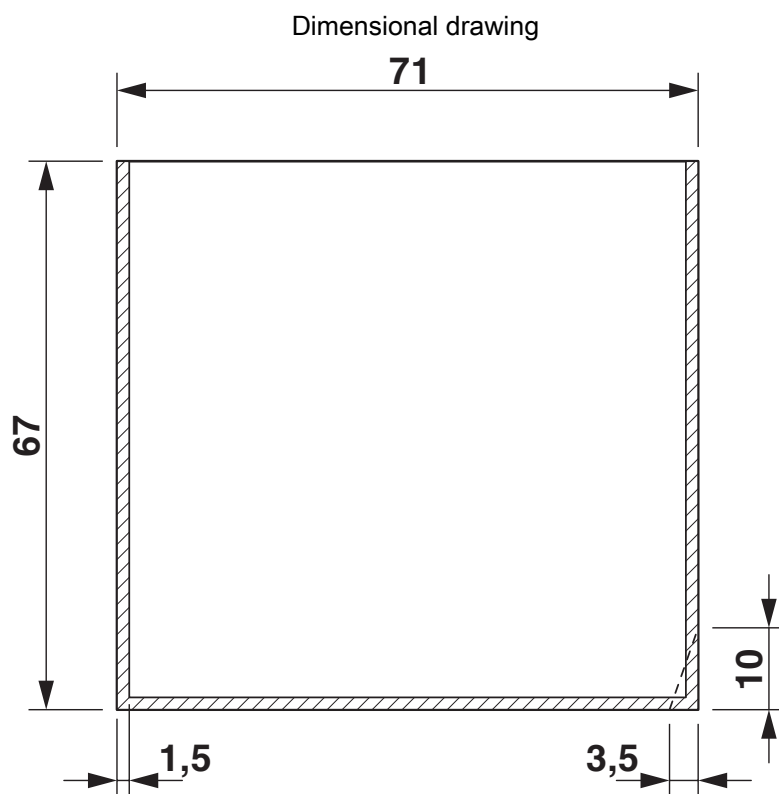

valid for PCB 7, see explosion drawing


# EG 22,5-A/PC GN - Upper housing part

2764823

<https://www.phoenixcontact.com/us/products/2764823>



Dimensional drawing

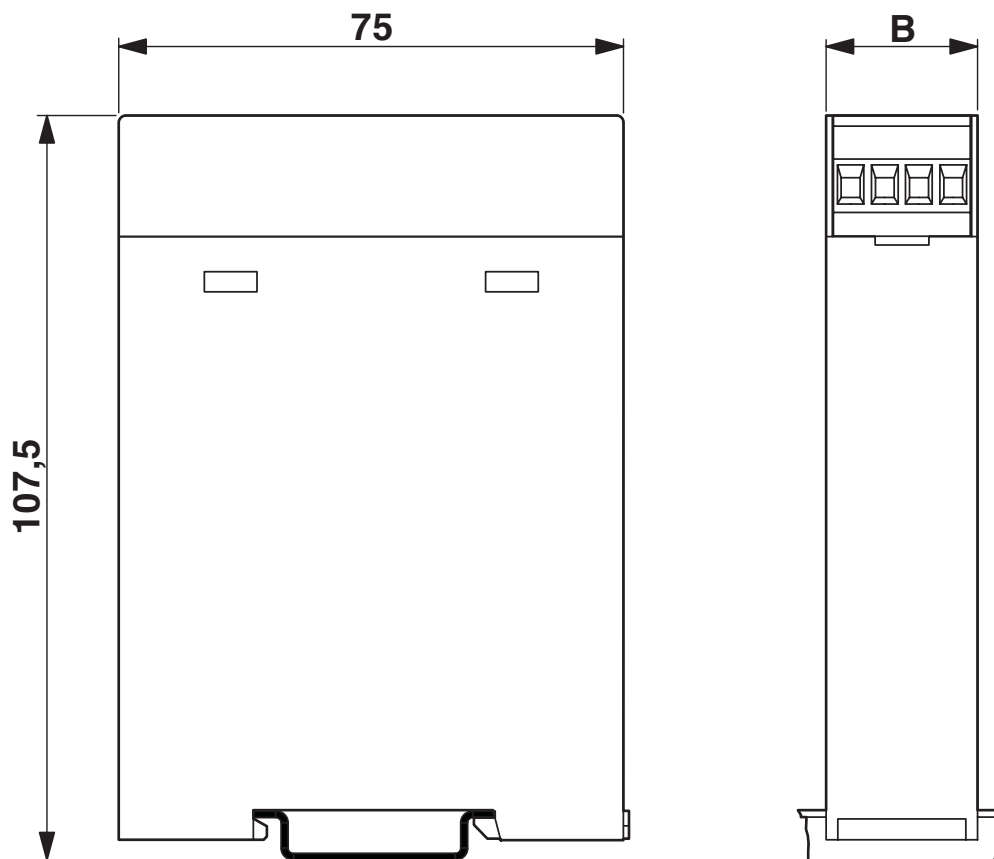

# EG 22,5-A/PC GN - Upper housing part

2764823

<https://www.phoenixcontact.com/us/products/2764823>



Component mounting side, if the double-level upper part is used


# EG 22,5-A/PC GN - Upper housing part

2764823

<https://www.phoenixcontact.com/us/products/2764823>



Dimensional drawing

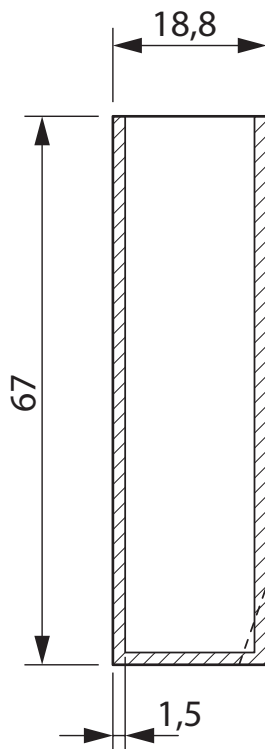

valid for PCB 1, see explosion drawing

# EG 22,5-A/PC GN - Upper housing part

2764823

<https://www.phoenixcontact.com/us/products/2764823>




valid for PCB 14

# EG 22,5-A/PC GN - Upper housing part

2764823

<https://www.phoenixcontact.com/us/products/2764823>

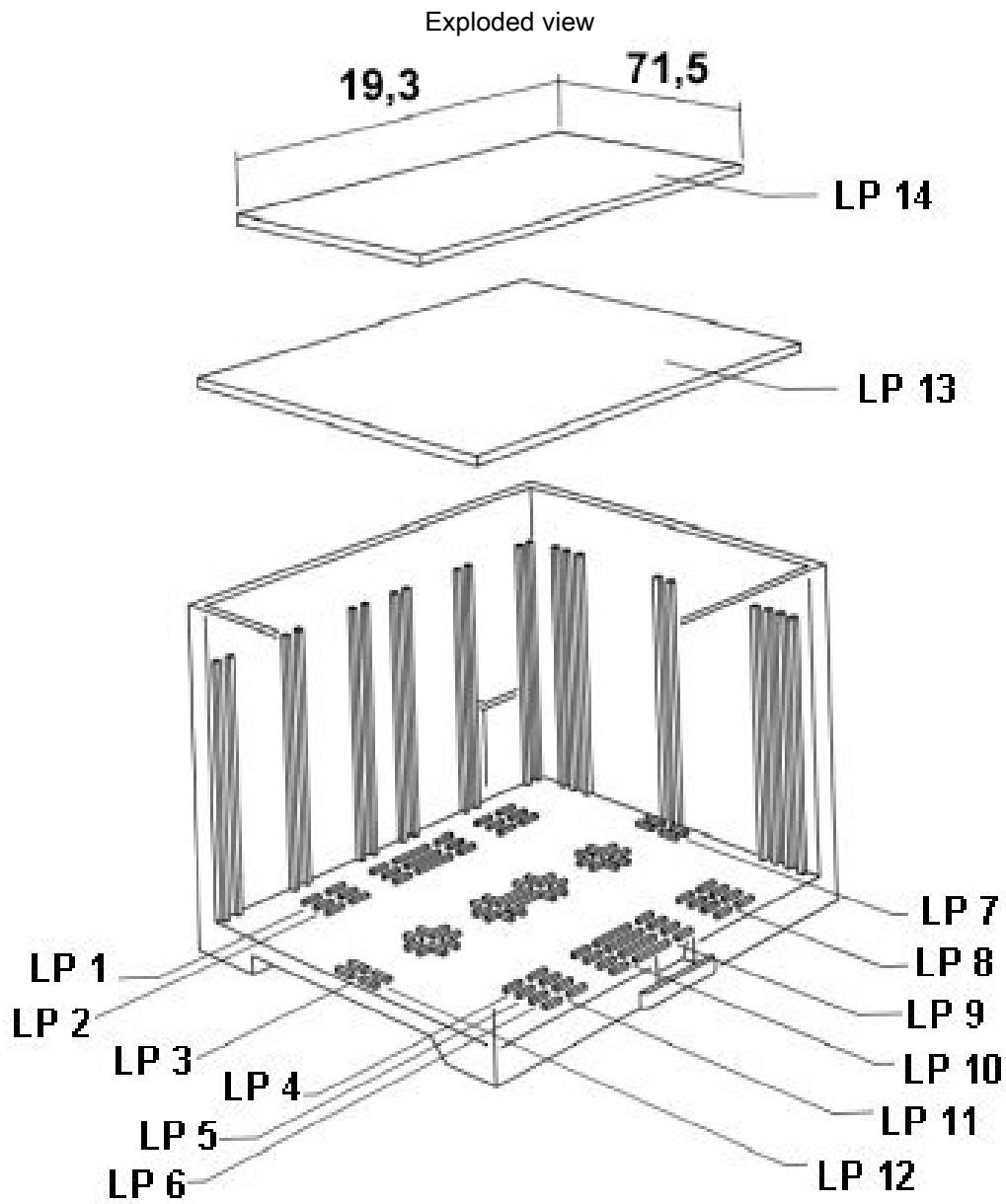

valid for PCB 13

# EG 22,5-A/PC GN - Upper housing part



2764823

<https://www.phoenixcontact.com/us/products/2764823>

## Approvals

To download certificates, visit the product detail page: <https://www.phoenixcontact.com/us/products/2764823>



**UL Recognized**

Approval ID: E240868

# EG 22,5-A/PC GN - Upper housing part



2764823

<https://www.phoenixcontact.com/us/products/2764823>

## Classifications

### ECLASS

|             |          |
|-------------|----------|
| ECLASS-13.0 | 27190603 |
| ECLASS-15.0 | 27190603 |

### ETIM

|           |          |
|-----------|----------|
| ETIM 10.0 | EC002779 |
|-----------|----------|

### UNSPSC

|             |          |
|-------------|----------|
| UNSPSC 21.0 | 31261500 |
|-------------|----------|

# EG 22,5-A/PC GN - Upper housing part



2764823

<https://www.phoenixcontact.com/us/products/2764823>

## Environmental product compliance

### EU RoHS

|   |                    |
|---|--------------------|
| Fulfills EU RoHS substance requirements | Yes, No exemptions |
|---|--------------------|

### China RoHS

|  |  |
|--|--|
| Environment friendly use period (EFUP) | EFUP-E                                   |
|  | No hazardous substances above the limits |

### EU REACH SVHC

|                                     |                            |
|-------------------------------------|----------------------------|
| REACH candidate substance (CAS No.) | No substance above 0.1 wt% |
|-------------------------------------|----------------------------|

Phoenix Contact 2026 © - all rights reserved  
<https://www.phoenixcontact.com>

Phoenix Contact USA  
586 Fulling Mill Road  
Middletown, PA 17057, United States  
(+717) 944-1300  
[info@phoenixcon.com](mailto:info@phoenixcon.com)