

IBS IL 24 BK RB LK-2MBD - Bus coupler



2855347

<https://www.phoenixcontact.com/us/products/2855347>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



INTERBUS bus coupler, with fiber optic connection and fiber optic remote bus branch, 24 V DC, transmission speed 2 Mbaud, without accessories

The figure shows the version IBS IL 24 BK RB-LK

Your advantages

- Optical path diagnostics
- Remote bus connections using fiber optic technology

Commercial data

Item number	2855347
Packing unit	1 pc
Note	Made to order (non-returnable)
Sales key	NULL
Product key	DRI111
GTIN	4017918876876
Weight per piece (including packing)	320.5 g
Weight per piece (excluding packing)	276.5 g
Customs tariff number	85389091
Country of origin	DE

IBS IL 24 BK RB LK-2MBD - Bus coupler




2855347

<https://www.phoenixcontact.com/us/products/2855347>

Technical data

Dimensions

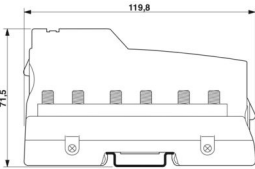Dimensional drawing	
Width	85 mm
Height	119.8 mm
Depth	71.5 mm

Material specifications

Color	green
-------	-------

Interfaces

INTERBUS

No. of channels	3
Connection method	F-SMA connector
Number of positions	2
Transmission speed	2 Mbps
Transmission physics	FO

Inline local bus

Connection method	Inline data jumper
Transmission speed	2 Mbps
Transmission physics	FO

Supply

Connection method	8-pos. Inline connector
-------------------	-------------------------

System properties

System limits

Number of local bus devices that can be connected	max. 63
Number of devices with parameter channel	63
Number of supported branch terminals with remote bus branch	max. 15

Module

ID code (dec.)	12
ID code (hex)	0C
Length code (hex)	0
Length code (dec)	0

IBS IL 24 BK RB LK-2MBD - Bus coupler



2855347

<https://www.phoenixcontact.com/us/products/2855347>

Process data channel	0 bit
Input address area	0 Byte
Register length	0 bit

Product properties

Product type	I/O component
Product family	Inline
Type	modular

Electrical properties

Protective circuit	Reverse polarity protection
--------------------	-----------------------------

Potentials: Bus coupler supply U_{BK} ; Communications power U_L (7.5 V) and the analog supply U_{ANA} (24 V) are generated from the bus coupler supply.

Supply voltage	24 V DC (via Inline connector)
Supply voltage range	19.2 V DC ... 30 V DC (including all tolerances, including ripple)
Current draw	max. 1.3 A (with max. number of connected I/O terminal blocks) typ. 120 mA (without connected Inline I/O terminals)

Potentials: Communications power (U_L)

Supply voltage	7.5 V DC $\pm 5\%$
Power supply	max. 2 A DC (observe derating)

Potentials: Supply of analog modules (U_{ANA})

Supply voltage	24 V DC
Supply voltage range	19.2 V DC ... 30 V DC (including all tolerances, including ripple)
Power supply	max. 0.5 A DC (observe derating)

Electrical isolation/isolation of the voltage ranges

Test voltage: 7.5 V communications power, 24 V analog supply, 24 V bus coupler supply/functional ground	500 V AC, 50 Hz, 1 min
---	------------------------

Connection data

Connection technology

Connection name	Inline connector
-----------------	------------------

Inline connector

Connection method	Spring-cage connection
Conductor cross-section, rigid	0.09 mm ² ... 1.5 mm ²
Conductor cross-section, flexible	0.09 mm ² ... 1.5 mm ²
Conductor cross-section AWG	28 ... 16

Environmental and real-life conditions

Ambient conditions

Ambient temperature (operation)	-25 °C ... 55 °C
Degree of protection	IP20

IBS IL 24 BK RB LK-2MBD - Bus coupler



2855347

<https://www.phoenixcontact.com/us/products/2855347>

Air pressure (operation)	80 kPa ... 106 kPa (up to 3000 m above sea level)
Air pressure (storage/transport)	70 kPa ... 106 kPa (up to 3000 m above sea level)
Ambient temperature (storage/transport)	-25 °C ... 85 °C
Permissible humidity (operation)	75 % ... 85 %
Permissible humidity (storage/transport)	75 % ... 85 %

Mounting

Mounting type	DIN rail mounting
---------------	-------------------

IBS IL 24 BK RB LK-2MBD - Bus coupler




2855347

<https://www.phoenixcontact.com/us/products/2855347>

Drawings

Dimensional drawing

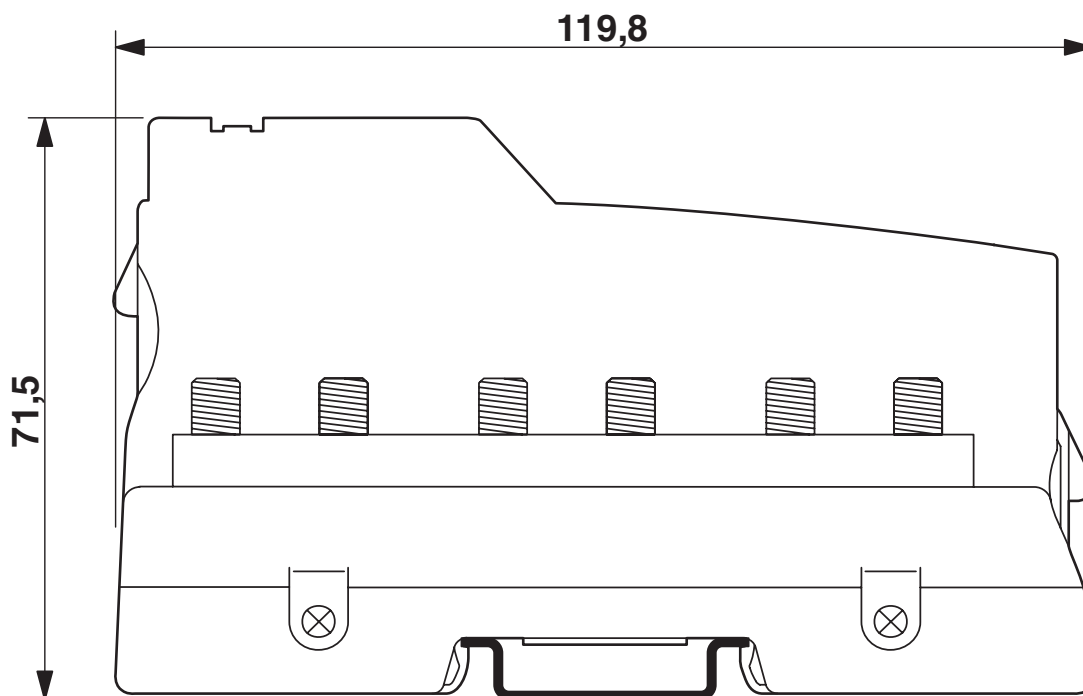

IBS IL 24 BK RB LK-2MBD - Bus coupler



2855347

<https://www.phoenixcontact.com/us/products/2855347>

Environmental product compliance

EU REACH SVHC

REACH candidate substance (CAS No.)	No substance above 0.1 wt%
-------------------------------------	----------------------------

Phoenix Contact 2026 © - all rights reserved

<https://www.phoenixcontact.com>

Phoenix Contact USA
586 Fulling Mill Road
Middletown, PA 17057, United States
(+717) 944-1300
info@phoenixcon.com