

FLT-ISG-BR-33 - Fixing bracket

2905759

<https://www.phoenixcontact.com/us/products/2905759>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.

Bracket for fixing the FLT-ISG-100-EX isolating spark gap to a flange, drill hole diameter of 33 mm.



Commercial data

| | |
|--------------------------------------|--------------------------------|
| Item number | 2905759 |
| Packing unit | 1 pc |
| Minimum order quantity | 1 pc |
| Note | Made to order (non-returnable) |
| Sales key | CL01 |
| Product key | CL1134 |
| GTIN | 4055626002507 |
| Weight per piece (including packing) | 174.2 g |
| Weight per piece (excluding packing) | 174.2 g |
| Customs tariff number | 73269098 |
| Country of origin | DE |

FLT-ISG-BR-33 - Fixing bracket

2905759

<https://www.phoenixcontact.com/us/products/2905759>



Technical data

Product properties

| | |
|--------------|-------------------|
| Product type | Mounting material |
|--------------|-------------------|

Material specifications

| | |
|----------|-----------------|
| Color | zinc color |
| | gray (RAL 7042) |
| Material | St/tZn |

Mounting

| | |
|---------------|----------------|
| Mounting type | Screw mounting |
|---------------|----------------|

FLT-ISG-BR-33 - Fixing bracket


2905759

<https://www.phoenixcontact.com/us/products/2905759>



Drawings

Dimensional drawing

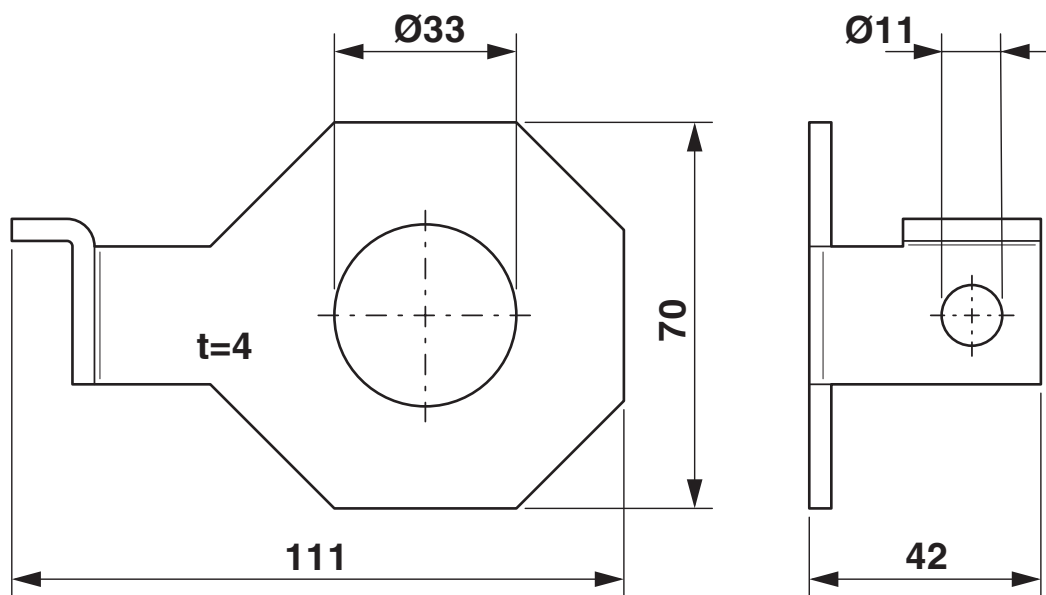

FLT-ISG-BR-33 - Fixing bracket



2905759

<https://www.phoenixcontact.com/us/products/2905759>

Classifications

ECLASS

| | |
|-------------|----------|
| ECLASS-13.0 | 27170692 |
| ECLASS-15.0 | 27170692 |

ETIM

| | |
|-----------|----------|
| ETIM 10.0 | EC000490 |
|-----------|----------|

UNSPSC

| | |
|-------------|----------|
| UNSPSC 21.0 | 39121700 |
|-------------|----------|

FLT-ISG-BR-33 - Fixing bracket



2905759

<https://www.phoenixcontact.com/us/products/2905759>

Environmental product compliance

EU RoHS

| | |
|---|--------------------|
| Fulfills EU RoHS substance requirements | Yes, No exemptions |
|---|--------------------|

China RoHS

| | |
|--|--|
| Environment friendly use period (EFUP) | EFUP-E |
| | No hazardous substances above the limits |

EU REACH SVHC

| | |
|-------------------------------------|----------------------------|
| REACH candidate substance (CAS No.) | No substance above 0.1 wt% |
|-------------------------------------|----------------------------|

EF3.1 Climate Change

| | |
|---------|---------------|
| CO2e kg | 1.278 kg CO2e |
|---------|---------------|

Phoenix Contact 2026 © - all rights reserved
<https://www.phoenixcontact.com>

Phoenix Contact USA
586 Fulling Mill Road
Middletown, PA 17057, United States
(+717) 944-1300
info@phoenixcon.com