

# UM108-SEPEF/L-A60 - Lateral element



2906500

<https://www.phoenixcontact.com/us/products/2906500>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



Side element with foot, tall design, left-hand, for 60 mm wide U-shaped cover, with PE contact to the DIN rail.

## Commercial data

|                                      |                                |
|--------------------------------------|--------------------------------|
| Item number                          | 2906500                        |
| Packing unit                         | 10 pc                          |
| Minimum order quantity               | 1 pc                           |
| Note                                 | Made to order (non-returnable) |
| Sales key                            | AC13                           |
| Product key                          | ACHDBA                         |
| GTIN                                 | 4017918131333                  |
| Weight per piece (including packing) | 24.81 g                        |
| Weight per piece (excluding packing) | 24.81 g                        |
| Customs tariff number                | 39269097                       |
| Country of origin                    | PL                             |

# UM108-SEPEF/L-A60 - Lateral element



2906500

<https://www.phoenixcontact.com/us/products/2906500>

## Technical data

### Product properties

|                              |                               |
|------------------------------|-------------------------------|
| Product type                 | Panel mounting base side part |
| Housing type                 | Press-drawn section housings  |
| Housing series               | UM                            |
| Product family               | UM108                         |
| Ventilation openings present | no                            |

### Material specifications

|  |                  |
|--|------------------|
| Color (Side element)                   | green (RAL 6021) |
| Material Lateral element               | PA               |
| Flammability rating according to UL 94 | V0               |

### Environmental and real-life conditions

#### Ambient conditions

|                                 |  |
|---------------------------------|--|
| Ambient temperature (operation) | -40 °C ... 105 °C (depending on power dissipation) |
|---------------------------------|--|

# UM108-SEPEF/L-A60 - Lateral element




2906500


<https://www.phoenixcontact.com/us/products/2906500>

## Drawings

Dimensional drawing

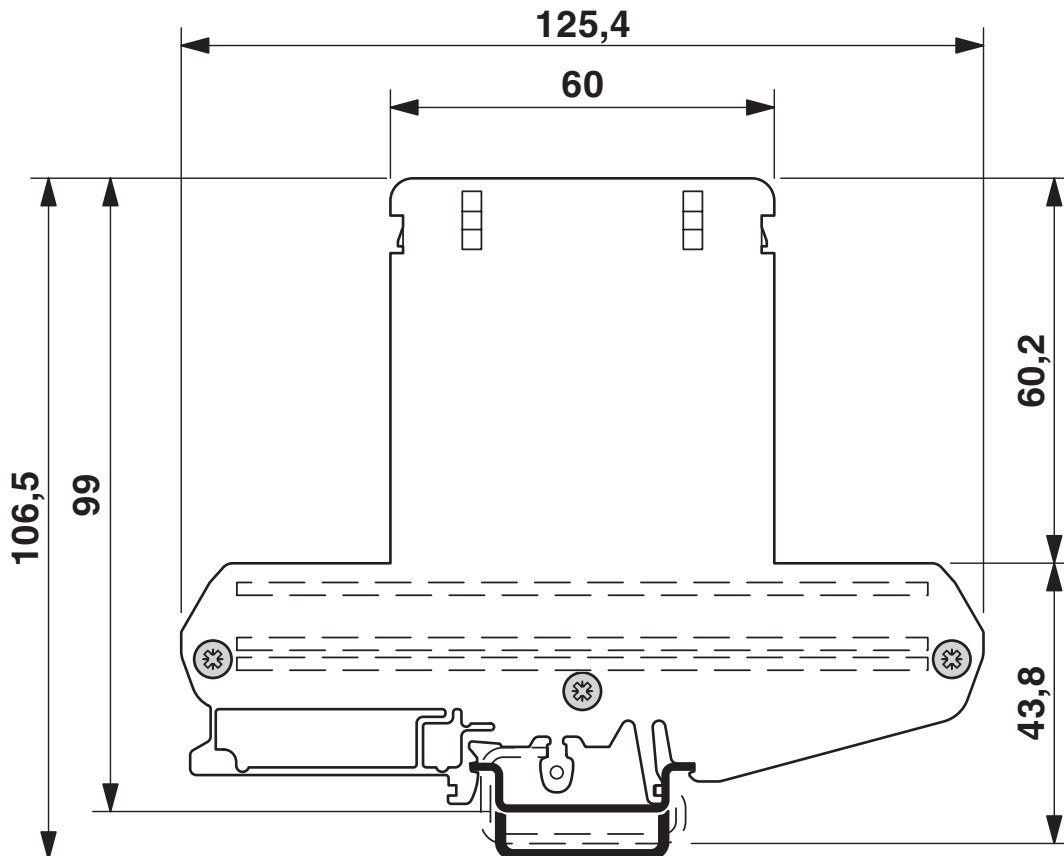

Drilling plan/solder pad geometry

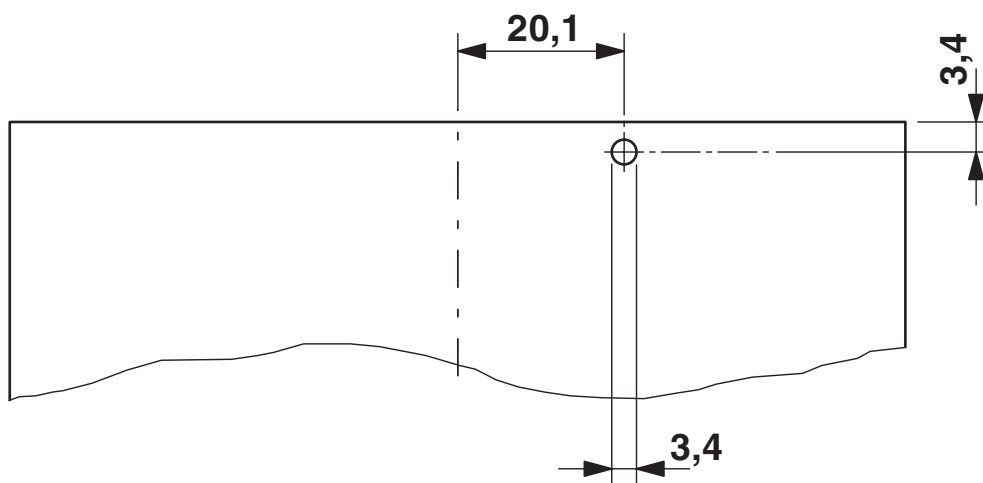

# UM108-SEPEF/L-A60 - Lateral element



2906500

<https://www.phoenixcontact.com/us/products/2906500>

## Approvals

To download certificates, visit the product detail page: <https://www.phoenixcontact.com/us/products/2906500>



**UL Recognized**

Approval ID: E240868

# UM108-SEPEF/L-A60 - Lateral element



2906500

<https://www.phoenixcontact.com/us/products/2906500>

## Classifications

### ECLASS

|             |          |
|-------------|----------|
| ECLASS-13.0 | 27190602 |
| ECLASS-15.0 | 27190602 |

### ETIM

|           |          |
|-----------|----------|
| ETIM 10.0 | EC002779 |
|-----------|----------|

### UNSPSC

|             |          |
|-------------|----------|
| UNSPSC 21.0 | 31261500 |
|-------------|----------|

# UM108-SEPEF/L-A60 - Lateral element



2906500

<https://www.phoenixcontact.com/us/products/2906500>

## Environmental product compliance

### EU RoHS

|   |                    |
|---|--------------------|
| Fulfills EU RoHS substance requirements | Yes, No exemptions |
|---|--------------------|

### China RoHS

|  |  |
|--|--|
| Environment friendly use period (EFUP) | EFUP-E                                   |
|  | No hazardous substances above the limits |

### EU REACH SVHC

|                                     |                            |
|-------------------------------------|----------------------------|
| REACH candidate substance (CAS No.) | No substance above 0.1 wt% |
|-------------------------------------|----------------------------|

Phoenix Contact 2026 © - all rights reserved  
<https://www.phoenixcontact.com>

Phoenix Contact USA  
586 Fulling Mill Road  
Middletown, PA 17057, United States  
(+717) 944-1300  
[info@phoenixcon.com](mailto:info@phoenixcon.com)