

UM 72-SEFE/L LBGY - Lateral element




2915960

<https://www.phoenixcontact.com/us/products/2915960>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.

Press-drawn section housings, DIN rail mounting, Lateral element (left), with snap-on foot, width: 5 mm, height: 89.6 mm, depth: 37.6 mm

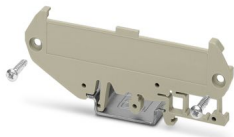

Your advantages

- Easy installation
- Flexible size and shape
- Inexpensive as a result of reducing the number of separate housing parts

Commercial data

Item number	2915960
Packing unit	10 pc
Minimum order quantity	250 pc
Note	Made to order (non-returnable)
Product key	ACHDBA
GTIN	4046356177955
Weight per piece (including packing)	6.63 g
Weight per piece (excluding packing)	6.63 g
Country of origin	PL

UM 72-SEFE/L LBGY - Lateral element



2915960

<https://www.phoenixcontact.com/us/products/2915960>

Technical data

Product properties

Product type	Panel mounting base side part
Housing type	Press-drawn section housings
Housing series	UM
Product family	UM72
Ventilation openings present	no

Dimensions

Width	5 mm
Height	89.6 mm
Depth	37.6 mm

Material specifications

Color (Housing)	beige (RAL 7032)
Flammability rating according to UL 94	V0
Housing material	PA

Environmental and real-life conditions

Ambient conditions

Ambient temperature (operation)	-40 °C ... 105 °C (depending on power dissipation)
Ambient temperature (storage/transport)	-40 °C ... 55 °C
Ambient temperature (assembly)	-5 °C ... 100 °C
Relative humidity (storage/transport)	80 %

Mounting

Mounting type	DIN rail mounting
---------------	-------------------

UM 72-SEFE/L LBGY - Lateral element



2915960

<https://www.phoenixcontact.com/us/products/2915960>

Classifications

ECLASS

ECLASS-13.0	27190602
ECLASS-15.0	27190601

ETIM

ETIM 9.0	EC002779
----------	----------

UNSPSC

UNSPSC 21.0	31261500
-------------	----------

UM 72-SEFE/L LBGY - Lateral element



2915960

<https://www.phoenixcontact.com/us/products/2915960>

Environmental product compliance

EU RoHS

Fulfills EU RoHS substance requirements	Yes, No exemptions
---	--------------------

China RoHS

Environment friendly use period (EFUP)	EFUP-E
	No hazardous substances above the limits

EU REACH SVHC

REACH candidate substance (CAS No.)	No substance above 0.1 wt%
-------------------------------------	----------------------------

EF3.1 Climate Change

CO2e kg	0.265 kg CO2e
---------	---------------

Phoenix Contact 2026 © - all rights reserved
<https://www.phoenixcontact.com>

Phoenix Contact USA
586 Fulling Mill Road
Middletown, PA 17057, United States
(+717) 944-1300
info@phoenixcon.com