

# UM-BEFE 35 - Base element

2955564

<https://www.phoenixcontact.com/us/products/2955564>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.

Base element with snap-on foot, for mounting on NS 32 or NS 35/7.5 DIN rail, with ribs, L = 35 mm



The figure shows a combination of versions UM-SE, UM 16,5 BE, UM-BE 35, UM-BEFE 35, UM-SE-A 73 and UM-A/U 73 CM

## Commercial data

Item number	2955564
Packing unit	10 pc
Minimum order quantity	10 pc
Sales key	AC13
Product key	ACHDDA
GTIN	4017918085537
Weight per piece (including packing)	21.23 g
Weight per piece (excluding packing)	21.18 g
Customs tariff number	85389099
Country of origin	PL

# UM-BEFE 35 - Base element

2955564


<https://www.phoenixcontact.com/us/products/2955564>

## Technical data

### Product properties

Product type	Component housing lower part
Housing type	Press-drawn section housings
Housing type	Plug-in module DIN rail-mount base
Housing series	UM
Product family	UM BE
Ventilation openings present	no

### Dimensions

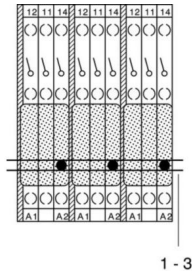Dimensional drawing	
Width	35 mm
Height	111 mm
Depth	27.7 mm

### Material specifications

Color (Housing)	green (RAL 6021)
Material	PA

### Environmental and real-life conditions

#### Ambient conditions

Ambient temperature (operation)	-40 °C ... 105 °C (depending on power dissipation)
Ambient temperature (storage/transport)	-40 °C ... 55 °C
Ambient temperature (assembly)	-5 °C ... 100 °C
Relative humidity (storage/transport)	80 %

### PCB data

Number of PCB holders	1
-----------------------	---

### Mounting

Mounting type	DIN rail mounting
---------------	-------------------


# UM-BEFE 35 - Base element

2955564

<https://www.phoenixcontact.com/us/products/2955564>



## Drawings

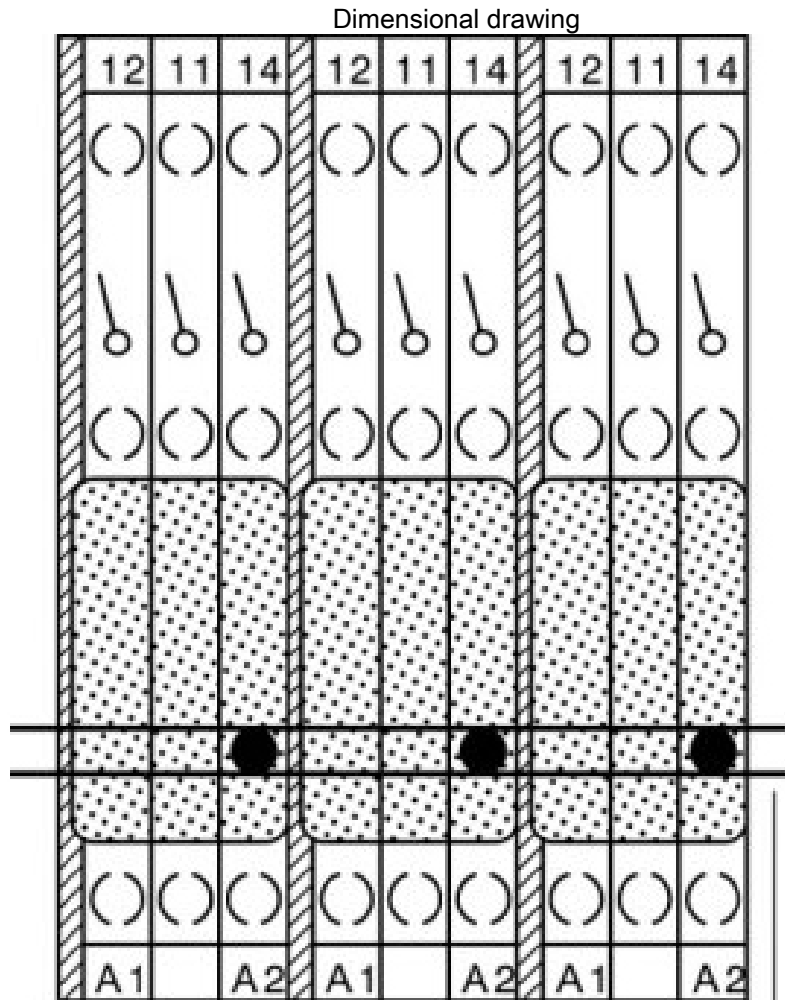

1 - 3


# UM-BEFE 35 - Base element



2955564

<https://www.phoenixcontact.com/us/products/2955564>

Dimensional drawing

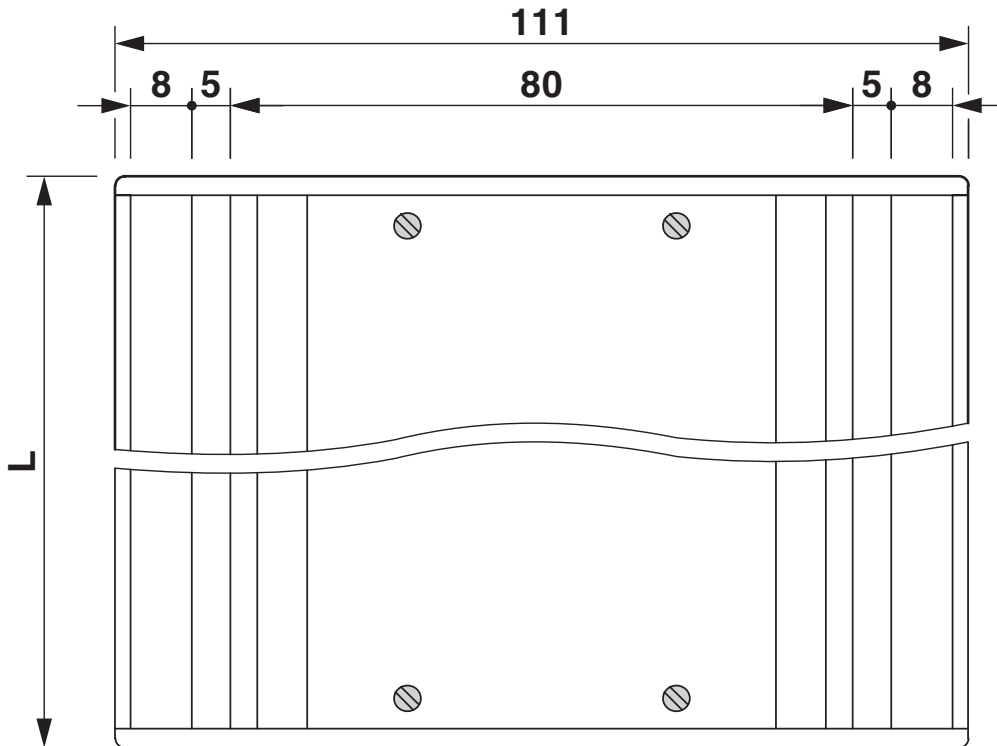

# UM-BEFE 35 - Base element



2955564

<https://www.phoenixcontact.com/us/products/2955564>

## Approvals

To download certificates, visit the product detail page: <https://www.phoenixcontact.com/us/products/2955564>



**UL Recognized**

Approval ID: E240868

# UM-BEFE 35 - Base element



2955564

<https://www.phoenixcontact.com/us/products/2955564>

## Classifications

### ECLASS

ECLASS-13.0	27190601
ECLASS-15.0	27190601

### ETIM

ETIM 10.0	EC002779
-----------	----------

### UNSPSC

UNSPSC 21.0	31261500
-------------	----------

# UM-BEFE 35 - Base element



2955564

<https://www.phoenixcontact.com/us/products/2955564>

## Environmental product compliance

### EU RoHS

Fulfills EU RoHS substance requirements	Yes, No exemptions
---	--------------------

### China RoHS

Environment friendly use period (EFUP)	EFUP-E
	No hazardous substances above the limits

### EU REACH SVHC

REACH candidate substance (CAS No.)	No substance above 0.1 wt%
-------------------------------------	----------------------------

### EF3.1 Climate Change

CO2e kg	0.349 kg CO2e
---------	---------------

Phoenix Contact 2026 © - all rights reserved  
<https://www.phoenixcontact.com>

Phoenix Contact USA  
586 Fulling Mill Road  
Middletown, PA 17057, United States  
(+717) 944-1300  
[info@phoenixcon.com](mailto:info@phoenixcon.com)