

FBST 6-PLC GY - Single plug-in bridge




2966825

<https://www.phoenixcontact.com/us/products/2966825>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.

Single plug-in bridge, number of positions: 2, nominal current: 6 A, length: 6 mm, color: gray

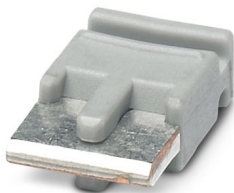

Commercial data

| | |
|--------------------------------------|---------------|
| Item number | 2966825 |
| Packing unit | 50 pc |
| Minimum order quantity | 50 pc |
| Sales key | C461 |
| Product key | DK62Z1 |
| GTIN | 4017918130640 |
| Weight per piece (including packing) | 0.445 g |
| Weight per piece (excluding packing) | 0.439 g |
| Customs tariff number | 85366990 |
| Country of origin | DE |

FBST 6-PLC GY - Single plug-in bridge



2966825

<https://www.phoenixcontact.com/us/products/2966825>

Technical data

Product properties

| | |
|---------------------|--------|
| Product type | Bridge |
| Number of positions | 2 |

Electrical properties

| | |
|----------------------|-----|
| Maximum load current | 6 A |
|----------------------|-----|

Connection data

| | |
|----------------------|-----|
| Maximum load current | 6 A |
|----------------------|-----|

Dimensions

| | |
|--------|------|
| Length | 6 mm |
|--------|------|

Material specifications

| | |
|--|-----------------|
| Color | gray (RAL 7042) |
| Flammability rating according to UL 94 | V0 |

Environmental and real-life conditions

Ambient conditions

| | |
|--|------------------|
| Ambient temperature (operation) (UL (Haz. Loc.)) | -40 °C ... 70 °C |
|--|------------------|

Approvals

UL, USA/Canada

| | |
|----------------|------------------------------------|
| Identification | Class I, Zone 2, AEx ec IIC T4 |
| | Class I, Zone 2, Ex ec IIC Gc T4 X |

FBST 6-PLC GY - Single plug-in bridge



2966825

<https://www.phoenixcontact.com/us/products/2966825>

Approvals

To download certificates, visit the product detail page: <https://www.phoenixcontact.com/us/products/2966825>



GL

Approval ID: 46016-03 HH



cULus Listed

Approval ID: E140324



cULus Listed

Approval ID: E140324



cULus Listed

Approval ID: E140324



cULus Listed

Approval ID: E199827

FBST 6-PLC GY - Single plug-in bridge



2966825

<https://www.phoenixcontact.com/us/products/2966825>

Classifications

ECLASS

| | |
|-------------|----------|
| ECLASS-13.0 | 27250303 |
| ECLASS-15.0 | 27250303 |

ETIM

| | |
|-----------|----------|
| ETIM 10.0 | EC000489 |
|-----------|----------|

UNSPSC

| | |
|-------------|----------|
| UNSPSC 21.0 | 39121400 |
|-------------|----------|

FBST 6-PLC GY - Single plug-in bridge



2966825

<https://www.phoenixcontact.com/us/products/2966825>

Environmental product compliance

EU RoHS

| | |
|---|--------------------|
| Fulfills EU RoHS substance requirements | Yes, No exemptions |
|---|--------------------|

China RoHS

| | |
|--|--|
| Environment friendly use period (EFUP) | EFUP-E |
| | No hazardous substances above the limits |

EU REACH SVHC

| | |
|-------------------------------------|----------------------------|
| REACH candidate substance (CAS No.) | No substance above 0.1 wt% |
|-------------------------------------|----------------------------|

EF3.1 Climate Change

| | |
|---------|---------------|
| CO2e kg | 0.022 kg CO2e |
|---------|---------------|

Phoenix Contact 2026 © - all rights reserved
<https://www.phoenixcontact.com>

Phoenix Contact USA
586 Fulling Mill Road
Middletown, PA 17057, United States
(+717) 944-1300
info@phoenixcon.com