

UMK-BE 11,25 GY - Base element



2973070

<https://www.phoenixcontact.com/us/products/2973070>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



Electronic board base, plug-in module base element

The figure shows a combination of versions UMK SE 11,25, UMK BE 11,25,- 22,5, - 45 and UMK-FE, in green

Commercial data

| | |
|--------------------------------------|---------------|
| Item number | 2973070 |
| Packing unit | 10 pc |
| Minimum order quantity | 1,000 pc |
| Product key | ACHDCA |
| GTIN | 4017918249359 |
| Weight per piece (including packing) | 4.65 g |
| Weight per piece (excluding packing) | 4.65 g |
| Country of origin | PL |

UMK-BE 11,25 GY - Base element

2973070

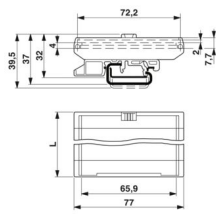
<https://www.phoenixcontact.com/us/products/2973070>

Technical data

Product properties

| | |
|----------------|---|
| Product type | Lower housing part |
| Housing type | Panel mounting base |
| Product family | UMK BE |
| Type | Module width 11.25 mm, since the housing can remain open at the top, it is possible for parts to protrude above the actual profile height |

Dimensions

| | |
|---------------------|---|
| Dimensional drawing |  |
| Width | 33.75 mm |
| Length | 77 mm |

Material specifications

| | |
|--|------|
| Color | gray |
| Flammability rating according to UL 94 | V2 |
| Housing material | PA |

Environmental and real-life conditions

Ambient conditions

| | |
|---------------------------------|-------------------|
| Ambient temperature (operation) | -40 °C ... 105 °C |
|---------------------------------|-------------------|

UMK-BE 11,25 GY - Base element

2973070

<https://www.phoenixcontact.com/us/products/2973070>

Drawings



UMK-BE 11,25 GY - Base element



2973070

<https://www.phoenixcontact.com/us/products/2973070>

Environmental product compliance

EU RoHS

| | |
|---|--------------------|
| Fulfills EU RoHS substance requirements | Yes, No exemptions |
|---|--------------------|

China RoHS

| | |
|--|--|
| Environment friendly use period (EFUP) | EFUP-E |
| | No hazardous substances above the limits |

EU REACH SVHC

| | |
|-------------------------------------|----------------------------|
| REACH candidate substance (CAS No.) | No substance above 0.1 wt% |
|-------------------------------------|----------------------------|

Phoenix Contact 2026 © - all rights reserved
<https://www.phoenixcontact.com>

Phoenix Contact USA
586 Fulling Mill Road
Middletown, PA 17057, United States
(+717) 944-1300
info@phoenixcon.com