


# UMK- EC90/32/EEX-XOL - Termination board



2975803

<https://www.phoenixcontact.com/us/products/2975803>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.

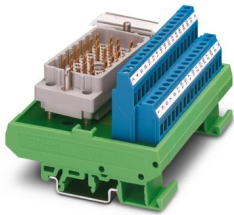

Termination board, connection 1: Screw connection, connection 2: ELCO connector 1x 32-position (Pin strip type 8016 (EEx i protection), left)

## Commercial data

Item number	2975803
Packing unit	1 pc
Note	Made to order (non-returnable)
Sales key	C422
Product key	DK2186
GTIN	4017918089122
Weight per piece (including packing)	233.5 g
Weight per piece (excluding packing)	198.08 g
Customs tariff number	85369010
Country of origin	DE

2975803

<https://www.phoenixcontact.com/us/products/2975803>

## Technical data

### Product properties

Product type	Interface module
Number of positions	32

### Electrical properties

Nominal voltage $U_N$	30 V AC/DC
Max. current carrying capacity per branch	2 A
Max. total current of all branches	64 A (32 branches with 2 A each)

### Connection data

#### Field level

Connection in acc. with standard	IEC / EN
Connection method	Screw connection
Stripping length	8 mm
Screw thread	M3
Conductor cross-section rigid	0.2 mm <sup>2</sup> ... 4 mm <sup>2</sup>
Conductor cross-section flexible	0.2 mm <sup>2</sup> ... 2.5 mm <sup>2</sup>
Conductor cross-section AWG	24 ... 12

#### Controller level

Connection method	ELCO connector
Number of connections	1
Number of positions	32
Note	Pin strip type 8016 (EEx i protection), left

### Signaling

Status display present	no
------------------------	----

### Dimensions

#### Item dimensions

Width	101.3 mm
Height	77 mm
Depth	58.5 mm

### Material specifications

Color	green (RAL 6021)
Housing insulation material	Polyamide PA non-reinforced

### Environmental and real-life conditions

#### Ambient conditions

Ambient temperature (operation)	-20 °C ... 40 °C
---------------------------------	------------------

# UMK- EC90/32/EEX-XOL - Termination board



2975803

<https://www.phoenixcontact.com/us/products/2975803>

Ambient temperature (storage/transport)	-20 °C ... 70 °C
---	------------------

## Standards and regulations

Standards/regulations	EN 50020
-----------------------	----------

## Mounting

Mounting position	any
-------------------	-----

## Notes

Notes on operation	For proper use, the specifications of the installation directive (see Downloads) must be observed. For applications or use with third-party products, the specifications, and the safety and warning instructions of the respective third-party manufacturer must also be met.
--------------------	--

# UMK- EC90/32/EEX-XOL - Termination board


2975803

<https://www.phoenixcontact.com/us/products/2975803>



## Drawings

Dimensional drawing

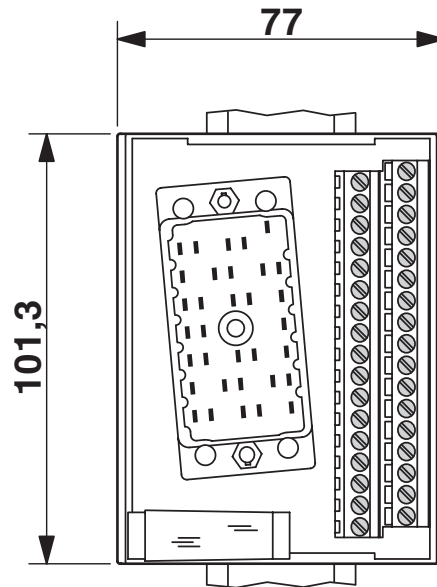

# UMK- EC90/32/EEX-XOL - Termination board



2975803

<https://www.phoenixcontact.com/us/products/2975803>

## Environmental product compliance

EU REACH SVHC

REACH candidate substance (CAS No.)	No substance above 0.1 wt%
-------------------------------------	----------------------------

Phoenix Contact 2026 © - all rights reserved

<https://www.phoenixcontact.com>

Phoenix Contact USA  
586 Fulling Mill Road  
Middletown, PA 17057, United States  
(+717) 944-1300  
[info@phoenixcon.com](mailto:info@phoenixcon.com)