


URTK/S VT-TERMINAL GROUP - Sample set



3030064

<https://www.phoenixcontact.com/us/products/3030064>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.

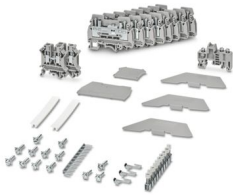

The set consists of the following: 8 x URTK/S, 2 x UK 6 N, 1 x D-UK 4/10, 1 x E/UK, 3 x USB 2-RTK/S, 3 x ATS-RTK, 1 x D-URTK, 1 x FB 10-RTK/S, 2 x ZB 8:UNBEDRUCKT

Commercial data

Item number	3030064
Packing unit	1 pc
Minimum order quantity	1 pc
Product key	BE1233
GTIN	4017918406127
Weight per piece (including packing)	449 g
Weight per piece (excluding packing)	449 g
Country of origin	DE

URTK/S VT-TERMINAL GROUP - Sample set



3030064

<https://www.phoenixcontact.com/us/products/3030064>

Set consists of

URTK/S - Test disconnect terminal block

0311087

<https://www.phoenixcontact.com/us/products/0311087>



Test disconnect terminal block, with two test sockets for 4 mm test plugs, or for receiving bridge bars or screw bridges, nom. voltage: 400 V, nominal current: 41 A, connection method: Screw connection, Rated cross section: 6 mm², cross section: 0.5 mm² - 10 mm², mounting type: NS 35/7,5, NS 35/15, NS 32, color: gray

UK 6 N - Feed-through terminal block

3004524

<https://www.phoenixcontact.com/us/products/3004524>



Feed-through terminal block, nom. voltage: 800 V, nominal current: 41 A, number of connections: 2, connection method: Screw connection, Rated cross section: 6 mm², cross section: 0.2 mm² - 10 mm², mounting type: NS 32, NS 35/7,5, NS 35/15, color: gray

URTK/S VT-TERMINAL GROUP - Sample set



3030064

<https://www.phoenixcontact.com/us/products/3030064>

D-UK 4/10 - End cover

3003020

<https://www.phoenixcontact.com/us/products/3003020>




End cover, depth: 35.9 mm, width: 1.8 mm, height: 42.5 mm, color: gray

E/UK - End bracket

1201442

<https://www.phoenixcontact.com/us/products/1201442>

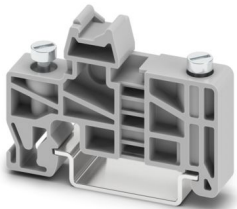

End bracket, The recommended tightening torque of 0.6 Nm to 0.8 Nm applies exclusively to the currently manufactured E/UK variant (V/C 05). A torque range of 0.5 Nm to 0.6 Nm is recommended for the previous variant (V/C 04). The V/C code can be found on the product label., material: PA, mounting type: NS 35/7,5, NS 35/15, color: gray

URTK/S VT-TERMINAL GROUP - Sample set



3030064

<https://www.phoenixcontact.com/us/products/3030064>

USB 2-RTK/S - Bridge bar

0311278

<https://www.phoenixcontact.com/us/products/0311278>



Bridge bar, pitch: 8.2 mm, number of positions: 2, color: silver-colored

ATS-RTK - Partition plate

0310224

<https://www.phoenixcontact.com/us/products/0310224>



Partition plate, depth: 45.8 mm, width: 0.8 mm, height: 97.5 mm, color: gray

URTK/S VT-TERMINAL GROUP - Sample set



3030064

<https://www.phoenixcontact.com/us/products/3030064>

D-URTK - Cover

0310020

<https://www.phoenixcontact.com/us/products/0310020>

Cover, depth: 41.5 mm, width: 2.2 mm, height: 72 mm, color: gray



FBI 10- 8 - Fixed bridge

0203263

<https://www.phoenixcontact.com/us/products/0203263>

Fixed bridge, pitch: 8 mm, number of positions: 10, color: silver-colored



URTK/S VT-TERMINAL GROUP - Sample set

3030064

<https://www.phoenixcontact.com/us/products/3030064>

FB 10- RTK/S - Screw bridge

0311171

<https://www.phoenixcontact.com/us/products/0311171>




Screw bridge, pitch: 8.2 mm, number of positions: 10, color: silver-colored

ZB 8:UNBEDRUCKT - Zack marker strip

1052002

<https://www.phoenixcontact.com/us/products/1052002>

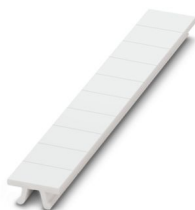

Zack marker strip, Strip, white (RAL 9010), unmarked, can be labeled with: PLOTMARK, CMS-P1-PLOTTER, mounting type: latching, for terminal block width: 8.2 mm, Number of individual labels: 10, text field height: 10.5 mm, text field width: 7 mm

URTK/S VT-TERMINAL GROUP - Sample set



3030064

<https://www.phoenixcontact.com/us/products/3030064>

Technical data

Product properties

Product type	Sample set
--------------	------------

Environmental and real-life conditions

Ambient conditions

Ambient temperature (operation)	-60 °C ... 105 °C (max. short-term operating temperature RTI Elec.)
Ambient temperature (storage/transport)	-25 °C ... 60 °C (for a short time, not exceeding 24 h, -60 °C to +70 °C)
Ambient temperature (assembly)	-5 °C ... 70 °C
Ambient temperature (actuation)	-5 °C ... 70 °C
Permissible humidity (storage/transport)	30 % ... 70 %

URTK/S VT-TERMINAL GROUP - Sample set



3030064

<https://www.phoenixcontact.com/us/products/3030064>

Classifications

UNSPSC

UNSPSC 21.0	26121600
-------------	----------

3030064

<https://www.phoenixcontact.com/us/products/3030064>

Environmental product compliance

China RoHS

Environment friendly use period (EFUP)	EFUP-50
	An article-related China RoHS declaration table can be found in the download area for the respective article under "Manufacturer declaration". For all articles with EFUP-E, no China RoHS declaration table issued and required.

EU REACH SVHC

REACH candidate substance (CAS No.)	No substance above 0.1 wt%
-------------------------------------	----------------------------

Phoenix Contact 2026 © - all rights reserved
<https://www.phoenixcontact.com>

Phoenix Contact USA
586 Fulling Mill Road
Middletown, PA 17057, United States
(+717) 944-1300
info@phoenixcon.com