


# URTK/S VT-TERMINAL GROUP - Sample set



3030064

<https://www.phoenixcontact.com/us/products/3030064>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.

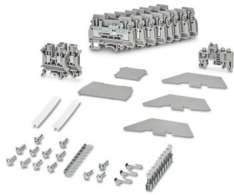

The set consists of the following: 8 x URTK/S, 2 x UK 6 N, 1 x D-UK 4/10, 1 x E/UK, 3 x USB 2-RTK/S, 3 x ATS-RTK, 1 x D-URTK, 1 x FB 10-RTK/S, 2 x ZB 8:UNBEDRUCKT

## Commercial data

Item number	3030064
Packing unit	1 pc
Minimum order quantity	1 pc
Product key	BE1233
GTIN	4017918406127
Weight per piece (including packing)	449 g
Weight per piece (excluding packing)	449 g
Country of origin	DE

# URTK/S VT-TERMINAL GROUP - Sample set



3030064

<https://www.phoenixcontact.com/us/products/3030064>

## Set consists of

### URTK/S - Test disconnect terminal block

0311087

<https://www.phoenixcontact.com/us/products/0311087>



Test disconnect terminal block, with two test sockets for 4 mm test plugs, or for receiving bridge bars or screw bridges, nom. voltage: 400 V, nominal current: 41 A, connection method: Screw connection, Rated cross section: 6 mm<sup>2</sup>, cross section: 0.5 mm<sup>2</sup> - 10 mm<sup>2</sup>, mounting type: NS 35/7,5, NS 35/15, NS 32, color: gray

---

### UK 6 N - Feed-through terminal block

3004524

<https://www.phoenixcontact.com/us/products/3004524>



Feed-through terminal block, nom. voltage: 800 V, nominal current: 41 A, number of connections: 2, connection method: Screw connection, Rated cross section: 6 mm<sup>2</sup>, cross section: 0.2 mm<sup>2</sup> - 10 mm<sup>2</sup>, mounting type: NS 32, NS 35/7,5, NS 35/15, color: gray

# URTK/S VT-TERMINAL GROUP - Sample set



3030064

<https://www.phoenixcontact.com/us/products/3030064>

## D-UK 4/10 - End cover

3003020

<https://www.phoenixcontact.com/us/products/3003020>




End cover, depth: 35.9 mm, width: 1.8 mm, height: 42.5 mm, color: gray

---

## E/UK - End bracket

1201442

<https://www.phoenixcontact.com/us/products/1201442>

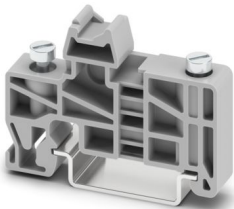

End bracket, The recommended tightening torque of 0.6 Nm to 0.8 Nm applies exclusively to the currently manufactured E/UK variant (V/C 05). A torque range of 0.5 Nm to 0.6 Nm is recommended for the previous variant (V/C 04). The V/C code can be found on the product label., material: PA, mounting type: NS 35/7,5, NS 35/15, color: gray

# URTK/S VT-TERMINAL GROUP - Sample set



3030064

<https://www.phoenixcontact.com/us/products/3030064>

## USB 2-RTK/S - Bridge bar

0311278

<https://www.phoenixcontact.com/us/products/0311278>



Bridge bar, pitch: 8.2 mm, number of positions: 2, color: silver-colored

---

## ATS-RTK - Partition plate

0310224

<https://www.phoenixcontact.com/us/products/0310224>



Partition plate, depth: 45.8 mm, width: 0.8 mm, height: 97.5 mm, color: gray

# URTK/S VT-TERMINAL GROUP - Sample set



3030064

<https://www.phoenixcontact.com/us/products/3030064>

## D-URTK - Cover

0310020

<https://www.phoenixcontact.com/us/products/0310020>

Cover, depth: 41.5 mm, width: 2.2 mm, height: 72 mm, color: gray



---

## FBI 10- 8 - Fixed bridge

0203263

<https://www.phoenixcontact.com/us/products/0203263>

Fixed bridge, pitch: 8 mm, number of positions: 10, color: silver-colored



# URTK/S VT-TERMINAL GROUP - Sample set



3030064

<https://www.phoenixcontact.com/us/products/3030064>

## FB 10- RTK/S - Screw bridge

0311171

<https://www.phoenixcontact.com/us/products/0311171>



Screw bridge, pitch: 8.2 mm, number of positions: 10, color: silver-colored

---

## ZB 8:UNBEDRUCKT - Zack marker strip

1052002

<https://www.phoenixcontact.com/us/products/1052002>



Zack marker strip, Strip, white (RAL 9010), unmarked, can be labeled with: PLOTMARK, CMS-P1-PLOTTER, mounting type: latching, for terminal block width: 8.2 mm, Number of individual labels: 10, text field height: 10.5 mm, text field width: 7 mm

# URTK/S VT-TERMINAL GROUP - Sample set



3030064

<https://www.phoenixcontact.com/us/products/3030064>

## Technical data

### Product properties

Product type	Sample set
--------------	------------

### Environmental and real-life conditions

#### Ambient conditions

Ambient temperature (operation)	-60 °C ... 105 °C (max. short-term operating temperature RTI Elec.)
Ambient temperature (storage/transport)	-25 °C ... 60 °C (for a short time, not exceeding 24 h, -60 °C to +70 °C)
Ambient temperature (assembly)	-5 °C ... 70 °C
Ambient temperature (actuation)	-5 °C ... 70 °C
Permissible humidity (storage/transport)	30 % ... 70 %

# URTK/S VT-TERMINAL GROUP - Sample set



3030064

<https://www.phoenixcontact.com/us/products/3030064>

## Classifications

### UNSPSC

UNSPSC 21.0	26121600
-------------	----------

3030064

<https://www.phoenixcontact.com/us/products/3030064>

## Environmental product compliance

### China RoHS

Environment friendly use period (EFUP)	EFUP-50
	An article-related China RoHS declaration table can be found in the download area for the respective article under "Manufacturer declaration". For all articles with EFUP-E, no China RoHS declaration table issued and required.

### EU REACH SVHC

REACH candidate substance (CAS No.)	No substance above 0.1 wt%
-------------------------------------	----------------------------

Phoenix Contact 2026 © - all rights reserved  
<https://www.phoenixcontact.com>

Phoenix Contact USA  
586 Fulling Mill Road  
Middletown, PA 17057, United States  
(+717) 944-1300  
[info@phoenixcon.com](mailto:info@phoenixcon.com)