

PS-5 - Test plug

3030983

<https://www.phoenixcontact.com/us/products/3030983>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.

Test plug, Modular test plug, number of positions: 1, color: red



Your advantages

- The test plugs make contact in the function shaft of terminal blocks from the CLIPLINE complete system
- Test adapters can be assembled individually using PS-... modular test plugs

Commercial data

| | |
|--------------------------------------|---------------|
| Item number | 3030983 |
| Packing unit | 10 pc |
| Minimum order quantity | 10 pc |
| Sales key | BE29 |
| Product key | BE2Z3X |
| GTIN | 4017918818920 |
| Weight per piece (including packing) | 3.4 g |
| Weight per piece (excluding packing) | 1.2 g |
| Customs tariff number | 85366990 |
| Country of origin | PL |

PS-5 - Test plug

3030983

<https://www.phoenixcontact.com/us/products/3030983>



Technical data

Product properties

| | |
|---------------------|--------------------------|
| Product type | Test plug terminal block |
| Number of positions | 1 |


Electrical properties

| | |
|----------------------|-------|
| Maximum load current | 2 A |
| Max. voltage | 250 V |

Connection data

| | |
|----------------------------------|--|
| Maximum load current | 2 A |
| Connection method | Spring-cage connection |
| Conductor cross-section flexible | 0.14 mm ² ... 1 mm ² |
| Conductor cross-section rigid | 0.14 mm ² ... 1 mm ² |
| Cross section AWG | 26 ... 18 |

Dimensions
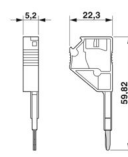
| | |
|---------------------|--|
| Dimensional drawing |  |
| Width | 5.2 mm |
| Height | 22.4 mm |
| Depth | 60 mm |

Material specifications

| | |
|--|----------------|
| Color | red (RAL 3001) |
| Material | PA |
| Flammability rating according to UL 94 | V0 |

Environmental and real-life conditions

Ambient conditions

| | |
|--|---|
| Ambient temperature (operation) | -60 °C ... 105 °C (max. short-term operating temperature RTI Elec.) |
| Ambient temperature (storage/transport) | -25 °C ... 60 °C (for a short time, not exceeding 24 h, -60 °C to +70 °C) |
| Ambient temperature (assembly) | -5 °C ... 70 °C |
| Ambient temperature (actuation) | -5 °C ... 70 °C |
| Permissible humidity (storage/transport) | 30 % ... 70 % |


PS-5 - Test plug

3030983

<https://www.phoenixcontact.com/us/products/3030983>



Drawings

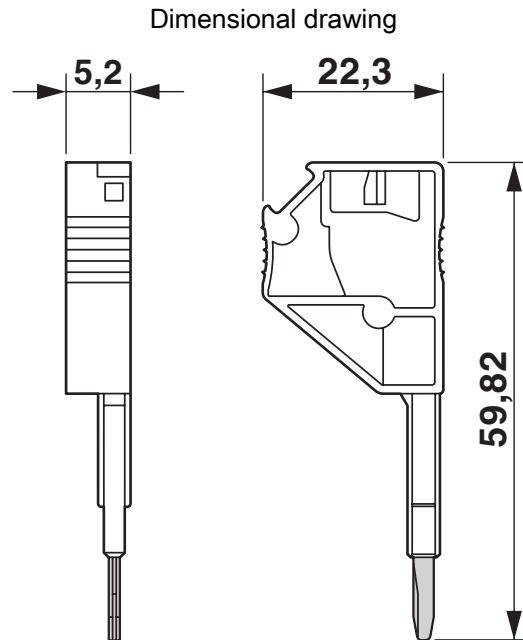

PS-5 - Test plug

3030983

<https://www.phoenixcontact.com/us/products/3030983>



Classifications

ECLASS

| | |
|-------------|----------|
| ECLASS-15.0 | 27250304 |
| ECLASS-13.0 | 27250304 |

ETIM

| | |
|-----------|----------|
| ETIM 10.0 | EC002555 |
|-----------|----------|

UNSPSC

| | |
|-------------|----------|
| UNSPSC 21.0 | 20122000 |
|-------------|----------|

PS-5 - Test plug

3030983

<https://www.phoenixcontact.com/us/products/3030983>



Environmental product compliance

EU RoHS

| | |
|---|--------------------|
| Fulfills EU RoHS substance requirements | Yes, No exemptions |
|---|--------------------|

China RoHS

| | |
|--|--|
| Environment friendly use period (EFUP) | EFUP-E |
| | No hazardous substances above the limits |

EU REACH SVHC

| | |
|-------------------------------------|----------------------------|
| REACH candidate substance (CAS No.) | No substance above 0.1 wt% |
|-------------------------------------|----------------------------|

EF3.1 Climate Change

| | |
|---------|---------------|
| CO2e kg | 0.055 kg CO2e |
|---------|---------------|

Phoenix Contact 2026 © - all rights reserved
<https://www.phoenixcontact.com>

Phoenix Contact USA
586 Fulling Mill Road
Middletown, PA 17057, United States
(+717) 944-1300
info@phoenixcon.com