


# UAB - Support bracket

3032428

<https://www.phoenixcontact.com/us/products/3032428>



Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.

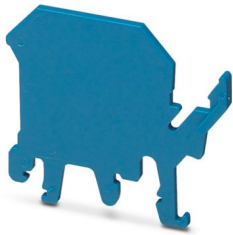

Support bracket, number of positions: 1, color: blue

## Commercial data

Item number	3032428
Packing unit	50 pc
Minimum order quantity	50 pc
Sales key	BE19
Product key	BE1ZWX
GTIN	4017918092252
Weight per piece (including packing)	3.87 g
Weight per piece (excluding packing)	3.806 g
Customs tariff number	39269097
Country of origin	DE

## Technical data

### Product properties

Product type	Support bracket
Number of positions	1
Pitch	200 mm

### Dimensions

Width	2 mm
Height	56 mm
Depth on NS 32	47 mm
Depth on NS 35/7,5	42 mm
Depth on NS 35/15	49.5 mm
Pitch	200 mm

### Material specifications

Color	blue (RAL 5015)
Flammability rating according to UL 94	V2
Insulating material	PA

### Environmental and real-life conditions

#### Ambient conditions

Ambient temperature (operation)	-60 °C ... 110 °C (Operating temperature range incl. self-heating; for max. short-term operating temperature, see RTI Elec.)
Ambient temperature (storage/transport)	-25 °C ... 60 °C (for a short time, not exceeding 24 h, -60 °C to +70 °C)
Ambient temperature (assembly)	-5 °C ... 70 °C
Ambient temperature (actuation)	-5 °C ... 70 °C
Permissible humidity (operation)	20 % ... 90 %
Permissible humidity (storage/transport)	30 % ... 70 %

# UAB - Support bracket

3032428

<https://www.phoenixcontact.com/us/products/3032428>



## Classifications

### ECLASS

ECLASS-13.0	27400607
ECLASS-15.0	27400607

### ETIM

ETIM 10.0	EC001166
-----------	----------

### UNSPSC

UNSPSC 21.0	39121700
-------------	----------

# UAB - Support bracket

3032428

<https://www.phoenixcontact.com/us/products/3032428>



## Environmental product compliance

### EU RoHS

Fulfills EU RoHS substance requirements	Yes, No exemptions
---	--------------------

### China RoHS

Environment friendly use period (EFUP)	EFUP-E
	No hazardous substances above the limits

### EU REACH SVHC

REACH candidate substance (CAS No.)	No substance above 0.1 wt%
-------------------------------------	----------------------------

### EF3.1 Climate Change

CO2e kg	0.016 kg CO2e
---------	---------------

Phoenix Contact 2026 © - all rights reserved  
<https://www.phoenixcontact.com>

Phoenix Contact USA  
586 Fulling Mill Road  
Middletown, PA 17057, United States  
(+717) 944-1300  
[info@phoenixcon.com](mailto:info@phoenixcon.com)